

40-60W, 2 x 4" AC-DC Power Supplies

Features

- ◆ Single Output
- ◆ Wide Range AC Input
- ◆ Low 1.07" profile
- ◆ Industry Standard Footprint
- ◆ Global Safety Agency Compliance
- ◆ Up to 88% efficiency



Key Market Segments & Applications



Specifications		
Model		ZPSA40 ZPSA60
Input Voltage range	-	90 - 264VAC (47 - 63Hz) or 120 - 370VDC*
Inrush Current (115 / 230VAC)	A	25 / 50
Input Current	A	< 1.2A < 1.4A
Leakage Current	mA	0.8mA maximum (264VAC, 60Hz)
Temperature Coefficient	-	±0.05%/°C
Voltage Accuracy	%	±1%
Minimum Load	-	None
Load Regulation	%	±1%
Line Regulation	%	±0.5%
Ripple & Noise	mV	1% or 50mV whichever is greater
Short Circuit Protection	-	Continuous - hiccup mode
Overvoltage Protection	V	Typically 110-130% of nominal
Hold Up Time (Typ)	ms	8ms at 115VAC input
LED Indicator	-	Green LED = OK
Operating Temperature	°C	0 to +70°C derate according to charts on page 2
Storage Temperature	°C	-20 to +85°C
Humidity (non condensing)	-	10 - 95% RH
Cooling	-	Convection
Withstand Voltage	-	Input to Ground 1.5kVAC, Input to Output 3kVAC, Output to Ground 500VAC for 1 min.
Isolation Resistance	-	>100M at 25C & 70%RH, Output to Ground 500VDC
Vibration (non operating)	-	-23.52m/s ² (10 - 55Hz: constant sweep 1 min X, Y, Z for 1 hour)
Shock	-	< 196.1 m/s ² (20G)
Safety Agency Certification	-	IEC/UL/CSA/EN62368-1, 60950-1, CE Mark
Conducted & Radiated EMI	-	EN55022-B, FCC Class B
Immunity	-	EN61000-4-2, -3, -4, -5, -6, -8, -11
Weight (Typ)	g	130
Size (WxLxH)	in	2 x 4 x 1.07 (including underside components)
Warranty	yrs	Two Years


*Safety certified for 47-63Hz input only

Model Selector

Model	Output (V)	Adjustment Range (V)	Maximum Output (A)	Peak Load (A)(4)	Output Power (W)	Efficiency (%)
ZPSA40-3R3	3.3	-	6.0	7.2	20	74
ZPSA60-3R3	3.3	-	8.0	8.5	26	74
ZPSA40-5	5	-	6.0	7.2	30	79
ZPSA60-5	5	-	8.0	9.0	40	79
ZPSA40-9	9	-	4.45	5.34	40	83
ZPSA60-9	9	-	6.67	8.0	60	83
ZPSA40-12	12	-	3.34	4.0	40	85
ZPSA60-12	12	-	5.0	6.0	60	85
ZPSA40-15	15	-	2.67	3.2	40	85
ZPSA60-15	15	-	4.0	4.8	60	85
ZPSA40-24	24	-	1.67	2.0	40	86
ZPSA60-24	24	-	2.5	3.0	60	86
ZPSA40-28	28	-	1.43	1.7	40	86
ZPSA60-28	28	-	2.14	2.6	60	86
ZPSA40-30	30	-	1.33	1.6	40	86
ZPSA60-30	30	-	2.0	2.4	60	86
ZPSA40-36	36	-	1.11	1.33	40	87
ZPSA60-36	36	-	1.67	2.0	60	86
ZPSA40-48	48	-	0.834	1.0	40	87
ZPSA60-48	48	-	1.25	1.5	60	87


(4) Average not to exceed max power, <30s, 10% duty cycle

Derating Curve

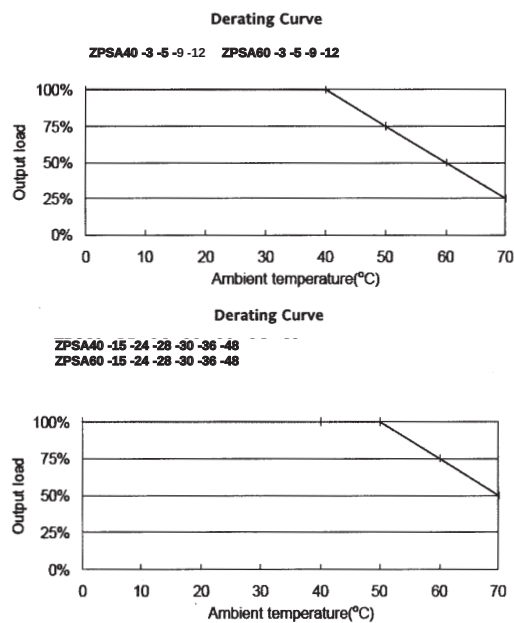

Outline Drawings

All Dimensions are in inches[mm]
Tolerances : $XX \pm 0.02$ [$XX \pm 0.5$] unless otherwise noted

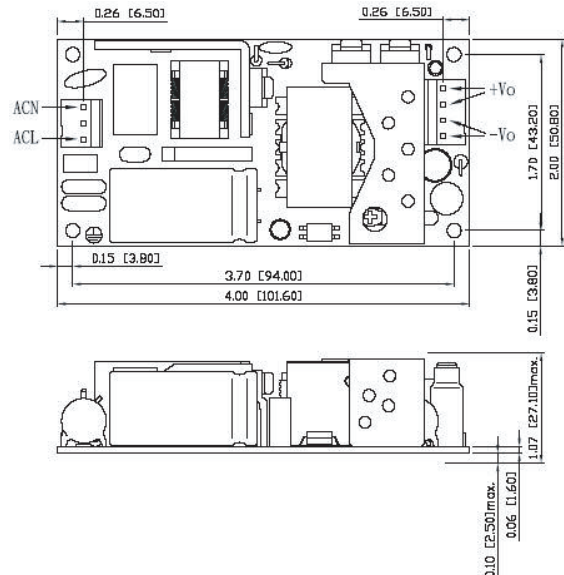

Other Industrial Products

SC40/60	40 to 80W, 3x5", 1 - 3 outputs
NV175	175W, 3x5", 1-5 outputs
ZWS	5 to 240W, single output
KPSA	5 to 15W, pcb mount
ZPD, ZPT	40W, 2x4" dual and triple outputs

Options

Suffix	Description
Blank	Molex connectors
/P	PCB mount pins

For additional information, please visit
<https://product.tdk.com/en/power/>



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

TDK-Lambda:

[ZPSA60-15](#) [ZPSA60-24](#) [ZPSA60-30](#) [ZPSA40-28](#) [ZPSA40-36](#) [ZPSA40-48](#) [ZPSA40-5](#) [ZPSA60-12](#) [ZPSA60-28](#)
[ZPSA60-5](#) [ZPSA60-9](#) [ZPSA40-12](#) [ZPSA40-24](#) [ZPSA40-15](#) [ZPSA40-30](#) [ZPSA40-3R3](#) [ZPSA40-9](#) [ZPSA60-36](#)
[ZPSA60-3R3](#) [ZPSA60-48](#)