

## Sponges

Plato® sponges are manufactured with pure cellulose (a wood derivative) which has the ability to absorb many times its weight in water. Also resistant to abrasion and tearing forces that occur during the tip wiping process. Cellular structure is designed to expand when wet, and retain water for long periods of time. Meets ANSI (J-STD-001B) for low sulfur content and fine porosity.


- Extend tip life
- Remove surface oxides
- Remove excess solder



### Product Dimensions


#### CS-1 Sponge

Comparable to Weller SP-60, Pace 4021-005  
1.5" x 2.12" x 1" thick (38mm x 54mm x 25mm)  
10 sponges/pack

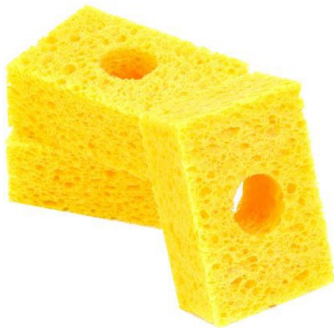


#### CS-9/625 Economy Sponge

Comparable to Hexacon 8101, 8101C, 8121, 8121C  
3.5" x 4.5" x 0.625" thick (89mm x 114mm x 16mm)  
10 sponges/pack

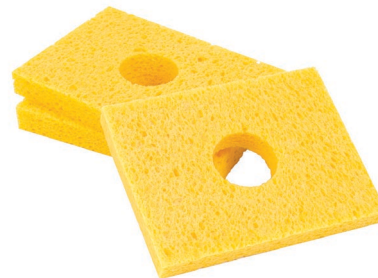


#### CS-14 Sponge

Comparable to Weller T52241999  
2.2" x 2.75" x 1" (55mm x 70mm x 25mm)  
10 sponges/pack

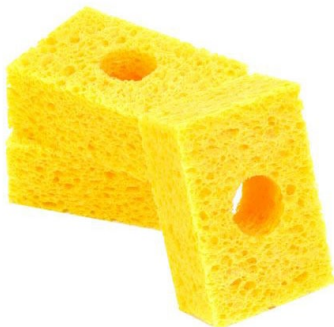

#### CS-14M Sponge w/multiple holes

Comparable to Weller T52241999  
2.2" x 2.75" 1" thick (55mm x 70mm x 25mm)  
10 sponges/pack

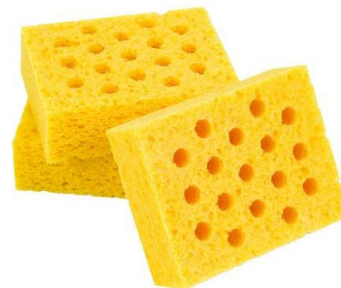

## Sponges

### Product Dimensions

#### CS-17 Sponge

Cut-to-fit sheet  
8" x 16" x 1" thick (203mm x 406mm x 25mm)  
1 sheet




#### CS-17/625 Economy Sponge

Cut-to-fit sheet  
8" x 16" x 0.625" thick (203mm x 406mm x 16mm)  
1 sheet




#### CS-36 Sponge

Comparable to Hexacon 8141, 8141C  
2.25" x 3.5" x 1" thick (57mm x 89mm x 25mm)  
10 sponges/pack

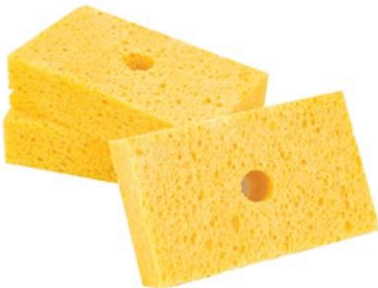


#### CS-44 Sponge

Comparable to Weller TC205  
2.7" x 2.7" x 1" thick (69mm x 69mm x 25mm)  
10 sponges/pack

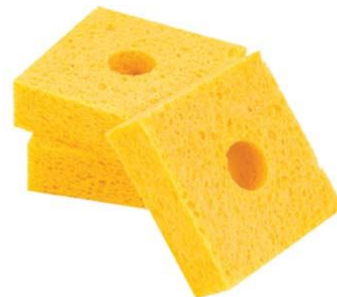


#### CS-44/625 Economy Sponge

Fits Hakko  
2.7" x 2.7" x 0.625" thick (69mm x 69mm x 16mm)  
10 sponges/pack

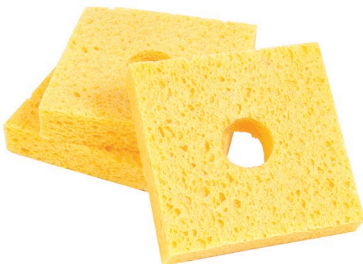

#### CS-47 Sponge

Comparable to Metcal STSS-YS3, AC-YS3, ACY10,  
Ungar 455, UTC234  
2.1" x 3.2" x 1" thick (53mm x 81mm x 25mm)  
10 sponges/pack

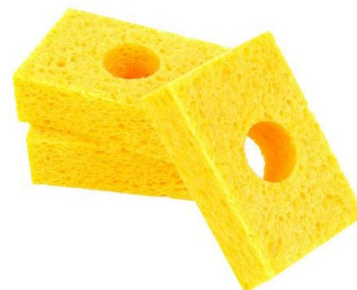



## Sponges

### Environmental Policy

We are committed to developing products to ensure a safer and cleaner environment. We will continue to meet and sustain the regulations of all federal, state and local government agencies.

### Resources

Plato products are supported by global sales, technical and customer services resources.

For additional technical information on these products or other Plato products in the United States, call the technical sales department at 800-858-4043, email [info@platoproducts.com](mailto:info@platoproducts.com) or visit our web site at: [www.platoproducts.com](http://www.platoproducts.com).

Important Notice to Purchaser/User: The information in this publication is based on tests that we believe are reliable. The results may vary due to differences in tests type and conditions. We recommend that each user evaluate the product to determine its suitability for the intended application. Conditions of use are outside our control and vary widely. Our only obligation and your only solution is replacement of product that is shown to be defective when you receive it. In no case will we be liable for any special, incidental, or consequential damages based on breach of warranty, negligence or any other theory.



● **Corporate Office**  
8125 Cobb Center Drive  
Kennesaw, GA 30152  
800-858-4043  
[tsales@techspray.com](mailto:tsales@techspray.com)

● **Europe**  
ITW Contamination Control BV  
Saffierlaan 5, 2132 VZ Hoofddorp  
The Netherlands  
+31 88 1307 400  
[info@itw-cc.com](mailto:info@itw-cc.com)

● **China**  
ITW Specialty Materials (Suzhou) Co., Ltd  
Hengqiao Road, Wujiang Economic  
Development Zone, Suzhou,  
Jiangsu Province, China 215200  
+6019-2184801  
[chinasales@itwsms.com](mailto:chinasales@itwsms.com)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Techspray:](#)

[CS-17/625](#)