

Biconical Antenna for Tektronix EMC pre-compliance

EMI-BICON-ANT (Com-Power ABF-900A offered by Tektronix)



The EMI-BICON-ANT is the Com-Power ABF-900A offered by Tektronix. This is a flexible biconical antenna. It can be used for emissions and immunity testing to meet various EMC standards. It has a frequency range of 25 MHz - 300 MHz. The flexible and foldable conical elements allow for easy storage and transport.


Key features

- Frequency range: 25 MHz to 300 MHz
- Collapsible antenna elements
- Individual calibration


Specifications

Antenna


Antenna type	Collapsible biconical
Frequency range	25 MHz – 300 MHz
Nominal input impedance	50 Ω
Polarization	Linear
Continuous input power (CW)	50 Watts
Connector	N-type (female)
Dimensions	134 cm x 73 cm
Weight	4.5 kg (max)
Antenna factor	

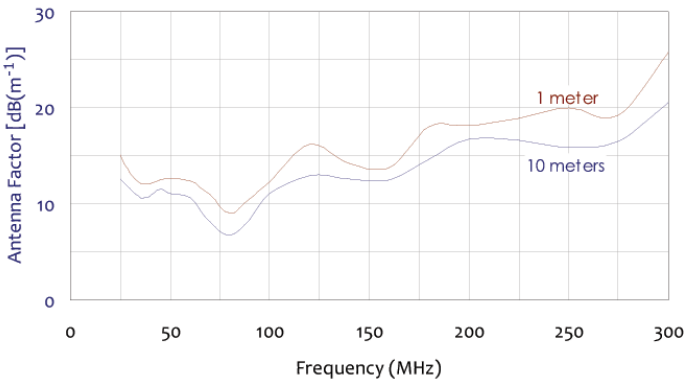


Isotropic gain

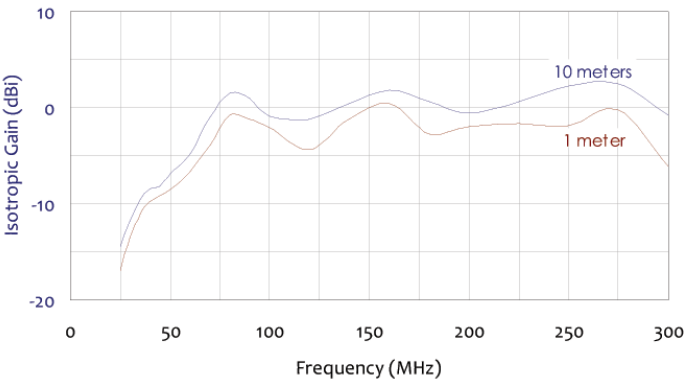

Return loss

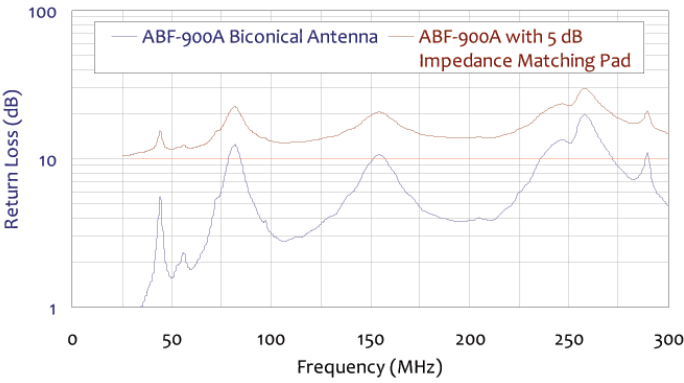

Field strength

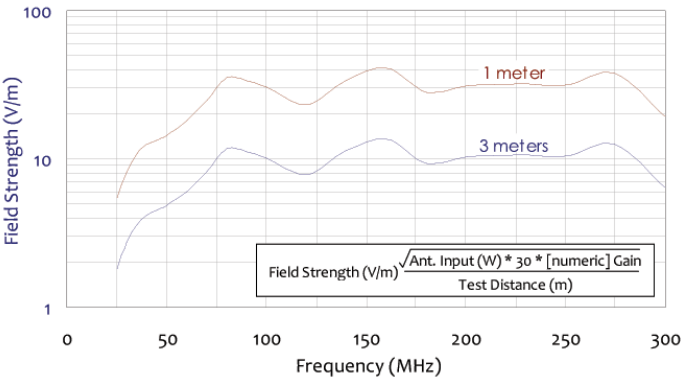

Ordering information

EMI-BICON-ANT and related accessories

Item	Description
EMI-BICON-ANT	25 MHz to 300 MHz collapsible biconical antenna
EMI-TRIPOD	Antenna Tripod:- Wood-Nylon, 0.8 to 1.5 meter adjustable height

Warranty

Three year warranty. All service provided by Com-Power Corporation. Contact <https://www.com-power.com/index.html> for service.

ASEAN / Australasia (65) 6356 3900
Belgium 00800 2255 4835*
Central East Europe and the Baltics +41 52 675 3777
Finland +41 52 675 3777
Hong Kong 400 820 5835
Japan 81 (3) 6714 3086
Middle East, Asia, and North Africa +41 52 675 3777
People's Republic of China 400 820 5835
Republic of Korea +822 6917 5084, 822 6917 5080
Spain 00800 2255 4835*
Taiwan 886 (2) 2656 6688

Austria 00800 2255 4835*
Brazil +55 (11) 3759 7627
Central Europe & Greece +41 52 675 3777
France 00800 2255 4835*
India 000 800 650 1835
Luxembourg +41 52 675 3777
The Netherlands 00800 2255 4835*
Poland +41 52 675 3777
Russia & CIS +7 (495) 6647564
Sweden 00800 2255 4835*
United Kingdom & Ireland 00800 2255 4835*

Balkans, Israel, South Africa and other ISE Countries +41 52 675 3777
Canada 1 800 833 9200
Denmark +45 80 88 1401
Germany 00800 2255 4835*
Italy 00800 2255 4835*
Mexico, Central/South America & Caribbean 52 (55) 56 04 50 90
Norway 800 16098
Portugal 80 08 12370
South Africa +41 52 675 3777
Switzerland 00800 2255 4835*
USA 1 800 833 9200

* European toll-free number. If not accessible, call: +41 52 675 3777

For Further Information. Tektronix maintains a comprehensive, constantly expanding collection of application notes, technical briefs and other resources to help engineers working on the cutting edge of technology. Please visit www.tek.com.

Copyright © Tektronix, Inc. All rights reserved. Tektronix products are covered by U.S. and foreign patents, issued and pending. Information in this publication supersedes that in all previously published material. Specification and price change privileges reserved. TEKTRONIX and TEK are registered trademarks of Tektronix, Inc. All other trade names referenced are the service marks, trademarks, or registered trademarks of their respective companies.



29 Jan 2018 37W-61344-0



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tektronix:](#)

[EMI-BICON-ANT](#)