


Fixed Wall Mount for 13" to 27" TVs and Monitors

MODEL NUMBER: DWF1327M

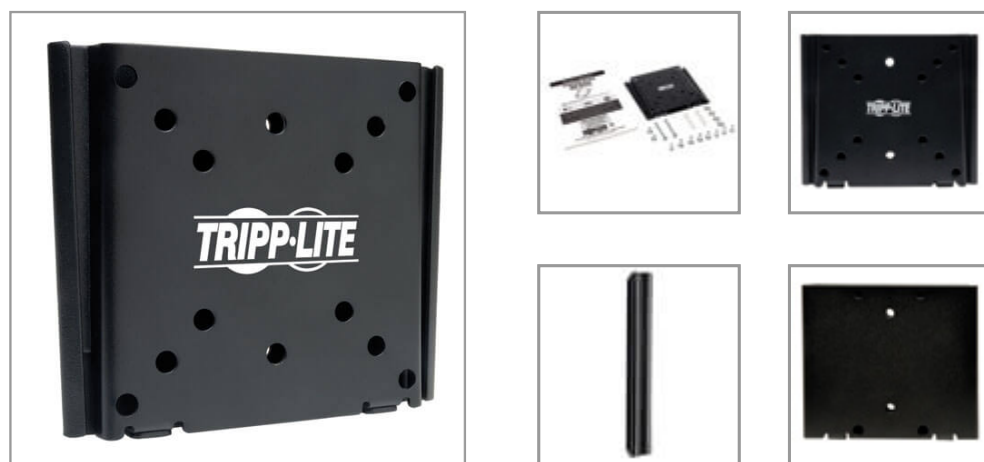

Low-profile mount hangs a flat-panel television, monitor or other display on the wall. Ideal for classrooms, boardrooms, hotels, bars and restaurants.

Description

The VESA-compliant DWF1327M Fixed Wall Mount allows you to mount your flat-panel television, monitor or other display on the wall. Ideal for classrooms, boardrooms, hotels, bars and restaurants, it fits most flat-panel displays from 13 to 27 inches. The low-profile mount is concealed behind the display to give a sleek, professional appearance. The durable all-metal frame with scratch-resistant powder-coated finish supports up to 88 lbs (39.9 kgs). Comes fully assembled for quick mounting to the wall with included hardware. Conforms to VESA-compliant displays with any of the following mounting hole patterns: 50 x 50 mm, 75 x 75 mm, 75 x 100 mm, 75 x 200 mm, 100 x 75 mm, 100 x 100 mm, 100 x 200 mm, 200 x 75 mm, 200 x 100 mm, and 200 x 200 mm.

Features

Mounts Your TV or Monitor to the Wall Fits most flat-panel televisions, monitors and other displays from 13 to 27 in. Ideal for classrooms, boardrooms, hotels, bars and restaurants. Mounts out of sight behind display for sleek, professional appearance. Mounting hardware included.

Durable Metal Construction Supports up to 88 lbs (39.9 kgs). Scratch-resistant powder-coated finish. Fully assembled for immediate installation.

VESA Compliance Supports the following VESA mounting hole patterns: 50 x 50 mm, 75 x 75 mm, 75 x 100 mm, 75 x 200 mm, 100 x 75 mm, 100 x 100 mm, 100 x 200 mm, 200 x 75 mm, 200 x 100 mm, and 200 x 200 mm.

Highlights

- Fits most flat-panel displays from 13 to 27 in.
- Hangs out of sight for a sleek, professional appearance
- Fully assembled for quick installation
- Supports up to 88 lbs (39.9 kgs)

Package Includes

- DWF1327M Fixed Wall Mount for 13" to 27" TVs and Monitor
- (2) M5 x 10 screws
- (4) M5 x 14 screws
- (4) M4 x 14 screws
- (4) D5 washers
- (2) Anchor bolts
- (2) Concrete anchors
- Owner's manual

Specifications

OVERVIEW	
UPC Code	037332183484
Device Compatibility	Monitor/HDTV
PHYSICAL	
Color	Black



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

VESA Pattern (mm)	100x100; 100x200; 100x75; 200x100; 200x200; 200x75; 50x50; 75x100; 75x200; 75x75
Degrees of Motion	Fixed
Material of Construction	Steel
Maximum Screen Size (cm)	68.58
Maximum Screen Size (in.)	27
Maximum Weight Capacity (kg)	40
Maximum Weight Capacity (lbs.)	88
Min/Max Arm Extension (cm)	N/A
Min/Max Arm Extension (in.)	N/A
Minimum Screen Size (in.)	13
Minimum Screen Size (cm)	33.02
Motion	Fixed
Mounting Location	Wall
Number of Displays	1
Shipping Dimensions (hwd / cm)	14.50 x 13.49 x 2.01
Shipping Dimensions (hwd / in.)	5.71 x 5.31 x 0.79
Shipping Weight (kg)	0.65
Shipping Weight (lbs.)	1.43
Unit Dimensions (hwd / cm)	12 x 14 x 1.5
Unit Dimensions (hwd / in.)	4.72 x 5.51 x .56
Unit Weight (kg)	0.65
Unit Weight (lbs.)	1.43
FEATURES & SPECIFICATIONS	
Tools Necessary	Yes
SPECIAL FEATURES	
Cord Management	No
Security Lock	No
STANDARDS & COMPLIANCE	
Approvals	RoHS3, REACH
WARRANTY	
Product Warranty Period (Worldwide)	5-year limited warranty



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies:

<https://www.tripplite.com/products/product-certification-agencies>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tripp Lite:](#)

[DWF1327M](#)