
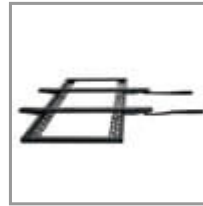


Fixed Wall Mount for 60" to 100" TVs and Monitors, UL Certified

MODEL NUMBER: DWF60100XX

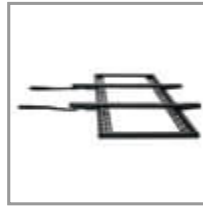

Low-profile mount hangs a flat-panel television, monitor or other display on the wall. Ideal for home theaters, classrooms, boardrooms, hotels, bars and restaurants.

Description

The VESA-compliant DWF60100XX Fixed Wall Mount allows you to mount your flat-panel television, monitor or other display on the wall. Ideal for home theaters, classrooms, boardrooms, hotels, bars and restaurants, it fits most flat-panel displays from 60 to 100 inches. The low-profile mount is concealed behind the display to give a sleek, professional appearance. Frame is open for easy wall access. Display brackets with connected straps adjust to compensate for off-center wall studs. Durable all-metal frame with scratch-resistant powder-coated finish supports up to 350 lbs (158.8 kgs). Mounting hardware included. Conforms to VESA-compliant displays with any of the following mounting hole patterns: 200 x 200 mm, 200 x 300 mm, 200 x 400 mm, 200 x 500 mm, 300 x 200 mm, 300 x 300 mm, 300 x 400 mm, 300 x 500 mm, 300 x 600 mm, 400 x 200 mm, 400 x 300 mm, 400 x 400 mm, 400 x 500 mm, 400 x 600 mm, 500 x 200 mm, 500 x 300 mm, 500 x 400 mm, 500 x 500 mm, 500 x 600 mm, 600 x 300 mm, 600 x 400 mm, 600 x 500 mm, 600 x 600 mm, 700 x 300 mm, 700 x 400 mm, 700 x 500 mm, 700 x 600 mm, 800 x 300 mm, 800 x 400 mm, 800 x 500 mm, 800 x 600 mm, 900 x 400 mm, 900 x 500 mm and 900 x 600 mm.

Features

Mounts Your TV or Monitor to the Wall Fits most flat-panel televisions, monitors and other displays from 60 to 100 in. Ideal for home theaters, classrooms, boardrooms, hotels, bars and restaurants. Mounts out of sight behind display for sleek, professional appearance. Mounting hardware included. Tested to accordance with UL Standard 2442.

Durable Metal Construction Supports up to 350 lbs (158.8 kgs). Open frame allows easy wall access. Adjustable display brackets with connected straps compensate for off-center wall studs. Scratch-resistant powder-coated finish.

VESA Compliance Supports the following VESA mounting hole patterns: 200 x 200 mm, 200 x 300 mm, 200 x 400 mm, 200 x 500 mm, 300 x 200 mm, 300 x 300 mm, 300 x 400 mm, 300 x 500 mm, 300 x 600 mm, 400 x 200 mm, 400 x 300 mm, 400 x 400 mm, 400 x 500 mm, 400 x 600 mm, 500 x 200 mm, 500 x 300 mm, 500 x 400 mm, 500 x 500 mm, 500 x 600 mm, 600 x 300 mm, 600 x 400 mm, 600 x 500 mm, 600 x 600 mm, 700 x 300 mm, 700 x 400 mm, 700 x 500 mm, 700 x 600 mm, 800 x 300 mm, 800 x 400 mm, 800 x 500 mm, 800 x 600 mm, 900 x 400 mm, 900 x 500 mm and 900 x 600 mm.

Specifications

Highlights

- Fits most flat-panel displays from 60 to 100 in.
- Hangs out of sight for a sleek, professional appearance
- Open frame for easy wall access
- Supports up to 350 lbs (158.8 kgs)

Package Includes

- Wall plate
- (2) Adapter brackets
- (4) M5 x 14 screws
- (4) M6 x 14 screws
- (4) M6 x 30 screws
- (4) M8 x 20 screws
- (4) M8 x 30 screws
- (4) Washers
- (8) Small spacers
- (4) Big spacers
- (6) Anchor bolts
- (6) Concrete anchors
- (6) D6 washers
- Owner's manual



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

OVERVIEW	
UPC Code	037332186676
Device Compatibility	Monitor/HDTV
PHYSICAL	
Color	Black
VESA Pattern (mm)	200x200; 200x300; 200x400; 200x500; 300x200; 300x300; 300x400; 300x500; 300x600; 400x200; 400x300; 400x400; 400x500; 400x600; 500x200; 500x300; 500x400; 500x500; 500x600; 600x300; 600x400; 600x500; 600x600; 700x300; 700x400; 700x500; 700x600; 800x300; 800x400; 800x500; 800x600; 900x400; 900x500; 900x600
Degrees of Motion	Fixed
Material of Construction	Steel
Maximum Screen Size (cm)	254
Maximum Screen Size (in.)	100
Maximum Weight Capacity (kg)	159
Maximum Weight Capacity (lbs.)	350
Min/Max Arm Extension (cm)	N/A
Min/Max Arm Extension (in.)	N/A
Minimum Screen Size (in.)	60
Minimum Screen Size (cm)	152.4
Motion	Fixed
Mounting Location	Wall
Number of Displays	1
Shipping Dimensions (hwd / cm)	4.06 x 43.99 x 126.75
Shipping Dimensions (hwd / in.)	1.60 x 17.32 x 49.90
Shipping Weight (kg)	6.08
Shipping Weight (lbs.)	13.40
Unit Dimensions (hwd / cm)	60.7 x 100.9 x 3.18
Unit Dimensions (hwd / in.)	24 x 39.72 x 1.25
Unit Weight (kg)	4.55
Unit Weight (lbs.)	10.03
FEATURES & SPECIFICATIONS	
Tools Necessary	Yes
SPECIAL FEATURES	
Cord Management	No



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

Security Lock	No
STANDARDS & COMPLIANCE	
Certifications	UL 2442
WARRANTY	
Product Warranty Period (Worldwide)	5-year limited warranty

© 2021 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies:

<https://www.tripplite.com/products/product-certification-agencies>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tripp Lite:](#)

[DWF60100XX](#)