


Portrait/Landscape Rotatable Fixed Flat-Screen Wall Mount for 37" to 70" TVs and Monitors

MODEL NUMBER: **DWM3770PLX**

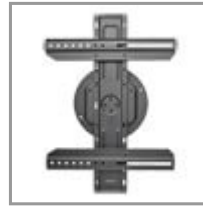

Hangs a flat-panel television, monitor or other display on the wall. Recommended for home theaters, classrooms, boardrooms, hotels, bars and restaurants. Rotates 90° for portrait and landscape viewing angles.

Description

The VESA-compliant DWM3770PLX Portrait/Landscape Rotatable Fixed Flat-Screen Wall Mount allows you to mount your flat-panel television, monitor or other display on the wall. Recommended for home theaters, classrooms, boardrooms, hotels, bars and restaurants, it fits most flat-panel displays from 37 to 70 inches.

The DWM3770PLX effortlessly rotates 90 degrees to position your display in either portrait or landscape mode to fit your environment and comfort level. The durable all-metal frame with scratch-resistant powder-coated finish supports up to 110 lbs (49.9 kgs).

To ease wall installation, the VESA plate attached to the display slides down into the wall-mounted plate. Mounting hardware is included. A built-in bubble level allows accurate wall plate leveling. The DWM3770PLX conforms to VESA-compliant displays with any of the following mounting hole patterns: 200 x 100 mm, 200 x 200 mm, 200 x 300 mm, 200 x 400 mm, 300 x 200 mm, 300 x 300 mm, 300 x 400 mm, 400 x 200 mm, 400 x 300 mm, 400 x 400 mm, 500 x 200 mm, 500 x 300 mm, 500 x 400 mm, 600 x 300 mm and 600 x 400 mm

Features

Mounts Your TV or Monitor to the WallFits most flat-panel televisions, monitors and other displays from 37 to 70 in. Recommended for home theaters, classrooms, boardrooms, hotels, bars and restaurants. Mounting hardware included. Display plate slides down into wall plate for easy wall-mounting.

Allows 90° RotationSpins effortlessly for portrait or landscape viewing.

Durable Metal ConstructionSupports up to 110 lbs (49.9 kgs). Scratch-resistant powder-coated finish blends with any décor. Built-in bubble level allows accurate display leveling.

VESA ComplianceSupports the following VESA mounting hole patterns: 200 x 100 mm, 200 x 200 mm, 200 x 300 mm, 200 x 400 mm, 300 x 200 mm, 300 x 300 mm, 300 x 400 mm, 400 x 200 mm, 400 x 300 mm, 400 x 400 mm, 500 x 200 mm, 500 x 300 mm, 500 x 400 mm, 600 x 300 mm and 600 x 400 mm

Highlights

- Fits most flat-panel displays from 37 to 70 in.
- Rotates smoothly 90° from portrait to landscape and vice versa
- Slide-in VESA plate for easy mounting
- Durable metal construction
- Supports up to 110 lbs (49.9 kgs)

Package Includes

- Wall plate
- Universal plate
- (2) Adapter brackets
- (4) M5 x 14 screws
- (4) M6 x 14 screws
- (4) M6 x 10 screws
- (4) M6 x 30 screws
- (4) M8 x 20 screws
- (4) M8 x 30 screws
- (4) Washers
- (4) D6 washers
- (8) Small spacers
- (4) Big spacers
- (4) Anchor bolts
- (4) Concrete anchors
- Hex key, 4 mm
- Owner's manual

Specifications



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

UPC Code	037332199874
Device Compatibility	Monitor/HDTV
PHYSICAL	
Color	Black
VESA Pattern (mm)	200x100; 200x200; 200x300; 200x400; 300x200; 300x300; 300x400; 400x200; 400x300; 400x400; 500x200; 500x300; 500x400; 600x300; 600x400
Degrees of Motion	90 Rotate
Distance from Wall (in.)	1.81
Distance from Wall (cm)	5
Distance from Wall (mm)	46
Material of Construction	Steel
Maximum Screen Size (cm)	177.8
Maximum Screen Size (in.)	70
Maximum Weight Capacity (kg)	50
Maximum Weight Capacity (lbs.)	110
Minimum Screen Size (in.)	37
Minimum Screen Size (cm)	93.98
Motion	Full
Mounting Location	Wall
Number of Displays	1
Shipping Dimensions (hwd / cm)	5.08 x 63.25 x 27.43
Shipping Dimensions (hwd / in.)	2.00 x 24.90 x 10.80
Shipping Weight (kg)	6.06
Shipping Weight (lbs.)	13.36
Unit Dimensions (hwd / in.)	15.9 x 23.9 x 1.8
Unit Weight (kg)	4.42
Unit Weight (lbs.)	9.75
FEATURES & SPECIFICATIONS	
Tools Necessary	Yes
SPECIAL FEATURES	
Cord Management	No
Security Lock	No
STANDARDS & COMPLIANCE	



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

Approvals	RoHS3, REACH
WARRANTY	
Product Warranty Period (Worldwide)	5-year limited warranty

© 2021 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies:
<https://www.tripplite.com/products/product-certification-agencies>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tripp Lite:](#)

[DWM3770PLX](#)