




Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

USB-A to Lightning Sync/Charge Cable, MFi Certified - White, M/M, USB 2.0, 6 ft. (1.83 m)

MODEL NUMBER: **M100-006-WH**

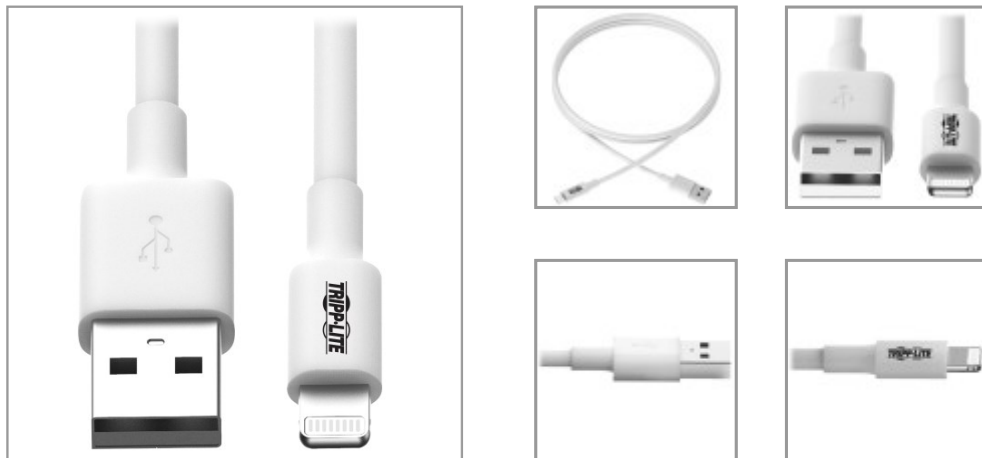

This USB Type-A to Lightning cable connects your iPhone, iPad or iPod device to the USB port on your computer or wall/car charger

Features

Tripp Lite's M100-006-WH 6-ft. (1.83 m) White USB Sync / Charge Cable with Lightning connector allows for uploading and downloading data, while charging the devices at the same time. Cable is MFi-certified for use with the latest generation of iPhone, iPad and iPod devices. Reversible Lightning connector allows plug-ability in either direction to the device.

Highlights

- Features a reversible 8-pin Lightning plug and a USB-A plug
- Works with any computer
- MFi-certified for broad compatibility with your Apple iPhone, iPad or iPod
- Compatible with all devices with 8-pin connectors
- Plugs into Apple device in either direction

Applications

- Charge and sync your Apple iPhone, iPad or iPod using the USB-A port on your computer or a wall charger up to 6-ft. (1.83 m) away
- Transfer photos and other important files between an external hard drive and your Apple device

System Requirements

- Device or charger with USB-A port
- Most current iPhone, iPad and iPod devices

Package Includes

- M100-006-WH USB Sync/Charge Cable with Apple Lightning Connector

Specifications

| OVERVIEW | |
|----------|--------------|
| UPC Code | 037332182180 |



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

| | |
|---------------------------------------|--------------------------------------|
| Technology | Lightning; USB; USB 2.0 (High Speed) |
| PHYSICAL | |
| Color | White |
| Cable Jacket Material | PVC |
| Cable Outer Diameter (OD) | 3.2mm |
| Wire Gauge (AWG) | 28/21 |
| Cable Length (ft.) | 6 |
| Cable Length (m) | 1.8 |
| Cable Length (in.) | 72 |
| Material of Construction | PVC |
| Shipping Dimensions (hwd / cm) | 11.61 x 5.99 x 0.13 |
| Shipping Dimensions (hwd / in.) | 4.57 x 2.36 x 0.05 |
| Shipping Weight (kg) | 0.02 |
| Shipping Weight (lbs.) | 0.05 |
| ENVIRONMENTAL | |
| Operating Temperature Range | -4 to 140 F (-20 to 60 C) |
| Storage Temperature Range | -4 to 176 F (-20 to 80 C) |
| Operating Humidity Range | 0% to 90% RH, Non-Condensing |
| Storage Humidity Range | 0% to 90% RH, Non-Condensing |
| Power Provided to Connected Device(s) | 12W (5V/2.4A) |
| CONNECTIONS | |
| Side A - Connector 1 | USB A (MALE) |
| Side B - Connector 1 | LIGHTNING (MALE) |
| Connector Plating | Nickel |
| Contact Plating | Gold |
| FEATURES & SPECIFICATIONS | |
| USB Specification | USB 2.0 (up to 480 Mbps) |
| STANDARDS & COMPLIANCE | |
| Certifications | RoHS, CA65, REACH, MFi |
| WARRANTY | |
| Product Warranty Period (Worldwide) | 2-year limited warranty |



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

© 2021 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies:
<https://www.tripplite.com/products/product-certification-agencies>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tripp Lite:](#)

[M100-006-WH](#)