




**Tripp Lite**  
1111 W. 35th Street  
Chicago, IL 60609 USA  
Telephone: 773.869.1234  
www.tripplite.com

## USB-A to Lightning Sync/Charge Cable, MFi Certified - White, M/M, USB 2.0, 10 ft. (3.05 m)

MODEL NUMBER: **M100-010-WH**

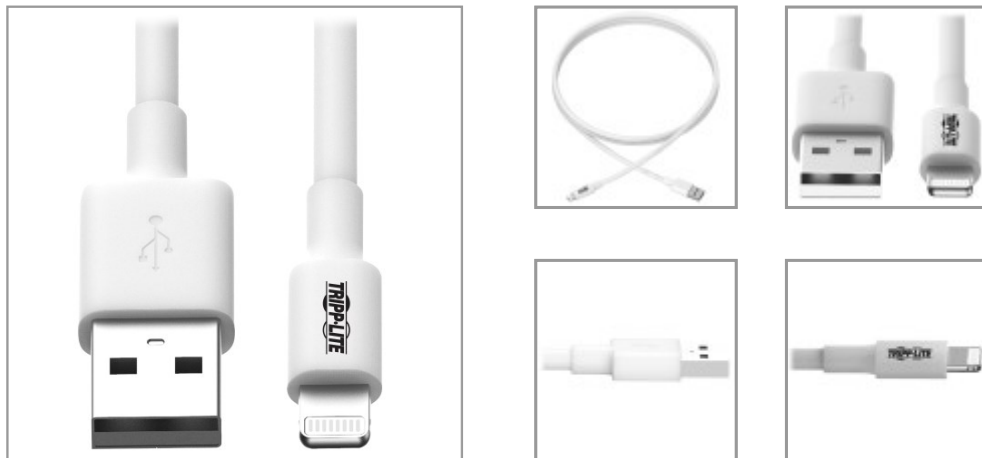

This USB Type-A to Lightning cable connects your iPhone, iPad or iPod device to the USB port on your computer or wall/car charger

### Features

The M100-010-WH USB Sync/Charge Cable connects your latest generation iPhone, iPad or iPod to the USB port on any computer, so you can charge your Apple device and transfer data over long distances. The 10-ft. (3.05 m) cable is MFi-certified for use with the latest generation of iPhone, iPad and iPod devices. Reversible 8-pin Lightning connector plugs into your Apple device in either direction.

### Highlights

- Features a reversible 8-pin Lightning plug and a USB-A plug
- Works with any computer
- MFi-certified for broad compatibility with your Apple iPhone, iPad or iPod
- Compatible with all devices with 8-pin connectors
- Plugs into Apple device in either direction

### Applications

- Charge and sync your Apple iPhone, iPad or iPod using the USB-A port on your computer or a wall charger up to 10-ft. (3.05 m) away
- Transfer photos and other important files between an external hard drive and your Apple device

### System Requirements

- Device or charger with USB-A port
- Most current iPhone, iPad and iPod devices

### Package Includes

- M100-010-WH USB Sync/Charge Cable with Apple Lightning Connector

## Specifications

OVERVIEW	
UPC Code	037332189769



**Tripp Lite**  
1111 W. 35th Street  
Chicago, IL 60609 USA  
Telephone: 773.869.1234  
www.tripplite.com

Technology	Lightning; USB; USB 2.0 (High Speed)
<b>PHYSICAL</b>	
Color	White
Cable Jacket Material	PVC
Cable Outer Diameter (OD)	3.7mm
Wire Gauge (AWG)	25/19
Cable Length (ft.)	10
Cable Length (m)	3
Cable Length (in.)	120
Material of Construction	PVC
Shipping Dimensions (hwd / cm)	14.48 x 3.05 x 7.62
Shipping Dimensions (hwd / in.)	5.70 x 1.20 x 3.00
Shipping Weight (kg)	0.09
Shipping Weight (lbs.)	0.20
<b>ENVIRONMENTAL</b>	
Operating Temperature Range	-4 to 140 F (-20 to 60 C)
Storage Temperature Range	-4 to 176 F (-20 to 80 C)
Operating Humidity Range	0% to 90% RH, Non-Condensing
Storage Humidity Range	0% to 90% RH, Non-Condensing
Power Provided to Connected Device(s)	12W (5V/2.4A)
<b>CONNECTIONS</b>	
Side A - Connector 1	USB A (MALE)
Side B - Connector 1	LIGHTNING (MALE)
Connector Plating	Nickel
Contact Plating	Gold
<b>FEATURES &amp; SPECIFICATIONS</b>	
USB Specification	USB 2.0 (up to 480 Mbps)
<b>STANDARDS &amp; COMPLIANCE</b>	
Certifications	RoHS, CA65, REACH, MFi
<b>WARRANTY</b>	
Product Warranty Period (Worldwide)	2-year limited warranty



**Tripp Lite**  
1111 W. 35th Street  
Chicago, IL 60609 USA  
Telephone: 773.869.1234  
[www.tripplite.com](http://www.tripplite.com)

© 2021 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies:  
<https://www.tripplite.com/products/product-certification-agencies>

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tripp Lite:](#)

[M100-010-WH](#)