


Universal Glass-Top Monitor Riser

MODEL NUMBER: **MR2208G**

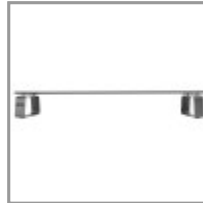

Raises your monitor 3 in. above your desk, table or workspace's surface to help ease eye and neck strain and free up valuable space. Also ideal for laptops, printers, fax machines and small televisions.

Description

The MR2208G Universal Glass-Top Monitor Riser not only frees up valuable space on your desk, table or workstation, it does so with chic, contemporary style and modern smoke glass, that fits perfectly into any home or office décor. By placing your monitor three inches above the surface, the MR2208G also helps ease eye and neck strain. The extra-large 8 x 22-inch tempered glass platform supports up to 40 lbs (18.1 kgs), making it also ideal for laptops, printers, fax machines and small televisions. Brushed aluminum legs with rubber feet secure the riser on smooth surfaces. A keyboard can fit easily beneath the glass platform for convenient storage. The MR2208G assembles in seconds using the included hardware.

Features

Raises a Monitor 3 in. Above Your Desk's Surface Frees up valuable work space Helps ease strain on eyes and neck For home or office Allows room underneath for keyboard storage Also ideal for laptops, printers, fax machines and small televisions

Durable Construction Extra-large 8 x 22 in. tempered smoke glass platform supports up to 40 lb. Brushed aluminum legs with rubber feet secure riser on smooth surfaces Assembles easily in seconds using included hardware Contemporary easy-cleaning design fits any home or office décor

Highlights

- Extra-large 8 x 22 in. tempered smoke colored glass platform
- Brushed aluminum legs with rubber feet
- Allows room underneath for keyboard storage
- Supports up to 40 lbs (18.1 kgs)
- Assembles easily in seconds

Package Includes

- Glass platform
- (2) Legs
- (4) M6 x 6 silver hex key screws
- Hex key, 4 mm
- Installation guide

Specifications

OVERVIEW	
UPC Code	037332197306
Device Compatibility	Monitor/HDTV
PHYSICAL	
Color	Silver
Material of Construction	Glass (Top), Metal (Legs)
Maximum Weight Capacity (kg)	18



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

Maximum Weight Capacity (lbs.)	40
Mounting Location	Desktop
Shipping Dimensions (hwd / cm)	4.83 x 61.72 x 22.10
Shipping Dimensions (hwd / in.)	1.90 x 24.30 x 8.70
Shipping Weight (kg)	2.30
Shipping Weight (lbs.)	5.08
Unit Dimensions (hwd / in.)	3.15 x 22 x 8.27
Unit Weight (kg)	1.77
Unit Weight (lbs.)	3.90
FEATURES & SPECIFICATIONS	
Tools Necessary	No
SPECIAL FEATURES	
Cord Management	No
Security Lock	No
STANDARDS & COMPLIANCE	
Approvals	RoHS3, REACH and CE
WARRANTY	
Product Warranty Period (Worldwide)	5-year limited warranty

© 2021 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies: <https://www.tripplite.com/products/product-certification-agencies>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tripp Lite:](#)

[MR2208G](#)