


## Right-Angle Cat6 Gigabit Molded UTP Ethernet Cable (RJ45 Right-Angle M to RJ45 M), Blue, 3 ft. (0.91 m)

MODEL NUMBER: N204-003-BL-RA

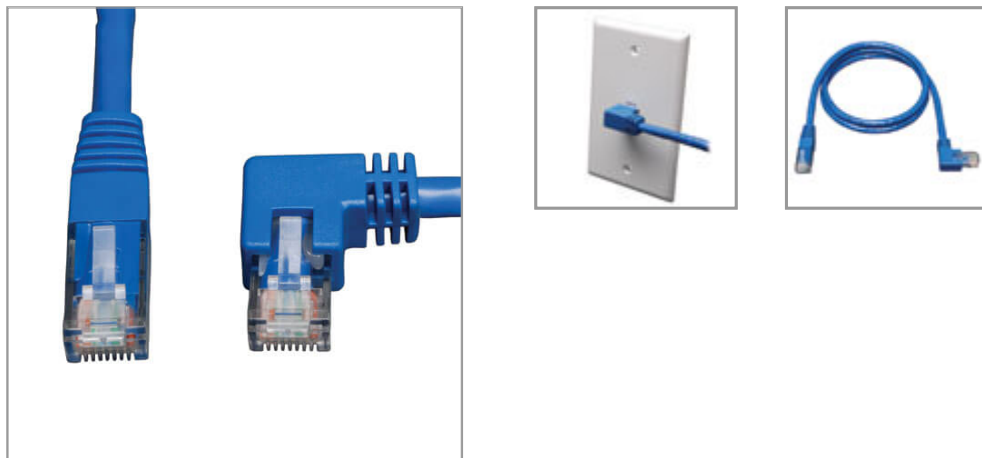

### Highlights

- Space saving design
- Right Angle connector to Straight
- Cat6 Gigabit rated

### System Requirements

- Use with Cat6, Cat5e, Cat5, or VoIP networks

### Package Includes

3-ft. (0.91 m) Blue Cat6 Right Angle to Straight RJ45 - RJ45 Patch cable

### Features

- 3-ft. (0.91 m) Blue Cat6, Right Angle to Straight RJ45 - RJ45 Patch cable
- PVC 4 Pair Stranded Conductors, 24AWG
- Fully Molded Ends
- ETL Verified to TIA/EIA -568-B
- 550Mhz Gigabit Speed Rated

## Specifications

OVERVIEW	
UPC Code	037332167521
Technology	Cat6
PHYSICAL	
Color	Blue
Cable Shielding	UTP
Cable Jacket Material	PVC
Cable Jacket Rating	CM
Number of Conductors	4 Pair
Cable Outer Diameter (OD)	6.0mm



**Tripp Lite**  
1111 W. 35th Street  
Chicago, IL 60609 USA  
Telephone: 773.869.1234  
[www.tripplite.com](http://www.tripplite.com)

Conductor Material	Stranded Copper
Conductor Gauge	24 AWG
Cable Length (ft.)	3
Cable Length (m)	0.9
Cable Length (in.)	36
Cable Length (cm)	91.4
Shipping Dimensions (hwd / cm)	0.64 x 16.51 x 20.32
Shipping Dimensions (hwd / in.)	0.25 x 6.50 x 8.00
Shipping Weight (kg)	0.05
Shipping Weight (lbs.)	0.10
<b>ENVIRONMENTAL</b>	
Operating Temperature Range	14 to 122 F (-10 to 50 C)
Storage Temperature Range	5 to 140 F (-15 to 60 C)
Operating Humidity Range	0% to 90% RH, Non-Condensing
Storage Humidity Range	0% to 90% RH, Non-Condensing
<b>COMMUNICATIONS</b>	
Bandwidth per TIA Standard	250 MHz
Maximum Bandwidth as Tested	500 MHz
Network Speed	1Gbps
IEEE Standards Supported	802.3an
<b>CONNECTIONS</b>	
Side A - Connector 1	RJ45 (MALE)
Side B - Connector 1	RJ45 (MALE) - RIGHT ANGLE
Crossover Wiring	No
Contact Plating	Gold
Connector Type	Molded
Wiring Configuration	EIA/TIA 568B
<b>SPECIAL FEATURES</b>	
IP68 Rated	No
Snagless Connector	No
Antibacterial	No
<b>STANDARDS &amp; COMPLIANCE</b>	



**Tripp Lite**  
1111 W. 35th Street  
Chicago, IL 60609 USA  
Telephone: 773.869.1234  
[www.tripplite.com](http://www.tripplite.com)

Certifications	RoHS, REACH
<b>WARRANTY</b>	
Product Warranty Period (Worldwide)	Lifetime limited warranty

© 2021 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies:

<https://www.tripplite.com/products/product-certification-agencies>

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tripp Lite:](#)

[N204-003-BL-RA](#)