


## Duplex Singlemode 9/125 Fiber Adapter (LC-SC M/F) 1 ft. (0.31 m)

MODEL NUMBER: **N458-001-9**

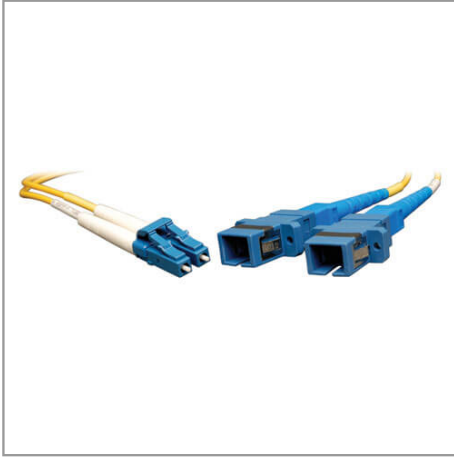

### Highlights

- Utilize Existing SC or ST Cabling with new LC type switches
- Available in 9/125 Singlemode, 62.5/125 or 50/125 Multimode LC/ST or LC/SC

### Package Includes

- LC/SC Duplex Singlemode 9/125 Male-Female Fiber Adapter Cable, 1-ft. (0.31 m)

### Features

- Save money by utilizing older, existing fiber ST or SC cables with new LC installations
- Also Available in LC/ST or LC/SC in both 62.5/125 and 50/125 micron

## Specifications

OVERVIEW	
UPC Code	037332146380
Technology	Singlemode
PHYSICAL	
Color	Yellow
Clad Diameter	125 micron
Core Diameter	8.3 micron
Number of Fibers	2
Cable Length (ft.)	1
Cable Length (m)	0.3
Cable Length (in.)	12
Shipping Dimensions (hwd / cm)	22.86 x 17.78 x 1.27
Shipping Dimensions (hwd / in.)	9.00 x 7.00 x 0.50
Shipping Weight (kg)	0.02



**Tripp Lite**  
1111 W. 35th Street  
Chicago, IL 60609 USA  
Telephone: 773.869.1234  
[www.tripplite.com](http://www.tripplite.com)

Shipping Weight (lbs.)	0.05
<b>CONNECTIONS</b>	
Side A - Connector 1	LC DUPLEX (MALE)
Side B - Connector 1	SC DUPLEX (FEMALE)
<b>SPECIAL FEATURES</b>	
Push/Pull Tabs	No
<b>WARRANTY</b>	
Product Warranty Period (Worldwide)	Lifetime limited warranty

© 2021 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies: <https://www.tripplite.com/products/product-certification-agencies>

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tripp Lite:](#)

[N458-001-9](#)