


OM3 can support 40GBASE-SR4 / 100GBASE-SR10 in applicable parallel optics networks

MTP/MPO Fan-Out Cable, MTP/MPO to 4xLC, 40GbE, 40GBASE-SR4, OM3 Plenum-Rated - Aqua, 2M (6 ft.)

MODEL NUMBER: **N844-02M-8LC-P**

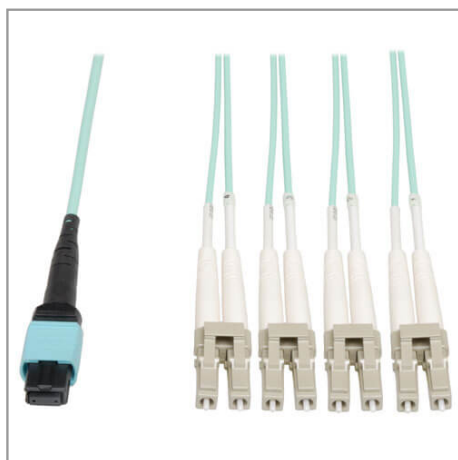

Features

- MTP / MPO to 8 x LC, 2 Meter Fan-out Cable
- 40GbE rated OM3 50/125 Multimode
- Plenum rated jacket

Specifications

OVERVIEW	
UPC Code	037332173768
Technology	Multimode; MTP/MPO
Optical Mode	OM3
PHYSICAL	
Cable Jacket Color	Aqua
Clad Diameter	125 micron
Core Diameter	50 micron
Number of Fibers	12
Cable Length (ft.)	6.6
Cable Length (m)	2

Highlights

- MTP / MPO to 8 x LC Fan-out Cable
- OM3, 40GbE rated, 40GBASE-SR4
- 50/125 Multimode

Package Includes

- 2M (6-ft.) MTP / MPO Fan-out Cable, MTP/MPO to 8 x LC, 40GbE OM3 Plenum



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

Cable Length (in.)	78.7
Shipping Dimensions (hwd / cm)	0.64 x 12.45 x 15.24
Shipping Dimensions (hwd / in.)	0.25 x 4.90 x 6.00
Shipping Weight (kg)	0.05
Shipping Weight (lbs.)	0.10
COMMUNICATIONS	
Network Speed	10Gbps / 40Gbps / 100Gbps
CONNECTIONS	
Side A - Connector 1	12-STRAND MTP (FEMALE)
Side B - Connector 1	(4) LC DUPLEX (MALE)
SPECIAL FEATURES	
Push/Pull Tabs	No
WARRANTY	
Product Warranty Period (Worldwide)	Lifetime limited warranty

© 2021 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies: <https://www.tripplite.com/products/product-certification-agencies>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tripp Lite:](#)

[N844-02M-8LC-P](#)