


OM3 can support 40GBASE-SR4 / 100GBASE-SR10 in applicable parallel optics networks

## MTP/MPO Fan-out Cable with Push/Pull Tab Connectors, MTP/MPO to 4xLC, 40GbE, 40GBASE-SR4, OM3 Plenum-rated - Aqua, 2M (6.56 ft.)

MODEL NUMBER: **N844-02M-8LC-PT**

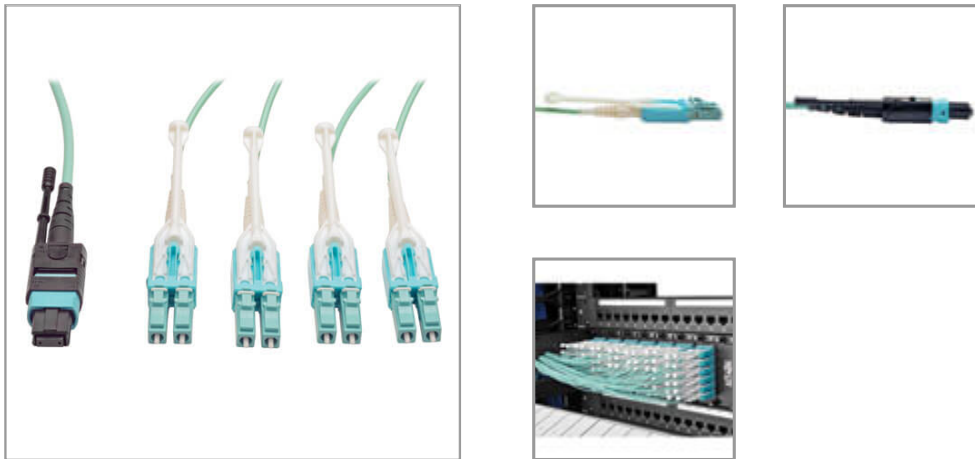

### Features

- MTP / MPO to 8 x LC Fan-out Cable
- Push/Pull tab connectors offer maximum accessibility in high density installations; install / remove with one hand without needing additional tools
- Slim uniboot design saves space and makes cables easier to manage
- Premium-grade ceramic ferrule designed specifically for 10GbE and faster applications
- Sturdy plastic housing for long-lasting durability
- OM3, 40GbE rated, 40GBASE-SR4
- Backward compatible with existing 50/125 fiber
- Plenum rated jacket

### Highlights

- MTP / MPO to 8 x LC Fan-out Cable
- Push/Pull tab connectors offer maximum accessibility in high density installations; install / remove with one hand without needing additional tools
- Slim uniboot design saves space and makes cables easier to manage
- Premium-grade ceramic ferrule designed specifically for 10GbE and faster applications
- Sturdy plastic housing for long-lasting durability
- OM3, 40GbE rated, 40GBASE-SR4
- Backward compatible with existing 50/125 fiber
- Plenum rated jacket

### Package Includes

- 2M (6.56-ft.) MTP / MPO Fan-out Cable, MTP/MPO to 8 x LC, 40GbE OM3 Plenum

## Specifications

OVERVIEW	
UPC Code	037332185266
Technology	Multimode; MTP/MPO
Optical Mode	OM3
PHYSICAL	



**Tripp Lite**  
1111 W. 35th Street  
Chicago, IL 60609 USA  
Telephone: 773.869.1234  
[www.triplite.com](http://www.triplite.com)

Cable Jacket Color	Aqua
Clad Diameter	125 micron
Core Diameter	50 micron
Number of Fibers	12
Cable Length (ft.)	6.6
Cable Length (m)	2
Cable Length (in.)	78.7
Shipping Dimensions (hwd / cm)	22.86 x 17.78 x 1.27
Shipping Dimensions (hwd / in.)	9.00 x 7.00 x 0.50
Shipping Weight (kg)	0.07
Shipping Weight (lbs.)	0.15
<b>COMMUNICATIONS</b>	
Network Speed	10Gbps / 40Gbps / 100Gbps
<b>CONNECTIONS</b>	
Side A - Connector 1	12-STRAND MTP (FEMALE)
Side B - Connector 1	(4) LC DUPLEX (MALE) WITH PULL/PUSH TAB
<b>SPECIAL FEATURES</b>	
Push/Pull Tabs	Yes
<b>WARRANTY</b>	
Product Warranty Period (Worldwide)	Lifetime limited warranty

© 2021 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies: <https://www.triplite.com/products/product-certification-agencies>

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tripp Lite:](#)

[N844-02M-8LC-PT](#)