


4-Outlet Vertical Power Strip, 2-15A & 2-20A, 120V, 15 ft. (4.57 m) Cord, 5-20P, 12 in.

MODEL NUMBER: **PS120420**

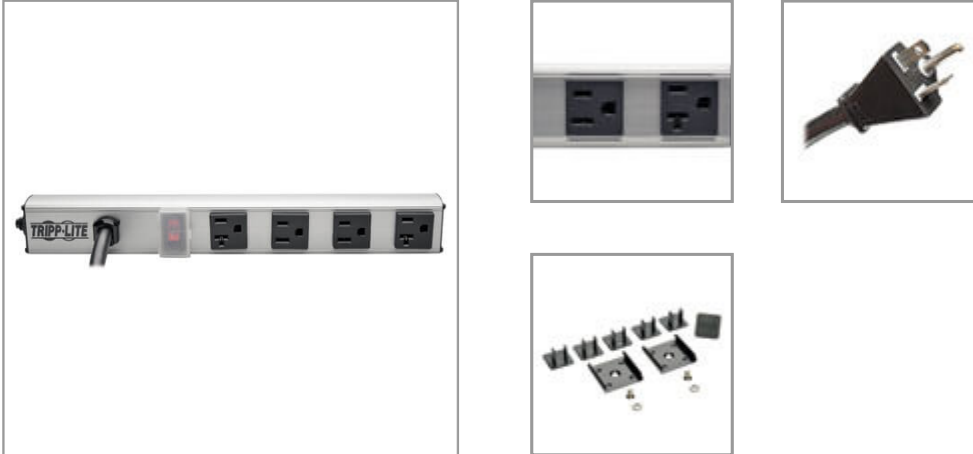

The P120420 power strip provides horizontal or vertical power distribution for rackmount, raceway and workbench applications in a convenient 12-in. mountable housing.

Description

The PS120420 provides a 20-amp, 120v power strip with 2 standard NEMA 5-15 outlets and 2 NEMA 5-20R outlets in a rugged, all-metal, mountable housing. It allows for both vertical and horizontal mounting, making it ideal for a variety of uses including office, rackmount, workbench, industrial and telecom applications. With a NEMA 5-20P, 15-ft. (4.57 m) power cord, you don't have to install the PS120420 next to outlets you already have; it can be mounted across the room and deliver reliable service where you need it most. A lighted and covered On/Off switch helps prevent accidental shut-offs, while a 20-amp circuit breaker guards against dangerous circuit overloads. Its sturdy all-metal extruded aluminum housing stands up to demanding network, laboratory or factory environments.

Features

Multi-Outlet Power Distribution

Vertical or Horizontal Mounting

Extra Long Power Cord

Premium Safety Features

Heavy-Duty Housing

Specifications

Highlights

- Ideal for applications needing multiple convenience outlets for powering a variety of electronic equipment
- 12-in. mountable housing with 2 NEMA 5-15R and 2 NEMA 5-20R outlets and a 15-ft. (4.57 m) power cord
- Lighted, covered On/Off switch and 20-amp circuit breaker
- Sturdy construction and heavy-duty, all-metal housing

Package Includes

- PS120420
- Mounting hardware
- Instruction manual



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

| OVERVIEW | |
|--|---|
| UPC Code | 037332186126 |
| INPUT | |
| Nominal Input Voltage(s) Supported | 120V AC |
| Recommended Electrical Service | 20A 120V |
| Input Cord Gauge Type | 12 gauge; SJT |
| Voltage Compatibility (VAC) | 120 |
| Input Plug Type | NEMA 5-20P |
| Input Cord Length (ft.) | 15 |
| Input Cord Length (m) | 4.57 |
| Integrated Cord Clip | No |
| OUTPUT | |
| Frequency Compatibility | 60 Hz |
| Output (Watts) | 1800 |
| Output Receptacles | (2) 5-15R; (2) 5-20R |
| Circuit Breaker (amps) | 20 |
| Transformer Accommodation | (2) Yes |
| Right-Angle Outlets | No |
| Outlet Spacing | 1.77 in center to center. |
| USER INTERFACE, ALERTS & CONTROLS | |
| Switches | Lighted 2 position switch controls power to all outlets |
| Locking Switch Cover | Transparent on/off switch cover prevents accidental turn-off |
| PHYSICAL | |
| Color | Silver |
| Antimicrobial Coating | No |
| Power Cord Color | Black |
| Form Factors Supported | Supports vertical or horizontal mounting in rack enclosures, raceways and a variety of other applications |
| Housing Color | Silver |
| Included Mounting Accessories | Includes mounting clips |
| Integrated Keyhole Mounting Slots | No |
| Material of Construction | Aluminum |
| Outlets Measurement (Center to Center) | 1.77" |



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

| | |
|-------------------------------------|---------------------------|
| Receptacle Color | Black |
| Shipping Dimensions (hwd / cm) | 9.40 x 15.24 x 39.88 |
| Shipping Dimensions (hwd / in.) | 3.70 x 6.00 x 15.70 |
| Shipping Weight (kg) | 1.63 |
| Shipping Weight (lbs.) | 3.60 |
| Unit Dimensions (hwd / cm) | 4.21 x 6.34 x 15.6 |
| Unit Dimensions (hwd / in.) | 1.25 x 1.62 x 12 |
| Unit Weight (kg) | 1.25 |
| Unit Weight (lbs.) | 2.75 |
| STANDARDS & COMPLIANCE | |
| Canada | cUL |
| UL1363 (Power Tap) | UL1363 |
| WARRANTY | |
| Product Warranty Period (Worldwide) | Lifetime limited warranty |

© 2021 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies:

<https://www.tripplite.com/products/product-certification-agencies>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tripp Lite:](#)

[PS120420](#)