


24-Outlet Vertical Power Strip, 120V, 20A, L5-20P, 15 ft. (4.57 m) Cord, 72 in.

MODEL NUMBER: **PS7224-20T**

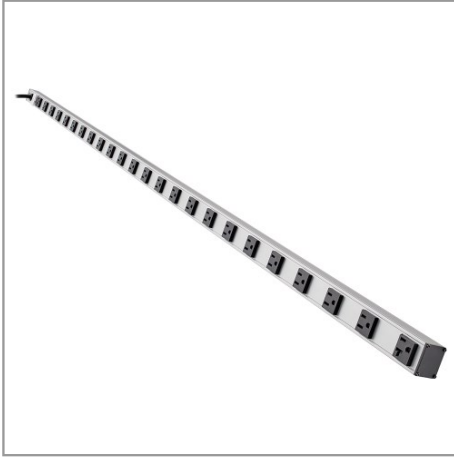

Highlights

- 24 outlets
- Convenient and safe covered, on/off switch
- 20-amp circuit breaker
- 15-ft. (4.57 m) cord with locking L5-20 input plug
- 72" length

Package Includes

- PS7224-20T
- Mounting hardware
- Instruction manual

Description

Tripp Lite's PS7224-20T power strip offers 20 amp, 120V multi-outlet AC power distribution in a convenient 72 inch mountable housing with NEMA L5-20 locking input plug. Offers horizontal or vertical power distribution in rackmount, raceway and workbench applications. Includes 24 output receptacles with 2.795 inch center-to-center spacing, 15-ft. (4.57 m) AC line cord and lighted power switch with locking transparent cover to prevent accidental shutoff. Sturdy all-metal extruded aluminum housing stands up to demanding network, laboratory or factory environments.

INPUT/OUTPUT: Input: NEMA L5-20P (twist lock)/Output: 22 NEMA 5-15R & 2 NEMA 5-20R

ELECTRICAL: 120V AC, 50/60Hz, 20A

FORMAT: 72 in. corded, mountable power strip

Features

- Sturdy all-metal 72 inch corded strip format with 2.795 inch center-to-center outlet spacing
- Included mounting hardware supports vertical or horizontal mounting in rack enclosures, raceways and more
- Includes 22 NEMA 5-15R and 2 NEMA 5-20R output receptacles
- Includes NEMA L5-20 twist-lock input plug connection
- Ideal for horizontal or vertical raceway style power distribution in office, workbench, industrial, networking and telecom applications
- Lighted power switch with locking transparent cover prevents accidental shutoff
- 20 amp electrical capacity with circuit breaker
- 120V AC, 50/60Hz electrical compatibility

Specifications

OVERVIEW



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

UPC Code	037332042378
INPUT	
Nominal Input Voltage(s) Supported	120V AC
Recommended Electrical Service	20A 120V
Input Cord Gauge Type	12 gauge; SJT
Voltage Compatibility (VAC)	120
Input Plug Type	NEMA L5-20P
Input Cord Length (ft.)	15
Input Cord Length (m)	4.57
Integrated Cord Clip	No
OUTPUT	
Frequency Compatibility	50 / 60 Hz
Output (Watts)	2400
Output Receptacles	(2) 5-15/20R; (22) 5-15R
Circuit Breaker (amps)	20
Transformer Accommodation	(12) Yes
Right-Angle Outlets	No
Outlet Spacing	2.795 in.
USER INTERFACE, ALERTS & CONTROLS	
Switches	Lighted 2 position switch controls power to all outlets
Locking Switch Cover	Transparent on/off switch cover prevents accidental turn-off
PHYSICAL	
Color	Silver
Antimicrobial Coating	No
Power Cord Color	Black
Form Factors Supported	Supports vertical or horizontal mounting in rack enclosures, raceways and a variety of other applications
Housing Color	Silver
Included Mounting Accessories	Includes mounting clips
Integrated Keyhole Mounting Slots	No
Material of Construction	Aluminum
Outlets Measurement (Center to Center)	72mm
Receptacle Color	Black



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

Shipping Dimensions (hwd / cm)	8.89 x 6.35 x 193.04
Shipping Dimensions (hwd / in.)	3.50 x 2.50 x 76.00
Shipping Weight (kg)	4.54
Shipping Weight (lbs.)	10.00
Unit Dimensions (hwd / cm)	183 x 3.8 x 3.8
Unit Dimensions (hwd / in.)	72 x 1.5 x 1.5
Unit Weight (kg)	2.99
Unit Weight (lbs.)	6.6
STANDARDS & COMPLIANCE	
Canada	cUL
UL1363 (Power Tap)	UL1363
WARRANTY	
Product Warranty Period (Worldwide)	Lifetime limited warranty

© 2021 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies: <https://www.tripplite.com/products/product-certification-agencies>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tripp Lite:](#)

[PS7224-20T](#)