


Protect It! Surge Protector with 6 Rotatable Outlets, 8 ft. (2.43 m) Cord, 1080 Joules, 2xUSB Charging ports (3.4A)

MODEL NUMBER: TLP608RUSBB

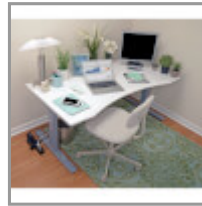

Highlights

- 6 rotatable outlets
- 8-ft. (2.43 m) cord
- 1080 joule rating
- 3.4 amp USB charging
- Diagnostic LED

Package Includes

- TLP608RUSBB surge suppressor
- Owners Manual

Description

The TLP608RUSBB surge suppressor offers reliable surge and line noise protection. Premium features include 6 rotatable outlets, 8-ft. (2.43 m) cord in attractive black housing. The unique rotating design provides convenience and flexibility. Each outlet rotates independently to provide the perfect position to connect your equipment. The TLP608RUSBB also includes 2 USB ports with 3.4 amps of total power that offers fast charging for smartphones, tablets, MP3 players and other portable devices. 1080 joules of surge protection to handle the strongest surge. Diagnostic LED alerts you to potential wiring or protection faults before connected equipment is damaged. \$50,000 Ultimate Lifetime Insurance (U.S., Canada, and Puerto Rico only).

Features

- 6 rotatable outlets
- 8-ft. (2.43 m) cord
- Surge suppression rating: 1080 joules
- 3.4 amp USB Charger
- EMI/RFI noise filtering
- Diagnostic LED indicates Protected (green)
- \$50,000 Ultimate Lifetime Insurance (U.S., Canada, and Puerto Rico only)
- Automatic shutoff permanently cuts power to outlets if protection circuit is incapacitated, preventing equipment damage and indicating replacement is required

Specifications



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

OVERVIEW	
UPC Code	037332184665
Product Type	Surge Protector
Charging Form Factor	Strip
Device Compatibility	Phone; Tablet; Amazon Kindle
INPUT	
Nominal Input Voltage(s) Supported	120V AC
Recommended Electrical Service	120V
Input Cord Length Details	8 ft cord
Voltage Compatibility (VAC)	120
Input Plug Type	NEMA 5-15P
Input Cord Length (ft.)	8
Right-Angle Plug	No
Input Cord Length (m)	2.44
Integrated Cord Clip	No
OUTPUT	
Frequency Compatibility	60 Hz
Output (Watts)	1800
Output Receptacles	(6) 5-15R
Circuit Breaker (amps)	15
Transformer Accommodation	(2) Yes
Right-Angle Outlets	No
USER INTERFACE, ALERTS & CONTROLS	
Diagnostic LED(s)	Yes
SURGE / NOISE SUPPRESSION	
AC Suppression Joule Rating	1080
AC Suppression Response Time	< 1ns
Protection Modes	Includes full normal mode (H-N) and common mode (N-G / H-G) line suppression
Clamping Voltage (RMS)	500
UL1449 Let Through Rating	500, 400, 500
EMI / RFI Filtering	Yes
Immunity	Conforms to IEE 587/ANSI C62.41



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

Automatic Shut-Off	Yes
CHARGING	
Number of Charging Ports	2
Charging Method	USB
Charging Port Type	USB A (FEMALE)
Charging Ports / Amps	(2) 3.4A
DATALINE SURGE SUPPRESSION	
Telephone/DSL Protection	No
Cable (Coax) Protection	No
Network (Ethernet) Protection	No
PHYSICAL	
Antimicrobial Coating	No
Power Cord Color	Black
Housing Color	Black
Integrated Keyhole Mounting Slots	Yes
Material of Construction	Plastic
Receptacle Color	Black
Shipping Dimensions (hwd / cm)	21.08 x 36.32 x 12.70
Shipping Dimensions (hwd / in.)	8.30 x 14.30 x 5.00
Shipping Weight (kg)	0.91
Shipping Weight (lbs.)	2.00
Unit Dimensions (hwd / cm)	32.84 x 5.13 x 5.26
Unit Dimensions (hwd / in.)	12.93 x 2.02 x 2.07
Unit Weight (kg)	0.64
Unit Weight (lbs.)	1.42
SPECIAL FEATURES	
Rotatable Outlets	Yes
STANDARDS & COMPLIANCE	
Approvals	RoHS
UL1449 3rd Edition (AC Suppression)	UL1449 3rd Edition
WARRANTY	



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

Product Warranty Period (Worldwide)	Lifetime limited warranty
Connected Equipment Insurance (U.S., Canada & Puerto Rico)	\$50,000 Ultimate Lifetime Insurance

© 2021 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies: <https://www.tripplite.com/products/product-certification-agencies>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tripp Lite:](#)

[TLP608RUSBB](#)