


WorkWise Standing Desk-Clamp Workstation, Single-Monitor

MODEL NUMBER: **WWSS1327CP**

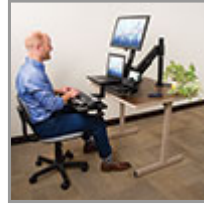

Adapt a traditional desk or table for sit-stand ergonomics without modifying the entire work surface. Clamp this workstation to a flat surface up to 3.35 in. thick and precisely position your monitor and keyboard.

Description

Tripp Lite's WWSS1327CP WorkWise™ Standing Desk-Clamp Workstation allows you to enjoy the benefits of standing for a portion of the day without using your entire work surface. Simply clamp the WWSS1327CP to the edge of a fixed-height desk or table from 1 to 3.35 inches thick. With a single touch, you can change the height of the workstation to improve ergonomics, promote health and increase productivity.

Press the lever to raise or lower the pneumatic arm. All sections move together for smooth transitions between sitting and standing. Increase tension for heavier loads or decrease it for lighter items. The arm adjusts up/down 3 inches, swivels 150° and can rotate 360° to swing the workstation out of the way when not in use (swing range is 49.8 inches from front to back). Built-in cable management reduces cable clutter. Maximum weight capacity is 29 pounds.

Single-arm mount holds up to a 27-inch flat-panel display (VESA 75x75 or 100x100 mounting patterns). Display can be rotated for horizontal or vertical viewing.

Middle platform is 23.6 x 9.9 inches and keeps accessories or a small laptop within reach. At its lowest height, the platform is 1.2 inches above the work surface. It adjusts up to 20.9 inches above the work surface.

Keyboard tray is 23.6 x 10.6 inches to hold the largest, most popular models. At its lowest height, the tray is 2.5 inches below the work surface. It adjusts up to 14.5 inches above the work surface. The wrist rest is removable. Plugs are included to fill exposed mounting holes.

Highlights

- Lever provides smooth one-touch height adjustment
- Swing arm provides left/right swivel adjustment
- Single-arm mount for a 13 to 27 in. flat-panel display
- Max. height of keyboard tray is 14.5 in. above work surface
- Maximum weight capacity is 29 lb.

Package Includes

- Pneumatic arm with lever
- Middle platform
- Keyboard tray with wrist rest
- Mount bracket
- Clamp top and bottom
- Support mast and (2) brackets
- Post
- EVA pad
- Pressure plate
- Cable manager and clip
- Arm swivel washer
- (29) M4, M6 and M8 screws (various lengths)
- (2) M8 nuts
- (4) Spacers
- Socket wrench
- (4) Hole plugs
- (3) Hex keys
- Owner's manual



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

Features

One-Touch Height Adjustment for Sit-Stand Ergonomics

- Lever raises or lowers pneumatic arm for smooth height adjustment
- Lever attaches to left or right side of keyboard tray
- Sections move together for seamless sit-stand transitions
- Use included hex key to increase or decrease tension according to load
- Maximum weight capacity is 29 lb.

Clamp Mount Requires Minimal Desk Space

- Clamps to a flat fixed-height work surface from 1 to 3.35 in. thick
- Provides stability at all workstation heights

Pneumatic Swing Arm

- Adjusts up/down 3 in. on pole
- Offers 150° swivel and 360° rotation
- Swing range is 49.8 in. from back of workstation to end of keyboard
- Integrated cable management reduces cable clutter

Single-Arm Monitor Mount

- Accommodates a 13 to 27 in. flat-panel display
- Compatible with VESA 75x75 and 100x100 mounting hole patterns
- Vertical adjustment and -13° to +45° tilt
- Display can be rotated for horizontal or vertical viewing

Middle Platform

- 23.6 x 9.9 in. platform
- Keeps accessories or a small laptop within reach

Keyboard Tray

- Extra-large 23.6 x 10.6 in. tray holds the largest, most popular models
- Keyboard tray adjusts up to 14.5 in. above the work surface
- Removable wrist rest mounts to the left or right
- Mounting hole plugs included

Specifications

OVERVIEW	
UPC Code	037332197122
PHYSICAL	



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

VESA Pattern (mm)	75x75; 100x100
Color	Black
Degrees of Motion	180 swivel and 360 rotate
Maximum Weight Capacity (kg)	13
Maximum Weight Capacity (lbs.)	29
Shipping Dimensions (hwd / cm)	18.03 x 41.40 x 77.47
Shipping Dimensions (hwd / in.)	7.10 x 16.30 x 30.50
Shipping Weight (kg)	19.37
Shipping Weight (lbs.)	42.70
Unit Dimensions (hwd / in.)	33.7 x 23.6 x 49.5
Unit Weight (kg)	15.97
Unit Weight (lbs.)	35.2
FEATURES & SPECIFICATIONS	
Tools Necessary	Yes
SPECIAL FEATURES	
Cord Management	No
WARRANTY	
Product Warranty Period (Worldwide)	5-year limited warranty

© 2021 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies:

<https://www.tripplite.com/products/product-certification-agencies>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tripp Lite:](#)

[WWSS1327CP](#)