


Locking Cell Phone Charging Station for 32 Devices – USB, with Sync for Smartphones

MODEL NUMBER: CSD32USB

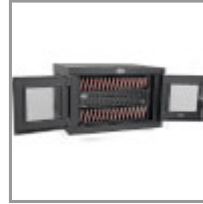

This lockable mobile phone charging station provides fast charging, convenient syncing, secure storage and device organization for up to 32 smartphones or small USB devices.

Features

Fast Charging for Up to 32 Smartphones 32 USB ports deliver the fastest charging supported by each device, up to 2.4A per port, via user-supplied USB cables. The station accommodates up to 32 smartphones with cases up to 7" x 3.65" x 1"; shelf dividers keep the devices organized. The CSD32USB is a compact solution for charging and securing cell phones in corporate, healthcare, industrial, commercial and retail environments.

Convenient Syncing A USB uplink port connects to a host computer for wired syncing to update software, back up data and return devices to standard configurations. The CSD32USB also supports wireless syncing and simultaneous syncing/charging (up to 1.5A per port during wired syncing).

Locking Steel Enclosure Keeps Mobile Devices Safe and Secure This secure phone charging station promotes comprehensive device protection with steel construction and a black powder-coated finish for long-term durability. A 3-point locking mechanism with included keys helps prevent device theft, damage and tampering, and an optional padlock hasp (with a user-supplied padlock) provides added security. Flow-through ventilation helps protect against overheating, and attachment points on the top and bottom of the unit allow mounting of cooling fans (sold separately). Specially coated shelves help prevent device scratches and scuffs.

Firmware Upgrade Ports for Software Upgrades Mini-USB firmware upgrade ports enable future software upgrades to support newer devices.

Easy to Install This lockable phone station ships ready for quick, easy installation. The split front doors open 180 degrees for improved device and service access. Rear-panel slots support wall-mount installation, while the unit is also set up for easy desktop securing. For convenient power connections, you can choose which side to attach the power cord.

Highlights

- Fast 2.4A USB charging for 32 smartphones or other USB devices
- Supports wired and wireless syncing for updating devices
- Secures devices in a locking, vented enclosure that can be mounted on a wall or desktop
- Attachment points included for mounting cooling fans
- Detachable 10-ft. (3.05 m) AC input cord with right-angle NEMA 5-15P plug reaches distant outlets

Applications

- Charge up to 32 smartphones or other USB devices in office, commercial, retail, industrial and healthcare environments
- Sync or back up phones via a wired or wireless connection
- Keep devices safe and secure during charging and storage

Package Includes

- CSD32USB 32-Device USB Charging Station for Smartphones, Black
- Padlock hasp
- Detachable 10-ft. (3.05 m) AC input cord with right-angle NEMA 5-15P plug
- (2) Keys
- Owner's manual

Specifications



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

OVERVIEW	
UPC Code	037332222275
Product Type	Multi-Device Charger
Charging Form Factor	Stationary Cabinet
Functions	Charge; Secure; Sync
Device Compatibility	Phone
Device Slots	32
INPUT	
Nominal Input Voltage(s) Supported	120V AC
Voltage Compatibility (VAC)	110; 120
Input Frequency	50 / 60 Hz (auto-select)
Input Plug Type	NEMA 5-15P
Input Cord Length (ft.)	10
Input Cord Length (m)	3.05
CHARGING	
Number of Charging Ports	32
Charging Method	USB
Charging Port Type	USB A (FEMALE)
Charging Ports Details	Pass through
Charging Ports / Amps	(32) 2.4A
Overcharge Protection	Yes
Charging Amps per Port	2.4A
PHYSICAL	
Color	Black
Antimicrobial Coating	No
Charging Station Form Factor	Stationary Cabinet
Material of Construction	Steel
Shipping Dimensions (hwd / in.)	17.91 x 23.23 x 26.77
Shipping Weight (kg)	30.39
Slot Dimensions - Bottom (hwd / in.)	3.67 x 1.0 x 7.0
Slot Dimensions - Bottom (hwd / mm)	9.32 x 2.54 x 17.78
Slot Dimensions - Top (hwd / in.)	3.67 x 1.0 x 7.0



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

Slot Dimensions - Top (hwd / mm)	9.32 x 2.54 x 17.78
Unit Dimensions (hwd / cm)	37.87 x 60.45 x 48.16
Unit Dimensions (hwd / in.)	14.910 x 23.800 x 18.960
Unit Weight (kg)	28.17
Unit Weight (lbs.)	62.11
Number of Shelves	2
ENVIRONMENTAL	
Power Consumption (Watts)	112
SPECIAL FEATURES	
Cord Management	Yes
EMI/RFI Line Noise Protection	Yes
Locking	Yes
Lock Type	Key
Built-In Circuit Breaker	Yes
Overcurrent Protection	Yes
Flow-Through Ventilation	Yes
UV Sterilization	No
STANDARDS & COMPLIANCE	
Certifications	FCC & IEC Class B, UL 60950 (Power Component); CAN/CSA-C22.2 No. 60950-1:07
Approvals	RoHS
NOM (Mexico)	Tested to NOM (Mexico)
WARRANTY	
Product Warranty Period (Worldwide)	2-year limited warranty
CATEGORY PAGE FILTERS (Y/N ONLY)	
External Receptacle	No

© 2021 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies:

<https://www.tripplite.com/products/product-certification-agencies>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tripp Lite:](#)

[CSD32USB](#)