


## Universal Thin Client Monitor Mount

MODEL NUMBER: **DMATC**

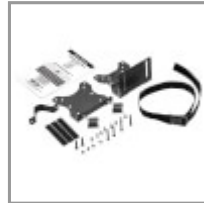

Thin client mounting bracket secures your small desktop terminal to your monitor, freeing up desk, table and floor space.

### Features

**Ideal for Use at Home, School and the Office** This thin client mount securely attaches to the back of your monitor, hiding your thin client out of the way and saving valuable desk, table and floor space. The adjustable frame fits most thin clients ranging from 0.76 to 2.8 inches wide and supports up to 11 lbs (4.9 kgs).

**Convenient Open Frame Design Allows Easy Access** The open frame allows you access to your thin client and its cabling for easy adjustments. Made from durable steel, the thin client mounting bracket features a scratch-resistant black powder-coated finish that blends with your décor and stands up to frequent handling.

**Versatile Mounting Options Give You More Choices** In addition to easy mounting to your monitor's 75 x 75 mm or 100 x 100 mm VESA plate, the thin client mount also attaches directly to a display mount pole, under a desk or on a wall. Mounting hardware and hook-and-loop straps for extra stability are included.

**5-Year Warranty and Environmentally Responsible Design** The DMATC comes with a 5-year warranty. It's manufactured in compliance with strict RoHS specifications, reflecting Tripp Lite's commitment to environmental responsibility.

### Highlights

- Mounts to back of your monitor to leave valuable desk, table and floor space clear
- Adjusts to fit wide range of thin clients from 0.76 to 2.8 in. and up to 11 lbs (4.9 kgs)
- Scratch-resistant powder-coated finish blends into your workspace décor
- Included hardware for pole, desk, wall or VESA mounting gives you installment choices
- Open frame design allows easy access to thin client and cabling for quick adjustments

### Applications

- Incorporate a thin client into your workspace without taking up valuable desk, table or floor space

### Package Includes

- Thin client bracket
- Safety strap
- Support bracket
- (3) Rubber strips
- (4) ST4.8 x 16 screws
- (2) M5 x 25 screws
- (8) M4 x 12 screws
- (4) D4 washers
- (4) M4 nuts
- Owner's manual

## Specifications

### OVERVIEW



**Tripp Lite**  
1111 W. 35th Street  
Chicago, IL 60609 USA  
Telephone: 773.869.1234  
[www.tripplite.com](http://www.tripplite.com)

UPC Code	037332212771
Device Compatibility	Monitor/HDTV
<b>PHYSICAL</b>	
Color	Black
VESA Pattern (mm)	75x75; 100x100
Degrees of Motion	Fixed
Material of Construction	Steel
Maximum Weight Capacity (kg)	5
Maximum Weight Capacity (lbs.)	11
Motion	Fixed
Mounting Location	Wall
Unit Dimensions (hwd / cm)	11.7 x 12.9 x 7.1
Unit Dimensions (hwd / in.)	4.6 x 5.1 x 2.8
Unit Weight (kg)	0.68
Unit Weight (lbs.)	1.5
<b>FEATURES &amp; SPECIFICATIONS</b>	
Tools Necessary	Yes
<b>SPECIAL FEATURES</b>	
Cord Management	No
<b>STANDARDS &amp; COMPLIANCE</b>	
Approvals	RoHS3, REACH and CE
<b>WARRANTY</b>	
Product Warranty Period (Worldwide)	5-year limited warranty

© 2021 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies: <https://www.tripplite.com/products/product-certification-agencies>

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tripp Lite:](#)

[DMATC](#)