


## Center Plate Insert, Decora Style - Vertical, 6 Ports

MODEL NUMBER: **N042D-006V-WH**

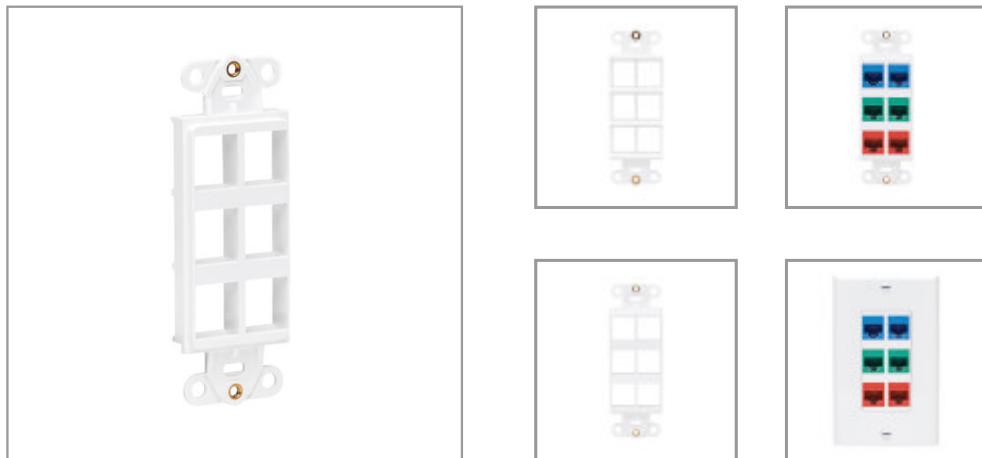

Clean, simple insert mounts within Decora-style wall plate for terminating in-wall audio/video, voice or Ethernet cable installations.

### Features

**Decora-Style Face Plate Connects Audio/Video, Voice and Data Cable Lines at the Wall** This vertical-style center insert provides a clean, simple method for your premise wiring applications, including home theater (audio/video), VoIP phones (voice) and Ethernet (data). Any type of keystone jack, including those used in HDMI, DisplayPort, RCA, USB and Cat5e/6/6a installations, snaps easily into the cutouts for quick cable connection.

**High-Impact Construction Designed to Blend In Seamlessly** The Decora-style polycarbonate insert plate is white and blends elegantly into any home or office décor for a sleek, professional installation. Mounting screws are included for flush mounting the insert with a Tripp Lite or other compatible Decora-style wall plate (sold separately).

### Highlights

- Ideal for home theater, VoIP or Ethernet premise wiring installations
- Compatible with any type of keystone jack, including HDMI, Cat5/6, USB and DisplayPort
- High-impact polycarbonate construction designed to last long in your décor
- Hardware included for mounting flush with compatible Decora-style wall plate

### Applications

- Complete your premise wiring application with a clean, sleek-looking Decora-style appearance

### Package Includes

- N042D-006V-WH Center Plate Insert, Decora Style - Vertical, 6 Ports
- (2) Mounting screws

## Specifications

OVERVIEW	
UPC Code	037332249739
Technology	Cat5/5e; Cat6; Cat6a; DisplayPort; HDBaseT; HDMI; USB; USB 2.0 (High Speed); USB 3.0 (SuperSpeed)
PHYSICAL	
Color	White
Material of Construction	ABS
ENVIRONMENTAL	
Operating Temperature Range	14 TO 140 F (-10 to 60 C)



**Tripp Lite**  
1111 W. 35th Street  
Chicago, IL 60609 USA  
Telephone: 773.869.1234  
[www.tripplite.com](http://www.tripplite.com)

Storage Temperature Range	-40 TO 154.4 F (-40 to 68 C)
Relative Humidity	10% TO 90% (NON-CONDENSING)
<b>CONNECTIONS</b>	
Side A - Connector 1	KEYSTONE JACK CUTOUT
Side B - Connector 1	KEYSTONE JACK CUTOUT
<b>STANDARDS &amp; COMPLIANCE</b>	
Certifications	Tested to RoHS, REACH
<b>WARRANTY</b>	
Product Warranty Period (Worldwide)	Lifetime limited warranty

© 2021 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies:

<https://www.tripplite.com/products/product-certification-agencies>

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tripp Lite:](#)

[N042D-006V-WH](#)