


Double-Gang Surface-Mount Back Box, White, TAA

MODEL NUMBER: **N080-SMB2-WH**

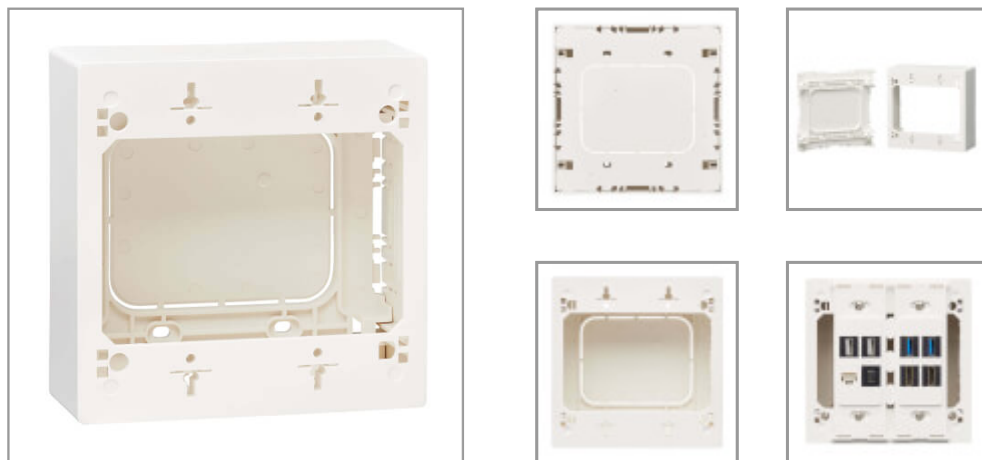

Deep double-gang junction box mounts a wall plate to complete multiple audio/video, voice and/or Ethernet in-wall connections.

Features

Double-Gang Surface-Mount Junction Box for Premise Applications The Tripp Lite N080-SMB2-WH is ideal for mounting a double-gang wall plate to complete multiple audio/video, voice and Ethernet in-wall connections using any type of keystone jack, including Cat5e/6/6a, USB, HDMI, DisplayPort and RCA.

Designed to work with mid-sized and standard double-gang wall plates, this back box is two inches deep.

Raceway Cutouts on Each Side for Easy Access The N080-SMB2-WH features raceway cutouts in three different sizes (1 inch, 1.25 inches and 1.75 inches in diameter) on each side, as well as a rectangular knockout on the back. The cover snaps securely to the base with no screws required.

Highly Adaptable to Match Your Specific Requirements Made from robust ABS thermoplastic, the N080-SMB2-WH is colored white to blend elegantly into any home or office decor for a sleek, professional installation. Four mounting screws are included.

TAA-Compliant for GSA Schedule Purchases The N080-SMB2-WH is compliant with the Federal Trade Agreements Act (TAA), which makes it eligible for GSA (General Services Administration) Schedule and other federal procurement contracts.

Highlights

- Mid-sized back box accommodates any mid-sized or standard double-gang wall plate
- High-impact ABS thermoplastic construction designed to last a long time
- Classic white color blends elegantly into your home or office décor
- Raceway cutouts in 3 different sizes at each panel allow bulk cabling
- Compliant with the Federal Trade Agreements Act (TAA) for GSA Schedule purchases

Applications

- Complete multiple in-wall audio/video, voice and/or Ethernet cable lines simultaneously

Package Includes

- N080-SMB2-WH Double-Gang Surface-Mount Junction Box
- (4) #6-20 wood screws
- (4) 2-sided adhesive strips

Specifications

OVERVIEW	
UPC Code	037332236272
Technology	Cat5/5e; Cat6; Cat6a; USB 2.0 (High Speed); USB 3.0 (SuperSpeed); HDBaseT; HDMI; USB; DisplayPort
PHYSICAL	
Color	White
Shipping Dimensions (hwd / cm)	30.48 x 25.40 x 1.27



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

Shipping Dimensions (hwd / in.)	12.00 x 10.00 x 0.50
Shipping Weight (kg)	0.18
Shipping Weight (lbs.)	0.39
Unit Dimensions (hwd / cm)	128 x 8 x 5
Unit Dimensions (hwd / in.)	5.10 x 3.30 x 2.10
Unit Weight (kg)	0.12
Unit Weight (lbs.)	0.27
ENVIRONMENTAL	
Operating Temperature Range	14 ~ 140F (-10 ~ 60C)
Storage Temperature Range	-40 ~ 154F (-40 ~ 68C)
Relative Humidity	10% ~ 90% RH
CONNECTIONS	
Side A - Connector 1	KEYSTONE JACK CUTOUT
Side B - Connector 1	KEYSTONE JACK CUTOUT
WARRANTY	
Product Warranty Period (Worldwide)	Lifetime limited warranty

© 2021 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies: <https://www.tripplite.com/products/product-certification-agencies>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tripp Lite:](#)

[N080-SMB2-WH](#)