


DisplayPort KVM Cable Kit, 3 in 1 - 4K DisplayPort, USB, 3.5 mm Audio (3xM/3xM), 4:4:4, 10 ft. (3.05 m), Black

MODEL NUMBER: P783-010

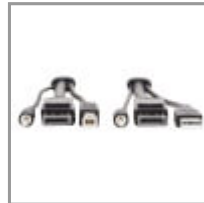

3-in-1 KVM cable kit with DisplayPort, USB A/B and 3.5 mm plugs connects your computer to a B002-DP1A4 or other compatible NIAP KVM.

Features

10-ft. (3.05 m) 3-in-1 Cable Connects Your DisplayPort Computer to a Tripp Lite NIAP KVM Switch This cable features DisplayPort, USB A/B and 3.5 mm audio connectors on both ends for connecting your computer to a KVM switch. Designed specifically for the Tripp Lite B002-DP1A4 NIAP KVM, the 10-ft. (3.05 m) cable supports DisplayPort video resolutions up to 3840 x 2160 (4K x 2K) at 60 Hz with true 4:4:4 chroma subsampling. It's compatible with HDCP 2.2, DisplayPort 1.2 and USB 2.0 (480 Mbps) standards. By combining three different cables into one convenient cord, you cut down on unnecessary clutter and save money.

Highlights

- Cuts cable clutter and saves money by combining 3 essential KVM cables into one
- Delivers UHD picture quality at resolutions up to 3840 x 2160 (4K x 2K) @ 60 Hz
- Supports true 4:4:4 chroma subsampling to meet latest color standards
- Transfers data at reliable USB 2.0 speeds up to 480 Mbps
- Plug-and-play operation with no software required for easy, immediate installation

Applications

- Connect a headless computer to a Tripp Lite KVM switch
- Upgrade or replace worn or lost KVM cables
- Eliminate clutter by replacing multiple cables with one new one
- Extend the distance between the KVM switch and computer to 10 ft.

System Requirements

- Tripp Lite B002-DP1A4 or other compatible NIAP KVM

Package Includes

- P783-010 DisplayPort KVM cable kit, 3 in 1 (M/M), 10 ft.

Specifications



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

UPC Code	037332241603
Technology	DisplayPort; USB
VIDEO	
Max Supported Video Resolution	3840 x 2160P @ 60 Hz (4K x 2K)
PHYSICAL	
Color	Black
Cable Length (ft.)	10
Cable Length (m)	3
Cable Length (in.)	120
Shipping Dimensions (hwd / cm)	25.40 x 20.32 x 1.27
Shipping Dimensions (hwd / in.)	10.00 x 8.00 x 0.50
Shipping Weight (kg)	0.34
Shipping Weight (lbs.)	0.74
ENVIRONMENTAL	
Operating Temperature Range	14 ~ 122F (-10 ~ 50C)
Storage Temperature Range	5 ~ 140F (-15 ~ 60C)
Relative Humidity	0 ~ 90% RH, Non-Condensing
CONNECTIONS	
Side A - Connector 1	3.5MM (MALE); DISPLAYPORT (MALE); USB A (MALE)
Side B - Connector 1	3.5MM (MALE); DISPLAYPORT (MALE); USB B (MALE)
Contact Plating	Gold
FEATURES & SPECIFICATIONS	
Displayport Specification	1.2
HDCP Specification	2.2
USB Specification	USB 2.0 (up to 480 Mbps)
WARRANTY	
Product Warranty Period (Worldwide)	Lifetime limited warranty

© 2021 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies: <https://www.tripplite.com/products/product-certification-agencies>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tripp Lite:](#)

[P783-010](#)