
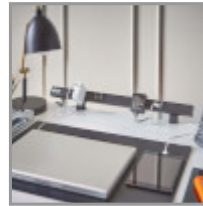


4-Outlet Power Strip with USB-A Charging (6.2A) - NEMA 5-15R, 120V, 15A, 10 ft. (3.05 m) Cord, 5-15P, 24 in.

MODEL NUMBER: **PSC240410USBB**

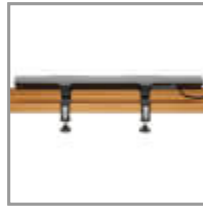

Four-outlet power strip with USB-A charging ports distributes power and charges mobile devices. Includes optional mounting clamps.

Features

24 in. Power Strip Provides 4 AC Outlets and 4 USB-A Charging Ports Compatible with standard electrical equipment, this UL-listed power strip has a 24-inch aluminum housing with a durable black finish. There are a total of four NEMA 5-15R outlets and four USB-A charging ports; each one-foot section has two outlets and two charging ports. The outlets are placed at a right angle to prevent connected power cords from blocking access to the adjacent outlet. In the event of an overload, a 15-amp resettable circuit breaker immediately shuts down the power strip to prevent equipment damage.

Charge Up to 4 Mobile Devices with 6.2A of Shared Power In addition to AC outlets, this power strip provides USB charging for up to four mobile devices, including tablets, e-readers and smartphones. Each pair of USB-A charging ports provides up to 3.1 amps of shared power. The USB ports eliminate the need for AC adapters for charging cords, leaving outlets available for AC equipment.

Place Outlets and Charging Ports Away from the Power Source The PSC240410USBB has a 10-ft. (3.05 m) cord, so you can mount it away from its AC wall outlet or other power source. The cord has a NEMA 5-15P plug.

Use Optional Mounting Clamps to Add Flexibility to Horizontal Installations If drilling mounting holes is not possible or desirable, use the included heavy-duty C-clamps to mount the power strip. The clamps attach to the edge of a desk, table, workbench or other solid, flat surface up to 2.25 inches thick. Slide the clamps onto the edge of your surface, hand tighten the adjustment knobs and snap the power strip into the built-in mounting clips. No drilling is required. It is easy to relocate the installation because there are no fasteners to remove. The PSC240410USBB also comes with clips for vertical or horizontal surface-mounting to a wall or workbench.

Highlights

- 4 right-angle 5-15R outlets distribute power to home and office electronics
- 4 USB-A charging ports power mobile devices; 6.2 amps of shared power
- 10-ft. (3.05 m) cord with 5-15P plug offers flexible placement in relation to an AC wall outlet
- 24 in. metal housing withstands the rigors of daily use
- Included clamps mount to a desk, table or workbench; no drilling required

Applications

- Distribute power to computer equipment and other devices in an office, workbench, industrial, retail or telecom environment
- Clamp mount a power strip to the edge of a desk or workbench for easy access to outlets and USB charging ports
- Provide outlets and USB charging ports at a trade show booth without permanently mounting the power strip

Package Includes

- PSC240410USBB 4-Outlet Power Strip with USB-A Charging
- (2) Mounting clamps with clips
- (2) Mounting clips for surface-mounting
- Owner's manual



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

Specifications

OVERVIEW	
UPC Code	037332238825
Product Type	Power Strip
Charging Form Factor	Strip
Device Compatibility	Phone; Tablet; Amazon Kindle
INPUT	
Nominal Input Voltage(s) Supported	120V AC
Recommended Electrical Service	15A 120V
Input Cord Gauge Type	14 gauge; SJT
Voltage Compatibility (VAC)	120
Input Plug Type	NEMA 5-15P
Input Cord Length (ft.)	10
Input Cord Length (m)	3.05
Integrated Cord Clip	No
OUTPUT	
Frequency Compatibility	50 / 60 Hz
Output (Watts)	1800
Output Receptacles	(4) 5-15R
Circuit Breaker (amps)	15
Transformer Accommodation	(4) Yes
Right-Angle Outlets	Yes
CHARGING	
Charging Ports / Amps	(1) 6.2A
Number of Charging Ports	1
Charging Method	USB
Charging Port Type	USB A (FEMALE)
PHYSICAL	
Color	Black
Antimicrobial Coating	No
Color (AC Line Cord)	Black
Form Factors Supported	Supports vertical or horizontal mounting in rack enclosures, raceways and a variety of other applications



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

Included Mounting Accessories	Desk/table mounting clamps
Integrated Keyhole Mounting Slots	No
Material of Construction	Aluminum
Outlets Measurement (Center to Center)	1.42 in.
Receptacle Color	Black
Shipping Dimensions (hwd / cm)	6.10 x 13.72 x 70.10
Shipping Dimensions (hwd / in.)	2.40 x 5.40 x 27.60
Shipping Weight (kg)	1.54
Shipping Weight (lbs.)	3.40
Unit Dimensions (hwd / cm)	60.69 x 3.18 x 4.09
Unit Dimensions (hwd / in.)	24 x 1.25 x 1.6
Unit Weight (kg)	1.04
Unit Weight (lbs.)	2.29
STANDARDS & COMPLIANCE	
Canada	cUL
UL1363 (Power Tap)	UL1363
WARRANTY	
Product Warranty Period (Worldwide)	Lifetime limited warranty

© 2021 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice.

Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies:

<https://www.tripplite.com/products/product-certification-agencies>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tripp Lite:](#)

[PSC240410USBB](#)