



SURGE PROTECTOR & POWER STRIP MODELS AND SPECIFICATIONS

Updated August 2017

Isobar® Premium Surge Protectors



A



B



C



D

							Data Line Protection						
Model	Outlet Qty. (NEMA/IEC Type)	Cord Length	Plug Style	Joules ⁽¹⁾	Total Transformer Capacity ⁽²⁾	Isolated Filter Banks Qty.	Tel/ Modem (RJ11)	Coaxial (Type F)	Ethernet (RJ45)	Diagnostic LEDs ⁽³⁾	Ultimate Lifetime Insurance ⁽⁴⁾	Retail Packaging	Housing Style ⁽⁵⁾
Isobar Audio/Video Surge Protectors—Metal Housing													
HT10DBS	10 (5-15R) ⁽⁶⁾	8 ft.	Right Angle	3840	6	2	1 line	3 line	1 line	3	\$500,000	Yes	A
ISOBAR6DBS	6 (5-15R)	6 ft.	Right Angle	2850	3	3	1 line	2 line	—	3	\$250,000	Yes	A
Isobar Surge Protectors—Metal Housing													
ISOBAR825ULTRA	8 (5-15R)	25 ft.	Right Angle	3840	4	4	—	—	—	3	\$50,000	Yes	B
ISOTEL8ULTRA	8 (5-15R)	12 ft.	Right Angle	3840	4	4	1 line	—	—	3	\$50,000	Yes	B
ISOBAR8ULTRA	8 (5-15R)	12 ft.	Right Angle	3840	4	4	—	—	—	3	\$50,000	Yes	B
IB8RM⁽⁷⁾	8 (5-15R)	12 ft.	Right Angle	3840	4	4	—	—	—	—	\$50,000	Yes	B
ISOTEL6ULTRA	6 (5-15R)	6 ft.	Right Angle	3330	4	3	2 line	—	—	3	\$50,000	Yes	B
ISOBAR6ULTRA	6 (5-15R)	6 ft.	Right Angle	3330	4	3	—	—	—	3	\$50,000	Yes	B
ISOBAR6	6 (5-15R)	6 ft.	Right Angle	3330	4	3	—	—	—	3	\$50,000	Yes	B
ISOTEL4ULTRA	4 (5-15R)	6 ft.	Right Angle	3330	2	2	1 line	—	—	3	\$50,000	Yes	B
ISOBAR4ULTRA	4 (5-15R)	6 ft.	Right Angle	3330	2	2	—	—	—	3	\$50,000	Yes	B
IBAR4	4 (5-15R)	6 ft.	Right Angle	3330	2	2	—	—	—	—	\$50,000	Yes	B
ISOBAR2-6	2 (5-15R)	6 ft.	Right Angle	1410	1	1	—	—	—	—	\$25,000	Yes	B
Isobar Under-Monitor Surge Protector with 2 USB Charging Ports (2.1A total)—Metal Housing													
MT-6PLUS	6 (5-15R)	8 ft.	Straight	3150	3	1	1 line	—	—	8	\$100,000	Yes	C
Isobar Direct Plug-In Surge Protectors—Metal Housing													
ULTRAFAX	2 (5-15R)	Direct Plug-In		1410	1	1	1 line	—	—	3	\$10,000	Yes	D
ULTRABLOK	2 (5-15R)	Direct Plug-In		1410	1	1	—	—	—	3	\$10,000	Yes	D
ISOBLOK2-0	2 (5-15R)	Direct Plug-In		1410	1	1	—	—	—	3	\$10,000	Yes	D
Isobar Hospital-Grade Surge Protector—Metal Housing													
ISOBAR6ULTRAHG	6 (5-15R HG)	15 ft.	Straight 5-15P HG	3330	3	1	—	—	—	3	—	Yes	B
Isobar 230V Surge Protectors—Metal Housing													
ISOBAR4/220	4 (5-15R)	6 ft.	Right Angle	330	2	2	—	—	—	—	—	Yes	B
EURO-4	4 (C13)	6 ft.	C14 inlet ⁽⁸⁾	680	2	2	—	—	—	—	—	Yes	B

All models are certified to meet UL 1449 (3rd Edition) standards; additional certifications vary by model. All models are rated for 120V AC (50/60 Hz) operation, except ISOBAR4/220 and EURO-4, which are rated for 230V AC (50/60 Hz) operation. Plugs are NEMA 5-15P, unless otherwise indicated. All models have a circuit breaker (either separate or integrated into the on/off switch). Models have an illuminated on/off switch, except MT-6PLUS has a power button and LED. ISOBAR6ULTRAHG has a switch with a snap-tight cover that reduces the risk of accidental shutoff. Most models have keyhole mounting slots. (1) The joule rating indicates how much surge energy the surge protector can absorb in a single event. A higher rating means more protection. (2) Transformer capacity varies with transformer size. (3) 8 LED models = 4 switch LEDs, "Low Voltage" (wall outlet is providing lower than nominal voltage), "Line OK" (wall outlet is properly wired), "Protected" and "Fault" (fault in wall outlet). 3 LED models = "Line OK," "Protected" and "Fault." (4) Ultimate Lifetime Insurance is valid in the U.S., Puerto Rico and Canada only. (5) Photos represent housing style only. Refer to the specification chart or visit [tripplite.com](http://www.tripplite.com) for exact model features. (6) HT10DBS has color-coordinated outlet/plug labels to coordinate outlets with equipment cords. (7) IB8RM has a switch on a 9 ft. cord for remote outlet control. (8) EURO-4 has a detachable C13-to-C14 cable.



FIND IT FAST! Try our interactive surge protector selector guide at www.tripplite.com/SPselector

Isobar® Premium Surge Protectors	1
Protect It!® Surge Protectors	2-5
Rack-Mount Surge Protectors	6

Specialty Surge Protectors (Safety, Eco, Network)	6
Power It!™ Power Strips	7-8
Safety Series Power Strips	8

Surge Protectors




For housing styles D – R, see pages 3 – 5.

						Data Line Protection								
UL Model	Outlet Qty.	Cord Length	Plug Style	Joules ⁽¹⁾	Total Transformer Capacity ⁽²⁾	Tel/Modem (RJ11)	Coaxial (Type F)	Tel/Ethernet (RJ45)	Diagnostic LEDs ⁽³⁾	Outlet Safety Covers	Housing Color	Ultimate Lifetime Insurance ⁽⁴⁾	Retail Packaging	Housing Style ⁽⁵⁾
Protect It! Surge Protectors—Plastic Housing														
HT1210SAT3	12	10 ft.	Right Angle	2880	8	—	3 in/3 out	1 in/2 out ⁽⁶⁾	PR, GR	Built-In	Black	\$250,000	Yes	A
TLP1208SAT	12	8 ft.	Right Angle	2880	8	—	1 in/1 out	1 in/2 out ⁽⁶⁾	PR, GR	Built-In	Black	\$250,000	Yes	A
TLP1208TELV	12	8 ft.	Right Angle	2880	8	1 in/2 out	1 in/1 out	—	PR, GR	Built-In	Black	\$150,000	Yes	A
TLP1208TEL	12	8 ft.	Right Angle	2160	8	1 in/2 out	—	—	PR, GR	Built-In	Black	\$150,000	Yes	A
TLP1008TELV	10	8 ft.	Right Angle	3345	8	1 in/2 out	1 in/1 out	—	PR, GR	Built-In	Black	\$150,000	Yes	A
TLP1008TEL	10	8 ft.	Right Angle	2395	8	1 in/2 out	—	—	PR, GR	Built-In	Black	\$150,000	Yes	A
TLP1006B	10	6 ft.	Right Angle	2880	10	—	—	—	PR, GR	Built-In	Black	\$100,000	Yes	B
TLP810NET	8	10 ft.	Right Angle	3240	6	1 in/1 out	1 in/1 out	1 in/1 out	PR ⁽⁷⁾ , GR	Built-In	Black	\$250,000	Yes	A
TLP810SAT	8	10 ft.	Right Angle	3240	6	1 in/1 out	2 in/2 out	—	PR ⁽⁷⁾ , GR	Built-In	Black	\$250,000	Yes	A
TLP808TELV	8	8 ft.	Right Angle	2160	6	1 in/2 out	1 in/1 out	—	PR ⁽⁷⁾ , GR	Built-In	Black	\$150,000	Yes	A
TLP808TEL	8	8 ft.	Right Angle	2160	6	1 in/2 out	—	—	PR, GR	Built-In	Light Gray	\$150,000	Yes	A
TLP825	8	25 ft.	Right Angle	1440	6	—	—	—	PR, GR	Built-In	Light Gray	\$75,000	Yes	A
TLP808	8	8 ft.	Right Angle	1440	6	—	—	—	PR, GR	Built-In	Light Gray	\$75,000	Yes	A
TLP808B	8	8 ft.	Right Angle	1440	6	—	—	—	PR, GR	Built-In	Black	\$75,000	Yes	A
TLP806TEL	8	6 ft.	Right Angle	2160	5	1 in/1 out	—	—	PR, GR	—	Black	\$150,000	Yes	C

Continued on next page

Surge Protectors (continued)

						Data Line Protection								
 Model	Outlet Qty.	Cord Length	Plug Style	Joules ⁽¹⁾	Total Transformer Capacity ⁽²⁾	Tel/Modem (RJ11)	Coaxial (Type F)	Tel/Ethernet (RJ45)	Diagnostic LEDs ⁽³⁾	Outlet Safety Covers	Housing Color	Ultimate Lifetime Insurance ⁽⁴⁾	Retail Packaging	Housing Style ⁽⁵⁾
Protect It! Surge Protectors—Plastic Housing (continued)														
SK6-6 (SUPER8)	8	8 ft.	Right Angle	1080	4	—	—	—	PR, GR, OK	8	Light Gray	\$35,000	Yes	D
HT706TSAT	7	6 ft.	Right Angle	2100	4	1 in/1 out	2 in/2 out	—	PR, GR	—	Black	\$100,000	Yes	E
HT706TV	7	6 ft.	Right Angle	1500	4	—	1 in/1 out	—	PR, GR	—	Black	\$50,000	Yes	E
SUPER7TEL15	7	15 ft.	Right Angle	2520	5	1 in/1 out	—	—	PR, GR	—	Light Gray	\$75,000	Yes	F
SUPER7TEL	7	7 ft.	Right Angle	2520	5	1 in/1 out	—	—	PR, GR	—	Light Gray	\$75,000	Yes	F
SUPER725B	7	25 ft.	Right Angle	2160	5	—	—	—	PR, GR	—	Black	\$75,000	Yes	F
SUPER7	7	7 ft.	Right Angle	2160	5	—	—	—	PR, GR	—	Light Gray	\$75,000	Yes	F
SUPER7B	7	7 ft.	Right Angle	2160	5	—	—	—	PR, GR	—	Black	\$75,000	Yes	F
SUPER7COAX	7	7 ft.	Right Angle	2160	5	—	1 in/1 out	—	PR, GR	—	Light Gray	\$75,000	Yes	F
TLP706TELC	7	6 ft.	Right Angle	1440	4	1 in/1 out	—	—	PR, GR	Built-In	Black	\$50,000	Yes	G
SUPER6TEL12	7	12 ft.	Right Angle	1080	5	1 in/1 out	—	—	PR	—	Light Gray	\$50,000	Yes	F
SUPER6TEL	7	6 ft.	Right Angle	1080	5	1 in/1 out	—	—	PR	—	Light Gray	\$50,000	Yes	F
TLP707TEL	7	7 ft.	Right Angle	1080	5	1 in/1 out	—	—	PR, GR	Built-In	Silver	\$50,000	Yes	H
TLP76RBTEL	7	6 ft.	Straight	1080	4	1 in/1 out	—	—	PR	—	Black	\$50,000	Yes	I
TLP74R	7	4 ft.	Straight	1080	4	—	—	—	PR	—	Light Gray	\$25,000	Yes	I
TLP74RB	7	4 ft.	Straight	1080	4	—	—	—	PR	—	Black	\$25,000	Yes	I
TLP725	7	25 ft.	Straight	1080	4	—	—	—	PR	—	Light Gray	\$25,000	Yes	J
TLP712	7	12 ft.	Straight	1080	4	—	—	—	PR	—	Light Gray	\$25,000	Yes	J
TLP712B	7	12 ft.	Straight	1080	4	—	—	—	PR	—	Black	\$25,000	Yes	J
STRIKER	7	6 ft.	Straight	1080	4	—	—	—	PR	—	Light Gray	\$20,000	Yes	J
HTSWIVEL6 ⁽⁶⁾	6	Direct Plug-In		1500	4	1 in/1 out	1 in/1 out	—	PR, GR	—	Black	\$50,000	Yes	K
SWIVEL6 ⁽⁸⁾	6	Direct Plug-In		1500	4	—	—	—	PR, GR	—	Black	\$20,000	Yes	K
TR-6FM	6	6 ft.	Right Angle	3040	3	1 in/1 out	—	—	PR, FA, OK	6	Light Gray	\$50,000	Yes	L
TR-6	6	6 ft.	Right Angle	2420	3	—	—	—	PR, FA, OK	4	Light Gray	\$50,000	Yes	L
TLP66NET	6	6 ft.	Straight	1080	4	—	—	1 in/1 out	PR, GR	Built-In	Light Gray	\$25,000	Yes	M
TLP64	6	4 ft.	Straight	540	4	—	—	—	PR, GR	Built-In	Light Gray	\$20,000	Yes	M
TLP606RNET ⁽⁸⁾	6	6 ft.	Right Angle	1440	4	1 in/1 out (Combo)	1 in/1 out	—	PR, GR	—	Black	\$150,000	Yes	N
TLP606SSTELB	6	6 ft.	Right Angle	1440	3	1 in/1 out	—	—	PR	—	Black	\$75,000	Yes	O
TLP606DMUSB ⁽⁹⁾	6	6 ft.	Straight	2100	4	2 USB Charging Ports (2.1A Total)			PR, GR	—	Black	\$40,000	Yes	P
TLP608RUSBB ⁽⁸⁾	6	8 ft.	Straight	1080	6	2 USB Charging Ports (3.4A Total)			PR, GR	—	Black	\$50,000	Yes	Q
TLP608	6	8 ft.	Right Angle	990	3	—	—	—	PR	—	Light Gray	\$20,000	Yes	R
TLP608TEL	6	8 ft.	Straight	990	3	1 in/1 out	—	—	PR	—	Light Gray	\$20,000	Yes	R
TLP606USB	6	6 ft.	Straight	990	3	2 USB Charging Ports (2.1A Total)			PR	—	Light Gray	\$20,000	Yes	R
TLP606USBB	6	6 ft.	Straight	990	3	2 USB Charging Ports (2.1A Total)			PR	—	Black	\$20,000	Yes	R


All models are certified to meet UL 1449 (3rd Edition) standards; additional certifications vary by model. All models are compatible with standard 120V operation. Outlets are NEMA 5-15R, unless otherwise indicated. Plugs are NEMA 5-15P, unless otherwise indicated. Most models include a 15A circuit breaker. Most models have an illuminated on/off switch, except TLP1008TELT, TLP1008TEL, TLP1006B, SUPER series models (not SUPER8) and TLP606SSTELB have an unlighted switch. Bench-mount models have a switch with a snap-light cover. Direct plug-in models, permanent-mount models, TLP26USBB and mobile models do not have a switch. TMC-6 has a power button and LED. Most models have keyhole slots, flanges or adjustable brackets for mounting. (1) The joule rating indicates how much surge energy the surge protector can absorb in a single event. A higher rating means more protection. (2) Transformer capacity varies with transformer size. (3) PR = Protected, GR = Grounded, PW = Power, FA = Fault, OK = Line OK. (4) Ultimate Lifetime Insurance is valid in the U.S., Puerto Rico and Canada only. (5) Photos represent housing style only. Refer to the specification chart or visit triplite.com for exact model features. (6) The second output jack is for telephone line (RJ11) connections only. (7) Includes an audible alarm that sounds if the "Protected" LED goes out. (8) HTSWIVEL6 and SWIVEL6 have 6 outlets (two groups of 3 outlets) that rotate 90°. TLP606RNET has 2 fixed outlets and 4 outlets that rotate 90°. TLP608RUSBB has 6 outlets that rotate 90°. SK40RUSBB has 4 outlets that rotate 90°. TLP31SAT has 2 fixed outlets and 1 outlet that rotates 90°. (9) Clamps to a flat surface.

Continued on next page

Surge Protectors (continued)




For housing styles T – 00, see next page.

						Data Line Protection								
 Model	Outlet Qty.	Cord Length	Plug Style	Joules ⁽¹⁾	Total Transformer Capacity ⁽²⁾	Tel/Modem (RJ11)	Coaxial (Type F)	Tel/Ethernet (RJ45)	Diagnostic LEDs ⁽³⁾	Outlet Safety Covers	Housing Color	Ultimate Lifetime Insurance ⁽⁴⁾	Retail Packaging	Housing Style ⁽⁵⁾
Protect It! Surge Protectors—Plastic Housing (continued)														
TLP615	6	15 ft.	Straight	790	3	—	—	—	PR	—	Light Gray	\$20,000	Yes	R
TLP615B	6	15 ft.	Straight	790	3	—	—	—	PR	—	Black	\$20,000	Yes	R
TLP606	6	6 ft.	Straight	790	3	—	—	—	PR	—	Light Gray	\$20,000	Yes	R
TLP606B	6	6 ft.	Straight	790	3	—	—	—	PR	—	Black	\$20,000	Yes	R
TLP604TEL	6	4 ft.	Straight	790	3	1 in/1 out	—	—	PR	—	Light Gray	\$20,000	Yes	R
TLP604	6	4 ft.	Straight	790	3	—	—	—	PR	—	Light Gray	\$20,000	Yes	R
TLP6B	6	6 ft.	Straight	360	3	—	—	—	PR	—	Black	\$10,000	Yes	R
TLP602	6	2 ft.	Straight	180	3	—	—	—	—	—	Light Gray	\$2,500	Yes	R
SPIKESTIK	6	6 ft.	Straight	540	3	—	—	—	PR	6	Light Gray	\$20,000	Yes	S
TLP404	4	4 ft.	Straight	450	2	—	—	—	PR	—	Light Gray	\$1,000	Yes	R

Continued on next page



Surge Protectors (continued)

						Data Line Protection								
 Model	Outlet Qty.	Cord Length	Plug Style	Joules ⁽¹⁾	Total Transformer Capacity ⁽²⁾	Tel/Modem (RJ11)	Coaxial (Type F)	Tel/Ethernet (RJ45)	Diagnostic LEDs ⁽³⁾	Outlet Safety Covers	Housing Color	Ultimate Lifetime Insurance ⁽⁴⁾	Retail Packaging	Housing Style ⁽⁵⁾
Protect It! Direct Plug-In Surge Protectors—Plastic Housing														
SK6-0	6	Direct Plug-In		540	4	—	—	—	PR	—	Light Gray	\$10,000	Yes	T
SK6-0B	6	Direct Plug-In		540	4	—	—	—	PR	—	Black	\$10,000	Yes	T
SK5TEL-0	5	Direct Plug-In		1080	4	1 in/1 out	—	—	PR, GR	—	Light Gray	\$15,000	Yes	T
TLP4BK	4	Direct Plug-In		720	3	—	—	—	PR, GR	—	Black	\$10,000	Yes	U
SK40RUSBB ⁽⁸⁾	4	Direct Plug-In		1080	4	2 USB Charging Ports (3.4A Total)			PR	—	Black	\$25,000	Yes	V
TLP31SAT ⁽⁶⁾	3	Direct Plug-In		1080	3	—	1 in/1 out	—	PR	—	Black	\$25,000	Yes	W
SK3-0	3	Direct Plug-In		660	2	—	—	—	PR, GR	—	Light Gray	\$5,000	Yes	T
SK30USB	3	Direct Plug-In		540	2	2 USB Charging Ports (2.1A Total)			PR	—	Black	\$5,000	Yes	X
SK34USBB	3	Direct Plug-In		540	2	4 USB Charging Ports (4.8A Total)			PR	—	Black	\$10,000	Yes	Y
SK120USB	1 Front, 2 Side	Direct Plug-In		540	3	2 USB Charging Ports (2.1A Total)			PR	—	Black	\$5,000	Yes	Z
SK10TG ⁽¹⁰⁾	1	Direct Plug-In		350	1	—	—	—	PR, PW	—	Black	\$5,000	Yes	AA
SK10USB	1	Direct Plug-In		1080	1	2 USB Charging Ports (2.4A Total)			PR	—	Black	\$5,000	Yes	BB
Protect It! Permanent-Mount (UL 962A) Surge Protectors—Plastic Housing														
TLP410DMUSB ⁽¹¹⁾	4	10 ft.	Straight	1500	4	2 USB Charging Ports (2.4A Total)			1 (Surge)	—	Black	\$20,000	Yes	CC
TLP310DMUSB ⁽¹²⁾	3	10 ft.	Straight	900	2	2 USB Charging Ports (2.4A Total)			1 in/1 out	—	Black	\$20,000	Yes	DD
TLP310USBC ⁽⁹⁾	3	10 ft.	Straight	510	3	2 USB Charging Ports (3.1A Total)			—	—	Black	\$20,000	Yes	EE
TLP310USBS ⁽¹³⁾	3	10 ft.	Straight	510	3	2 USB Charging Ports (3.1A Total)			—	—	Black	\$20,000	Yes	FF
Protect It! Desktop USB Charging Station with Two-Outlet Surge Protector—Plastic Housing														
TLP26USBB	2	6 ft.	Right Angle	1080	1	4 USB Charging Ports (4.8A Total)			PR, GR	—	Black	\$50,000	Yes	GG
Protect It! Under-Monitor Surge Protector—Plastic Housing														
TMC-6	6	6 ft.	Right Angle	1440	4	1 in/1 out	—	—	PR, GR	—	Black	\$50,000	Yes	HH
Protect It! Mobile Surge Protectors—Plastic Housing														
TRAVELER3USB	3	18 in.	Right Angle	1050	2	2 USB Charging Ports (2.1A Total)			PR	—	Black	\$25,000	Yes	II
TRAVELER	2	Direct Plug-In (Retractable)		1050	2	1 in/1 out	—	—	PR, GR	—	Black	\$50,000	Yes	JJ
TRAVELER100BT	2	Direct Plug-In (Retractable)		1050	2	—	—	1 in/1 out	PR, GR	—	Black	\$50,000	Yes	JJ
TRAVELCUBE	1	Direct Plug-In		1080	1	1 in/2 out	—	—	PR, GR	—	Light Gray	\$10,000	Yes	KK
SPIKECUBE	1	Direct Plug-In		600	1	—	—	—	PR, GR	—	Light Gray	\$5,000	Yes	KK
Protect It! Surge Protectors—Metal Housing														
TLM606HJ	6	6 ft.	Straight	1340	3	—	—	—	PR	—	Light Gray	\$75,000	Yes	LL
TLM606	6	6 ft.	Straight	900	3	—	—	—	PR	—	Light Gray	\$5,000	Yes	LL
TLM626TEL15	6	15 ft.	Straight	1340	4	1 in/1 out	—	—	PR, GR	—	Light Gray	\$75,000	Yes	MM
TLM626	6	6 ft.	Straight	1340	4	—	—	—	PR, GR	—	Light Gray	\$75,000	Yes	MM
Waber®-by-Tripp Lite Industrial Surge Protectors—Metal Housing														
DG115-SI	6	6 ft.	Straight	2100	3	—	—	—	PR	—	Light Gray	—	No	NN
DG206	6	6 ft.	Straight	1050	3	—	—	—	PR	—	Light Gray	—	No	NN
PM6NS	6	6 ft.	Straight	900	3	—	—	—	PR	—	Light Gray	—	No	NN
Waber-by-Tripp Lite Commercial Surge Protector—Metal Housing														
PM6SN1	6	6 ft.	Straight	900	3	—	—	—	PR	—	Light Gray	—	No	NN
Bench/Cabinet-Mount Surge Protectors—Metal Housing														
SS7619-15	24	15 ft.	Straight	1650	24	—	—	—	PR	6	Silver	—	No	OO
SS7415-15	16	15 ft.	Straight	1650	16	—	—	—	PR	6	Silver	—	No	OO
SS3612	12	15 ft.	Straight	1050	12	—	—	—	PR	6	Silver	—	No	OO
SS361220	12 ⁽¹⁴⁾	15 ft.	Straight	1650	12	—	—	—	PR	6	Silver	—	No	OO
SS240806	8	6 ft.	Straight	1050	8	—	—	—	PR	6	Silver	—	No	OO
SS480806	8	6 ft.	Straight	1650	8	—	—	—	PR	6	Silver	—	No	OO

All models are certified to meet UL 1449 (3rd Edition) standards; additional certifications vary by model. All models are compatible with standard 120V operation. Outlets are NEMA 5-15R, unless otherwise indicated. Plugs are NEMA 5-15P, unless otherwise indicated. Most models include a 15A circuit breaker. Most models have an illuminated on/off switch, except TL1008TELTV, TLP1008TEL, TLP1008B, SUPER series models (not SUPER8) and TLP606SSTELB have an unlighted switch. Bench-mount models have a switch with a snap-tight cover. Direct plug-in models, permanent-mount models, TLP26USBB and mobile models do not have a switch. TMC-6 has a power button and LED. Most models have keyhole slots, flanges or adjustable brackets for mounting. (1) The joule rating indicates how much surge energy the surge protector can absorb in a single event. A higher rating means more protection. (2) Transformer capacity varies with transformer size. (3) PR = Protected, GR = Grounded, PW = Power, FA = Fault, OK = Line OK. (4) Ultimate Lifetime Insurance is valid in the U.S., Puerto Rico and Canada only. (5) Photos represent housing style only. Refer to the specification chart or visit trippite.com for exact model features. (6) HTSWIVEL6 and SWIVEL6 have 6 outlets (two groups of 3 outlets) that rotate 90°. TLP606RNET has 2 fixed outlets and 4 outlets that rotate 90°. TLP608RUSBB has 6 outlets that rotate 90°. SK40RUSBB has 4 outlets that rotate 90°. TLP31SAT has 2 fixed outlets and 1 outlet that rotates 90°. (9) Clamps to a flat surface. (10) SK10TG features a timer for 1, 3 or 6 hours. (11) Fits in 2 1/8" dia. cutouts. (12) Fits in 2 1/4" dia. cutouts. (13) Includes mounting brackets. (14) SS361220 has a NEMA 5-20P plug, 10 NEMA 5-15R outlets and 2 NEMA 5-15/20R outlets.

Rack-Mount Surge Protectors



 US	Outlet Qty. (NEMA Type)		 A									
	Front	Rear	Cord Length	Plug Type	Plug Style	Joules ⁽¹⁾	Total Transformer Capacity ⁽²⁾	Isolated Filter Banks Qty.	Diagnostic LEDs ⁽³⁾	Ultimate Lifetime Insurance ⁽⁴⁾	Retail Packaging	Housing Style ⁽⁵⁾
Model												
Isobar Rack-Mount Premium Surge Protectors (1U)—Metal Housing												
ISOBAR12ULTRA	2 (5-15R)	10 (5-15R)	15 ft.	5-15P	Straight	3840	6	2	3	\$25,000	No	A
IBAR12	2 (5-15R)	10 (5-15R)	15 ft.	5-15P	Straight	3840	6	2	3	\$25,000	No	A
IBAR12-20ULTRA	2 (5-15R)	10 (5-20R)	15 ft.	5-20P	Straight	3840	6	1	3	\$25,000	No	A
IBAR12-20T	2 (5-15R)	10 (5-20R)	15 ft.	L5-20P	Straight	3840	6	1	3	\$25,000	No	A

Protect It! Rack-Mount Surge Protector (1U)—Metal Housing

DRS-1215	6 (5-15R)	8 (5-15R)	15 ft.	5-15P	Straight	3000	7	0	1	—	No	A
-----------------	-----------	-----------	--------	-------	----------	------	---	---	---	---	----	----------

All models are certified to meet UL 1449 (3rd Edition) standards; additional certifications vary by model. All models are rated for 120V AC (50/60 Hz) operation. All models have a metal housing, circuit breaker(s) and an illuminated on/off switch with a snap-tight cover that reduces the risk of accidental shutoff. All models have removable mounting flanges. (1) The joule rating indicates how much surge energy the surge protector can absorb in a single event. A higher rating means more protection. (2) Transformer capacity varies with transformer size. (3) 1 LED model = "Protected." 3 LED models = "Line OK," "Protected" and "Fault." (4) Ultimate Lifetime Insurance is valid in the U.S., Puerto Rico and Canada only. (5) Photos represent housing style only. Refer to the specification chart or visit tripplite.com for exact model features.



Safety Series & Eco-Surge™ Surge Protectors

Model	Outlet Qty.	Cord Length	Plug Style	Joules ⁽¹⁾	Total Transformer Capacity ⁽²⁾	Diagnostic LEDs ⁽³⁾	Special Features	Outlet Safety Covers	Housing Color	Ultimate Lifetime Insurance ⁽⁴⁾	Retail Packaging	Housing Style ⁽⁵⁾
Protect It! Safety Series Surge Protectors—Metal Housing												
TLM825SA	8	25 ft.	Straight	3900	6	PR	Cord Clip, Cord Wrap w/Hanger	4	Yellow	\$100,000	Yes	B
TLM812SA	8	12 ft.	Straight	1500	6	PR	Cord Clip, Cord Wrap w/Hanger	4	Yellow	\$50,000	Yes	B
TLM615SA	6	15 ft.	Straight	2700	4	PR	Cord Clip, Cord Wrap w/Hanger	4	Yellow	\$75,000	Yes	C
TLM609SA	6	9 ft.	Straight	1500	4	PR	Cord Clip, Cord Wrap w/Hanger	4	Yellow	\$50,000	Yes	C
TLM626SA	6	6 ft.	Straight	900	4	PR	—	4	Yellow	\$10,000	Yes	D

ECO-Surge Energy-Saving Surge Protectors—Plastic Housing

TLP1210SATG⁽⁶⁾	12	10 ft.	Right Angle	3600	8	PR, GR	Master Device Outlet Control	Built-In	Gray	\$250,000	Yes	E
TLP808NETG⁽⁷⁾	8	8 ft.	Right Angle	2160	6	PR, GR	Master Device Outlet Control	Built-In	Gray	\$150,000	Yes	E
TLP78TUSBG⁽⁸⁾	7	8 ft.	Straight	2100	4	PR, GR	Dual Timers	—	Gray	\$150,000	Yes	F
TLP74TG	7	4 ft.	Straight	1400	4	PR, GR	Dual Timers	—	Gray	\$75,000	Yes	F
TLP76MSG	7	6 ft.	Straight	1080	4	PR	6 Individually Switched Outlets	—	Gray	\$25,000	Yes	G

All models are certified to meet UL 1449 (3rd Edition) standards; additional certifications vary by model. Safety series models comply with OSHA safety color code standards. All models are compatible with standard 120V operation. Outlets are NEMA 5-15R. All models have a 15A circuit breaker and an illuminated on/off switch. Models have keyhole mounting slots (except TLP78TUSBG and TLP74TG). (1) The joule rating indicates how much surge energy the surge protector can absorb in a single event. A higher rating means more protection. (2) Transformer capacity varies with transformer size. (3) PR = Protected, GR = Grounded. (4) Ultimate Lifetime Insurance is valid in the U.S., Puerto Rico and Canada only. (5) Photos represent housing style only. Refer to the specification chart or visit tripplite.com for exact model features. (6) TLP1210SATG includes coaxial (Type F, 2 in/2 out) and tel/Ethernet (RJ45, 1 in/1 out) line protection. (7) TLP808NETG includes tel/Ethernet (RJ45, 1 in/1 out) line protection. (8) TLP78TUSBG includes 2 USB charging ports (2.0A total).




DataShield® In-Line Surge Protectors


Model	Input Connection	Output Connection	Description	Clamping Voltage (RMS)	Circuit Breaker	Housing Material	Housing Color	Retail Packaging	Housing Style ⁽⁵⁾
DB25-ALL⁽⁹⁾	DB25 Serial	DB25 Serial	Protects DB25 serial ports	18V	340A	Plastic	Putty	No	H
DB9⁽¹⁰⁾	DB9 Serial	DB9 Serial	Protects DB9 serial ports	18V	340A	Plastic	Putty	No	H
DNET1	RJ45 Male	RJ45 Female	Protects network and phone lines (10/100Base-T, token ring applications)	7.5V	750A	Plastic	Putty	No	I
DSUT1CSU	RJ45 Male	RJ45 Female	Protects T1 and ISDN (RJ11/45/48) lines	60V	200A	Plastic	Putty	No	I
DTL2	RJ11/RJ45 Male	RJ11/RJ45 Female	Protects up to 2 network or phone lines	260V	250A	Plastic	Putty	No	J

(5) Photos represent housing style only. Refer to the specification chart or visit tripplite.com for exact model features. (9) Reversible for use with male or female captive DB25 ports. (10) Reversible for use with male or female captive DB9 ports.

Power Strips

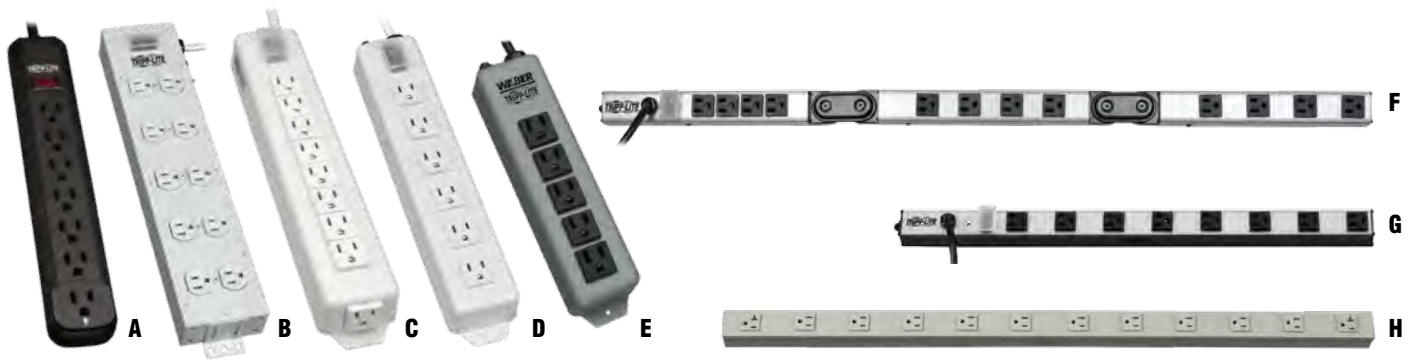

For additional models, see next page.

 Model	Outlet Qty. (NEMA Type)	Cord Length	NEMA Plug Type (Style)	Total Transformer Capacity ⁽¹⁾	Circuit Breaker	Illuminated On/Off Switch ⁽²⁾	Housing Color	Retail Packaging	Housing Style ⁽³⁾
Power It! Home/Office Power Strips—Plastic Housing									
PS725B	7 (5-15R)	25 ft.	5-15P (Straight)	4	15A	Yes	Black	Yes	A
PS712B	7 (5-15R)	12 ft.	5-15P (Straight)	4	15A	Yes	Black	Yes	A
PS615	6 (5-15R)	15 ft.	5-15P (Straight)	3	15A	Yes	Light Gray	Yes	A
PS66B	6 (5-15R)	6 ft.	5-15P (Straight)	3	15A	Yes	Black	Yes	A
PS410	4 (5-15R)	10 ft.	5-15P (Straight)	2	15A	Yes	Light Gray	Yes	A
Waber-by-Tripp Lite Industrial Power Strip—Plastic Housing									
PS6	6 (5-15R)	4 ft.	5-15P (Straight)	3	15A	Yes	Light Gray	No	A
Power It! Home/Office Power Strips—Metal Housing									
TLM1015NC	10 (5-15R) ⁽⁴⁾	15 ft.	5-15P (Straight)	5	15A	Yes	Light Gray	Yes	B
TLM915NC	9 (5-15R)	15 ft.	5-15P (Straight)	5	15A	Yes	Light Gray	Yes	C
TLM615NC	6 (5-15R)	15 ft.	5-15P (Straight)	3	15A	Yes	Light Gray	Yes	D
TLM615NCRA	6 (5-15R) ⁽⁴⁾	15 ft.	5-15P (Straight)	6	15A	Yes	Light Gray	Yes	D
TLM615NC20	6 (5-20R) ⁽⁵⁾	15 ft.	5-20P (Straight)	3	20A	Yes	Light Gray	Yes	D
TLM606NC	6 (5-15R)	6 ft.	5-15P (Straight)	3	15A	Yes	Light Gray	Yes	D
TLM406NC	4 (5-15R)	6 ft.	5-15P (Straight)	2	15A	Yes	Light Gray	Yes	D
TLM306NC	3 (5-15R)	6 ft.	5-15P (Straight)	2	15A	Yes	Light Gray	Yes	D
Foldable Power Strips—Metal Housing									
PSF3612	12 (5-15R)	15 ft.	5-15P (Straight)	10	12A	Yes	Silver	No	F
PSF2408	8 (5-15R)	15 ft.	5-15P (Straight)	6	12A	Yes	Silver	No	F
Bench/Cabinet-Mount Power Strips—Metal Housing									
PS7224	24 (5-15R)	15 ft.	5-15P (Straight)	24	15A	Yes	Silver	No	G
PS7224-20	22 (5-15R), 2 (5-20R) ⁽⁵⁾	15 ft.	5-20P (Straight)	24	20A	Yes	Silver	No	G
PS7224-20HW	22 (5-15R), 2 (5-20R) ⁽⁵⁾	—	Hardwire	24	—	Switchless	Putty	No	H
PS7224-20T	22 (5-15R), 2 (5-20R) ⁽⁵⁾	15 ft.	L5-20P (Straight)	24	20A	Yes	Silver	No	G
PS6020	20 (5-15R)	15 ft.	5-15P (Straight)	20	15A	Yes	Silver	No	G
PS4816	16 (5-15R)	15 ft.	5-15P (Straight)	16	15A	Yes	Silver	No	G
PS4816B	16 (5-15R)	15 ft.	5-15P (Straight)	16	15A	Yes	Black	No	G
PS3612	12 (5-15R)	15 ft.	5-15P (Straight)	12	15A	Yes	Silver	No	G
PS3612B	12 (5-15R)	15 ft.	5-15P (Straight)	12	15A	Yes	Black	No	G
PS3612-20HW	10 (5-15R), 2 (5-20R) ⁽⁵⁾	—	Hardwire	12	—	Switchless	Putty	No	H
PS361206	12 (5-15R)	6 ft.	5-15P (Straight)	12	15A	Yes	Silver	No	G
PS361220	10 (5-15R), 2 (5-20R) ⁽⁵⁾	15 ft.	5-20P (Straight)	12	20A	Yes	Silver	No	G
PS3612RA	12 (5-15R) ⁽⁴⁾	15 ft.	5-15P (Right Angle)	12	15A	Yes	Silver	No	G
PS2408	8 (5-15R)	15 ft.	5-15P (Straight)	8	15A	Yes	Silver	No	G
PS2408B	8 (5-15R)	15 ft.	5-15P (Straight)	8	15A	Yes	Black	No	G
PS240810	8 (5-15R)	10 ft.	5-15P (Straight)	8	15A	Yes	Silver	No	G
PS2408RA	8 (5-15R) ⁽⁴⁾	15 ft.	5-15P (Right Angle)	8	15A	Yes	Silver	No	G
PS480806	8 (5-15R)	6 ft.	5-15P (Straight)	8	15A	Yes	Silver	No	G
PS120406	4 (5-15R)	6 ft.	5-15P (Straight)	2	15A	Yes	Silver	No	G
PS120410	4 (5-15R)	10 ft.	5-15P (Straight)	2	15A	Yes	Silver	No	G
PS120420	2 (5-15R), 2 (5-20R) ⁽⁵⁾	15 ft.	5-20P (Straight)	2	20A	Yes	Silver	No	G
PS240406	4 (5-15R)	6 ft.	5-15P (Straight)	4	15A	Yes	Silver	No	G

All models are certified to meet UL standards; additional certifications vary by model. All models are compatible with standard 120V operation. Most models have keyhole slots, flanges or adjustable brackets for mounting. (1) Transformer capacity varies with transformer size. (2) Most models have a snap-tight cover that reduces the risk of accidental shutoff. Visit triplite.com for exact model features. (3) Photos represent housing style only. Refer to the specification chart or visit triplite.com for exact model features. (4) Right-angle outlets. (5) NEMA 5-20R outlets support NEMA 5-15P and NEMA 5-20P plugs.

Continued on next page



FIND IT FAST! Try our interactive power strip selector guide at www.triplite.com/PSselector

Power Strips (continued)

For housing styles A – E, see previous page.



Model	Outlet Qty. (NEMA Type)	Cord Length	NEMA Plug Type (Style)	Total Transformer Capacity ⁽¹⁾	Circuit Breaker	Illuminated On/Off Switch ⁽²⁾	Housing Color	Retail Packaging	Housing Style ⁽³⁾
Wabber-by-Tripp Lite Industrial Power Strips—Metal Housing									
UL800CB-15	10 (5-15R) ⁽⁴⁾	15 ft.	5-15P (Straight)	5	15A	Yes	Black	No	B
UL17CB-15	9 (5-15R)	15 ft.	5-15P (Right Angle)	4	15A	Yes	Dark Gray	No	C
UL24CB-15	6 (5-15R)	15 ft.	5-15P (Right Angle)	3	15A	Yes	Dark Gray	No	D
UL24RA-15	6 (5-15R) ⁽⁴⁾	15 ft.	5-15P (Right Angle)	3	15A	Yes	Dark Gray	No	D
UL620-15	6 (5-15/20R) ⁽⁵⁾	15 ft.	5-20P (Straight)	3	20A	Yes	Dark Gray	No	D
6SP	6 (5-15R)	6 ft.	5-15P (Straight)	3	15A	Yes	Dark Gray	No	D
6NX6	6 (5-15R)	6 ft.	5-15P (Straight)	3	15A	Yes	Light Gray	No	D
6SPDX-15	6 (5-15R)	15 ft.	5-15P (Straight)	3	15A	Yes	Light Gray	No	D
6SPDX	6 (5-15R)	6 ft.	5-15P (Straight)	3	15A	Yes	Light Gray	No	D
602-15	5 (5-15R)	15 ft.	5-15P (Straight)	3	15A	Switchless	Light Gray	No	E
602	5 (5-15R)	6 ft.	5-15P (Straight)	3	15A	Switchless	Dark Gray	No	E
UL603CB-6	4 (5-15R)	6 ft.	5-15P (Straight)	2	15A	Yes	Dark Gray	No	D
4SPDX	4 (5-15R)	6 ft.	5-15P (Straight)	2	15A	Yes	Light Gray	No	D
3SP	3 (5-15R)	6 ft.	5-15P (Straight)	2	15A	Yes	Light Gray	No	D
3SP9	3 (5-15R)	9 ft.	5-15P (Straight)	2	15A	Yes	Light Gray	No	D

Rack-Mount AC Charger Power Strip (1U)—Metal Housing

PS1916D1U	16 (5-15R Dongles)	15 ft.	5-15P (Straight)	16	15A	Yes	Black	No	I
-----------	--------------------	--------	------------------	----	-----	-----	-------	----	----------

Rack-Mount Power Strips (1U)—Metal Housing

RS-1215	6 Front, 6 Rear (5-15R)	15 ft.	5-15P (Straight)	6	15A	Yes	Black	No	J
RS-1215-RA	6 Front, 6 Rear (5-15R) ⁽⁴⁾	15 ft.	5-15P (Straight)	12	15A	Yes	Black	No	J
RS-1215-20	6 Front, 6 Rear (5-20R) ⁽⁵⁾	15 ft.	5-20P (Straight)	12	20A	Yes	Black	No	J
RS-1215-20T	6 Front, 6 Rear (5-15/20R) ⁽⁵⁾	15 ft.	L5-20P (Straight)	12	20A	Yes	Black	No	J
RS-0615-F	6 Front (5-15R)	15 ft.	5-15P (Straight)	3	15A	Yes	Black	No	J
RS-0615-R	6 Rear (5-15R)	15 ft.	5-15P (Straight)	3	15A	Yes	Black	No	J

All models are certified to meet UL standards; additional certifications vary by model. All models are compatible with standard 120V operation. Most models have keyhole slots, flanges or adjustable brackets for mounting. (1) Transformer capacity varies with transformer size. (2) Most models have a snap-tight cover that reduces the risk of accidental shutoff. Visit tripplite.com for exact model features. (3) Photos represent housing style only. Refer to the specification chart or visit tripplite.com for exact model features. (4) Right-angle outlets. (5) NEMA 5-20R outlets support NEMA 5-15P and NEMA 5-20P plugs.

Safety Series Power Strips

Model	Outlet Qty. (NEMA Type)	Cord Length	NEMA Plug Type (Style)	Total Transformer Capacity ⁽¹⁾	Circuit Breaker	Outlet Safety Covers	Illuminated On/Off Switch	Cord Clip and Cord Wrap with Hanger	Housing Style ⁽³⁾
Power It! Safety Series Power Strips with GFCI Plug—Include retail packaging									
TLM825GF	8 (5-15R)	25 ft.	5-15P (Straight)	6	15A	4	Yes	Yes	K
TLM812GF	8 (5-15R)	12 ft.	5-15P (Straight)	6	15A	4	Yes	Yes	K
TLM609GF	6 (5-15R)	9 ft.	5-15P (Straight)	4	15A	4	Yes	Yes	L
Power It! Safety Series Power Strips—Include retail packaging									
TLM815NS	8 (5-15R)	15 ft.	5-15P (Straight)	6	15A	4	Yes	Yes	K
TLM609NS	6 (5-15R)	9 ft.	5-15P (Straight)	4	15A	4	Yes	Yes	L
TLM626NS	6 (5-15R)	6 ft.	5-15P (Straight)	4	15A	4	Yes	No	M

Housings are yellow. All models are certified to meet UL standards and comply with OSHA safety color code standards. All models are compatible with standard 120V operation. Outlets have a right-angle design. All models have a metal housing and keyhole mounting slots. (1) Transformer capacity varies with transformer size. (3) Photos represent housing style only. Refer to the specification chart or visit tripplite.com for exact model features.



ABOUT TRIPP LITE

Since 1922, Tripp Lite has established a global reputation for quality manufacturing, superior value and excellent service. Tripp Lite makes 4,000 products to power, protect, manage, house, cool, connect and mount electronic equipment. Learn more at www.tripplite.com.

Copyright © 2017 Tripp Lite. All trademarks are the property of their respective owners. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Photos and illustrations may differ slightly from actual products.



Tripp Lite Corporate Headquarters

1111 West 35th Street • Chicago, IL 60609 USA
773.869.1234 • www.tripplite.com

17-05-225 95-34B9

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tripp Lite:](#)

[6SPDX-15](#)