


3-Outlet Surge Protector with 2 USB Ports, 10 ft. (3.05 m) Cord - 510 Joules, Desk Clamp, White Housing

MODEL NUMBER: TLP310USBCW

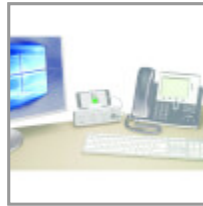

Clamps safely to your workstation to protect your electronics against surges and charge your mobile devices.

Features

510-Joule Surge Protection for Home or Office Electronics The 510-joule rating means your computer, printer, scanner, external hard drive and other sensitive electronic components are protected against strong surges and spikes.

This power surge protector with USB ports features full normal mode (H-N) and common mode (N-G/H-G) line surge suppression. It filters out disruptive EMI/RFI line noise that can cause equipment damage or data loss and exceeds IEEE 587 Category A and B surge suppression specifications.

Charges a Wide Range of Electronic Devices This 10-ft. (3.05 m) surge protector features two USB ports that produce 3.1A of combined power to charge your mobile devices, including smartphones, tablets and MP3 players. A top storage shelf holds smartphones and other small devices while they're charging.

Fits Effortlessly Into Your Workstation This 3-plug surge protector mounts to a clamp that attaches to most desks, tables and flat surfaces, bringing power and device charging to your desktop. The 10-ft. (3.05 m) power cord has a NEMA 5-15P plug and fits through the back of the clamp to reduce cable clutter.

Lifetime Limited Warranty and Ultimate Lifetime Insurance This three-outlet surge protector comes with a lifetime limited warranty and is backed by Tripp Lite's \$20,000 Ultimate Lifetime Insurance for any connected components damaged by a power surge (U.S., Canada and Puerto Rico only).

Highlights

- Clamps firmly to most desks, tables and flat surfaces
- 3 NEMA 5-15R outlets power most computers and peripherals
- 2 USB ports (3.1A total) for charging mobile devices
- 510 joules of surge suppression
- 10-ft. (3.05 m) power cord reaches distant AC outlets

Applications

- Supplies power and charging in a limited amount of space, making it perfect for homes and offices, as well as college dorms and hotel rooms
- Safeguards your computer, printer and peripherals from dangerous surges
- Shields TVs, DVD players, video game consoles, streaming media players, sound systems and device chargers from surges
- Charges your equipment while keeping it safe

Package Includes

- TLP310USBCW Protect It! 3-Outlet Surge Protector
- Desk clamp
- Mounting hardware
- Owner's manual

Specifications



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

OVERVIEW	
UPC Code	037332224897
Product Type	Surge Protector
Charging Form Factor	Strip
Device Compatibility	Phone; Tablet; Amazon Kindle
INPUT	
Nominal Input Voltage(s) Supported	120V AC
Recommended Electrical Service	120V
Input Cord Length Details	Strip
Voltage Compatibility (VAC)	120
Input Plug Type	NEMA 5-15P
Input Cord Length (ft.)	10
Right-Angle Plug	No
Input Cord Length (m)	3.05
Integrated Cord Clip	No
OUTPUT	
Frequency Compatibility	60 Hz
Output (Watts)	1800
Output Receptacles	(4) 5-15R
Circuit Breaker (amps)	15
Transformer Accommodation	(3) Yes
Right-Angle Outlets	No
USER INTERFACE, ALERTS & CONTROLS	
Diagnostic LED(s)	Yes
Diagnostic LED Details	X1 Green LED - Protected
SURGE / NOISE SUPPRESSION	
AC Suppression Joule Rating	510
AC Suppression Response Time	< 1ns
Protection Modes	Includes full normal mode (H-N) and common mode (N-G / H-G) line suppression
Clamping Voltage (RMS)	1000
UL1449 Let Through Rating	1000
EMI / RFI Filtering	Yes



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

Immunity	Conforms to IEE 587/ANSI C62.41
Automatic Shut-Off	No
CHARGING	
Number of Charging Ports	2
Charging Method	USB
Charging Port Type	USB A (FEMALE)
Charging Ports / Amps	(2) 3.1A
DATALINE SURGE SUPPRESSION	
Telephone/DSL Protection	No
Cable (Coax) Protection	No
Network (Ethernet) Protection	No
PHYSICAL	
Antimicrobial Coating	No
Power Cord Color	White
Housing Color	White
Included Mounting Accessories	Mounting hardware
Integrated Keyhole Mounting Slots	No
Material of Construction	Plastic
Receptacle Color	White
Shipping Dimensions (hwd / in.)	7.40 x 4.10 x 5.40
Shipping Weight (kg)	1.18
Unit Dimensions (hwd / cm)	4.93 x 4.47 x 14.7
Unit Dimensions (hwd / in.)	1.94 x 1.76 x 5.8
SPECIAL FEATURES	
Rotatable Outlets	No
STANDARDS & COMPLIANCE	
Approvals	RoHS
UL1449 3rd Edition (AC Suppression)	UL1449, UL962A
WARRANTY	
Product Warranty Period (Worldwide)	Lifetime limited warranty



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

Connected Equipment Insurance (U.S., Canada & Puerto Rico)	\$20,000 Ultimate Lifetime Insurance
---	--

© 2021 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies:
<https://www.tripplite.com/products/product-certification-agencies>

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tripp Lite:](#)

[TLP310USBCW](#)