




**Tripp Lite**  
1111 W. 35th Street  
Chicago, IL 60609 USA  
Telephone: 773.869.1234  
www.tripplite.com

## Protect It! 6-Outlet Home Computer Surge Protector, 2 ft. (0.61 m) Cord, 180 Joules

MODEL NUMBER: TLP602

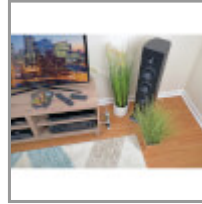

### Highlights

- 6 outlets / 2-ft. (0.61 m) cord
- 180 joule rating

### Package Includes

- TLP602 Surge Suppressor
- Instruction manual and warranty information

### Description

Tripp Lite's TLP602 offers economical AC surge suppression for workstations, desktop PCs, telecom systems and other sensitive electronics. Built-in AC surge suppression shields connected equipment from damage and performance problems due to transient surges. TLP602 offers 6 total outlets, 2-ft. (0.61 m) cord. AC suppression rated at 180 joules shields equipment from surges and line noise. Attractive gray housing with keyhole mounting tabs and 1 designated transformer plug outlet offers convenient protection of desktop computer equipment and accessories.

PLUG/OUTLETS: Input: NEMA5-15P/Output: 6 NEMA5-15R/2-ft. (0.61 m) AC line cord

ELECTRICAL: 120V AC, 50/60Hz, 15A (Requires NEMA5-15R wall receptacle)

FORMAT: Corded multi-outlet strip

SUPPRESSION: AC: 150V RMS Clamping/180 joules

### Features

- 6 outlets
- 2-ft. (0.61 m) cord
- Surge suppression rating: 180 joules
- 15 amp resettable circuit breaker
- Includes full normal mode (H-N) and common mode (N-G/H-G) line surge suppression
- Can accommodate 1 large transformer plug without covering remaining outlets, 4 total transformers
- Keyhole support for wall mounting
- Lighted power switch
- \$2,500 Ultimate Lifetime Insurance (USA and Canada Only)

## Specifications

### OVERVIEW

UPC Code

037332095404



**Tripp Lite**  
1111 W. 35th Street  
Chicago, IL 60609 USA  
Telephone: 773.869.1234  
[www.tripplite.com](http://www.tripplite.com)

| INPUT                              |  |
|------------------------------------|--|
| Nominal Input Voltage(s) Supported | 120V AC  |
| Recommended Electrical Service     | 120V (110-125V)  |
| Voltage Compatibility (VAC)        | 120  |
| Maximum Surge Amps                 | 12000  |
| Input Plug Type                    | NEMA 5-15P   |
| Input Cord Length (ft.)            | 2  |
| Right-Angle Plug                   | No   |
| Input Cord Length (m)              | 0.61   |
| Integrated Cord Clip               | No   |
| OUTPUT                             |  |
| Frequency Compatibility            | 50 / 60 Hz   |
| Output (Watts)                     | 1800   |
| Output Receptacles                 | (6) 5-15R  |
| Circuit Breaker (amps)             | 15   |
| Transformer Accommodation          | (2) Yes  |
| Outlet Orientation                 | Single row   |
| USER INTERFACE, ALERTS & CONTROLS  |  |
| Diagnostic LED(s)                  | No   |
| Switches                           | Combination AC circuit breaker and 2 position on/off power switch                  |
| SURGE / NOISE SUPPRESSION          |  |
| AC Suppression Joule Rating        | 180  |
| AC Suppression Response Time       | < 1 ns   |
| Protection Modes                   | Includes full normal mode (H-N) and common mode (N-G / H-G) line surge suppression |
| Clamping Voltage (RMS)             | 150  |
| UL1449 Let Through Rating          | 500V   |
| Automatic Shut-Off                 | No   |
| DATALINE SURGE SUPPRESSION         |  |
| Telephone/DSL Protection           | No   |
| Cable (Coax) Protection            | No   |
| Network (Ethernet) Protection      | No   |



**Tripp Lite**  
1111 W. 35th Street  
Chicago, IL 60609 USA  
Telephone: 773.869.1234  
[www.tripplite.com](http://www.tripplite.com)

| PHYSICAL   |  |
|--|--|
| Antimicrobial Coating                                      | No   |
| Power Cord Color   | Light Gray   |
| Housing Color  | Light Gray   |
| Integrated Keyhole Mounting Slots                          | Yes  |
| Keyhole Slot Mounting Measurement (Center to Center)       | Distance between slots = 101mm; Distance between slot height = 28mm  |
| Material of Construction                                   | Plastic  |
| Outlets Measurement (Center to Center)                     | 28.5mm   |
| Receptacle Color   | Light gray   |
| Shipping Dimensions (hwd / cm)                             | 5.08 x 10.16 x 28.45   |
| Shipping Dimensions (hwd / in.)                            | 2.00 x 4.00 x 11.20  |
| Shipping Weight (kg)                                       | 0.34   |
| Shipping Weight (lbs.)                                     | 0.74   |
| Unit Dimensions (hwd / cm)                                 | 3.00 x 4.29 x 23.98  |
| Unit Dimensions (hwd / in.)                                | 1.18 x 1.69 x 9.44   |
| Unit Weight (kg)   | 0.26   |
| Unit Weight (lbs.)   | .57  |
| SPECIAL FEATURES   |  |
| Rotatable Outlets  | No   |
| STANDARDS & COMPLIANCE                                     |  |
| Canada   | cUL  |
| Approvals  | Exceeds IEEE 587 category A&B specifications   |
| UL1449 3rd Edition (AC Suppression)                        | UL1449 3RD EDITION   |
| UL1363 (Power Tap)   | UL1363   |
| WARRANTY   |  |
| Product Warranty Period (Worldwide)                        | Lifetime limited warranty  |
| Connected Equipment Insurance (U.S., Canada & Puerto Rico) | \$2,500 <a class="insuranceLink" href="//www.tripplite.com/support/insurance-policy">Ultimate Lifetime Insurance</a> |

© 2021 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies: <https://www.tripplite.com/products/product-certification-agencies>

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Tripp Lite:](#)

[TLP602](#)