

SMD Seam Sealing Crystals

2.0 x 1.6 x 0.5 mm AY Series

Automotive
Application Series

Features

- Reliable seam sealed ceramic package.
- Wide operating temperature range.
- Superior performance and stringent reliability in harsh environment.
- Application: TPMS, ECM, ABS and sensor modules.
- Compact size.
- RoHS Compliant / Pb Free.




Electrical Specifications

Item / Type	AY
Frequency Range	16 ~ 50 MHz
Frequency Tolerance (at 25 °C)	± 10 ppm, ± 20 ppm, or specify
Frequency Stability Over Operating Temperature Range	± 10 ppm, ± 20 ppm, or specify
Operating Temperature Range	-40 ~ +125 °C
Shunt Capacitance (C0)	3 pF Max.
Drive Level	1 ~ 200 μW (50 μW typical)
Load Capacitance	8 pF, 10 pF, 12 pF, or specify
Aging (at 25 °C)	± 3 ppm / year Max.
Storage Temperature Range	- 40 ~ + 85 °C
Reliability Standard	AEC-Q200

Equivalent Series Resistance(ESR)

Fundamental	
16 ~ 19.2 MHz	200 Ω Max.
19.2 ~ 30 MHz	100 Ω Max.
30 ~ 50 MHz	80 Ω Max.

Dimensions

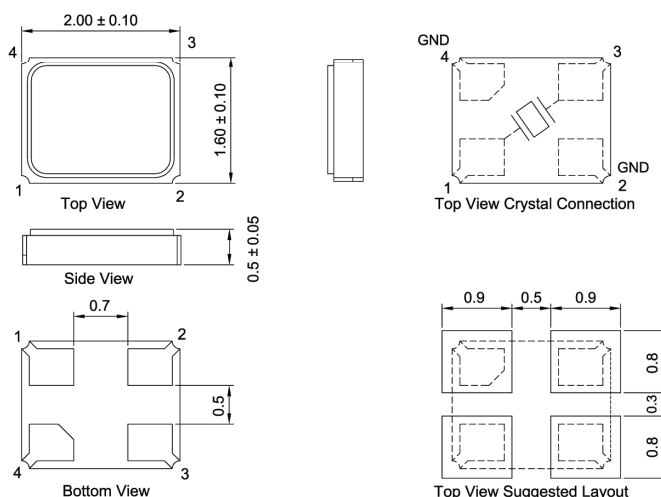

Units: mm

Remark : Specification subject to change without prior notice. Please confirm with our sales.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TXC Corporation:](#)

[AY-16.000MAMQ-T](#) [AY-16.000MAMV-T](#) [AY-16.000MFNQ-T](#) [AY-16.000MFNV-T](#) [AY-20.000MAMQ-T](#) [AY-20.000MAMV-T](#) [AY-20.000MFNQ-T](#) [AY-20.000MFNV-T](#) [AY-24.000MAMQ-T](#) [AY-24.000MAMV-T](#) [AY-24.000MFNQ-T](#) [AY-24.000MFNV-T](#) [AY-25.000MAMQ-T](#) [AY-25.000MAMV-T](#) [AY-25.000MFNQ-T](#) [AY-25.000MFNV-T](#) [AY-26.000MAMQ-T](#) [AY-26.000MAMV-T](#) [AY-26.000MFNQ-T](#) [AY-26.000MFNV-T](#) [AY-27.120MFNQ-T](#) [AY-27.120MFNV-T](#) [AY-30.000MFNQ-T](#) [AY-30.000MFNV-T](#) [AY-32.000MFNQ-T](#) [AY-32.000MFNV-T](#) [AY-38.400MAMQ-T](#) [AY-38.400MAMV-T](#) [AY-38.400MFNQ-T](#) [AY-38.400MFNV-T](#) [AY-40.000MAMQ-T](#) [AY-40.000MAMV-T](#) [AY-40.000MFNQ-T](#) [AY-40.000MFNV-T](#) [AY-48.000MAMQ-T](#) [AY-48.000MAMV-T](#) [AY-48.000MFNQ-T](#) [AY-48.000MFNV-T](#) [AY-48.000MEQY-T](#) [AY-48.000MFMQ-T](#) [AY-32.000MDQB-T](#)