

Molded Parts

Specification Control Drawing

Part Number : 222K163-8
Description : Boot, 90°, With Lip

- NOTES
1. All dimensions are in

inches

millimeters

2. Dimensions appearing in table are as follows:

a - As Supplied

b - After Unrestricted Recovery

3. Molding ports are optional. When -00 modification number is specified molding ports will be located as shown.

4. If eyelet clip (000W212) is required with part then add CS-1858 to description (i.e. 202K121-3-0-CS-1858).

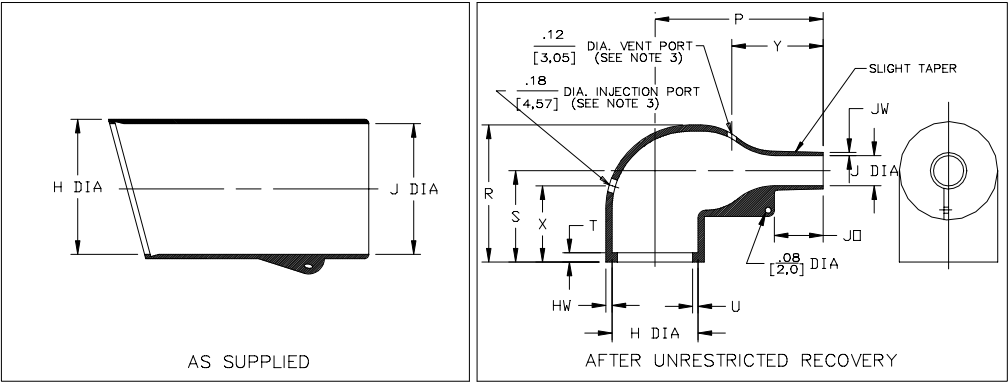


TABLE OF DIMENSIONS														
PART NUMBER	H		J		P	R	S	T	U	JO	HW	JW	X	Y
	Min	Max	Min	Max	±10%	±10%	±10%	±10%	±10%	±10%	±20%	±20%	±20%	±20%
	a	b	a	b	b	b	b	b	b	b	b	b	b	b
222K163-8	1.69 [43,0]	1.11 [28,2]	.98 [25,0]	.39 [9,9]	2.17 [55,0]	1.77 [45,0]	1.18 [30,0]	.12 [3,0]	.07 [1,7]	.63 [16,0]	.08 [2,0]	.04 [1,0]	.98 [25,0]	1.18 [30,0]

If this document is printed it becomes uncontrolled.
Check for the latest revision.

tyco/Electronics

TYCO ELECTRONICS
300 CONSTITUTION DRIVE
MENLO PARK, CALIFORNIA 94025

Revision : B
Date : 3/03/03

Part Number : 222K163-8
Description : Boot, 90°, With Lip

Molded Parts

Specification Control Drawing

Part Number : 222K163-8
Description : Boot, 90°, With Lip

COMPATABILITY CHART					
MATERIAL DASH NO.	MATERIAL DESCRIPTION	RT SPEC	COATING SLASH NO.	COATING S NO.	COATING DESCRIPTION
-8	Polyolefin, Space	RT-1308	N/A		

ORDERING INFORMATION

222K163

-8

-XX

/XX

Base part number

Material dash number
(See Compatability Chart)

Modification number
(If necessary, see front of scd binder for a complete list)

Adhesive slash number
(If necessary, see Compatability Chart)

THIS DRAWING IS SUBJECT TO CHANGE WITHOUT NOTICE; CONSULT YOUR
NEAREST FIELD REPRESENTATIVE FOR CURRENT REVISION

tyco/Electronics

TYCO ELECTRONICS
300 CONSTITUTION DRIVE
MENLO PARK, CALIFORNIA 94025

Revision : B
Date : 3/03/03

Part Number : 222K163-8
Description : Boot, 90°, With lip

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[222K174-100/184-0](#)