

SPECIFICATION CONTROL DRAWING

55A6372

TITLE

TWO CONDUCTOR CABLE, TIN-COATED COPPER CONDUCTOR,
UNSHIELDED, UNJACKETED, 600 VOLT


DATE:

5-8-84

REVISION:

This specification sheet forms a part of the latest issue of Raychem Specification 55A.

COMPONENT WIRES - 55A6355-AWG-*

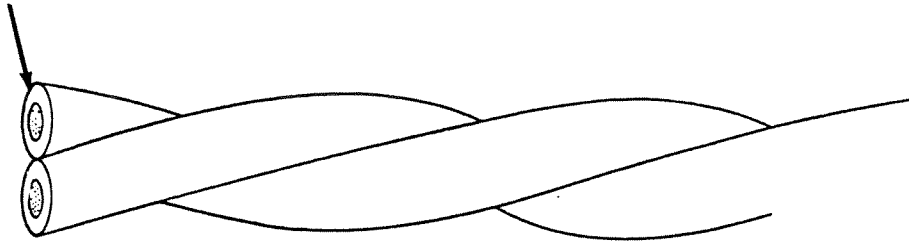

CABLE CONSTRUCTION DETAILS				
PART NUMBER	CONDUCTOR SIZE (AWG)	OUTSIDE DIAMETER (in.)		MAXIMUM WEIGHT (lb/1000 ft)
		NOMINAL ^{1/}	MAXIMUM	
55A6372-24-*	24	.074	.078	4.0
55A6372-22-*	22	.086	.090	5.8
55A6372-20-*	20	.102	.108	8.9
55A6372-18-*	18	.122	.128	13.5
55A6372-16-*	16	.138	.144	17.3
55A6372-14-*	14	.172	.180	26.6
55A6372-12-*	12	.208	.216	40.3

^{1/} Nominal values are for information only.
Nominal values are not requirements.

CABLE RATINGS AND ADDITIONAL REQUIREMENTS

TEMPERATURE RATING: 150°C

Maximum continuous conductor temperature

VOLTAGE RATING: 600 volts

BLOCKING: 200°C ± 3°C for 6 hours

DIELECTRIC WITHSTAND: 1500 volts, 60 Hz

FLAMMABILITY:

Procedure 1, 3 seconds (maximum); 3 in.
(maximum); no flaming of facial tissue

PART NUMBER:

The "*" in the part numbers above
shall be replaced by color code
designators in accordance with
MIL-STD-681 with slashes separating
component wire colors.

Example: AWG 16, white and black:
55A6372-16-9/0

DIMENSIONS ARE IN INCHES, AND UNLESS OTHERWISE DESIGNATED ARE NOMINAL.

Raychem

Page 1 of 1

THIS SPECIFICATION SHEET TAKES PRECEDENCE OVER
DOCUMENTS REFERENCED HEREIN. REFERENCED DOC-
UMENTS SHALL BE OF THE ISSUE IN EFFECT ON DATE
OF INVITATION FOR BID.

Raychem Corporation
300 Constitution Drive, Menlo Park, California 94025
415) 361 3333 TWX 910 373 1205

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[55A6372-22-5/59CS2063](#)