

SPECIFICATION CONTROL DRAWING


55A6544TITLE TWO CONDUCTOR CABLE, SILVER-COATED COPPER CONDUCTOR,
UNSHIELDED, UNJACKETED, 600 VOLT

Date 3-251-99

Revision B

This specification sheet forms a part of the latest issue of Raychem Specification 55A.

COMPONENT WIRES - 55A6543

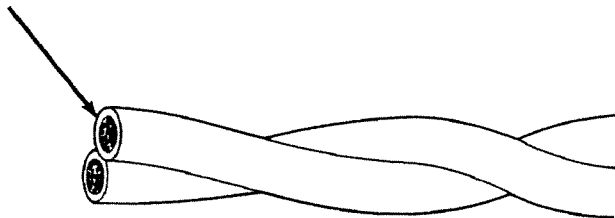

CABLE CONSTRUCTION DETAILS

PART NUMBER	CONDUCTOR SIZE (AWG)	OUTSIDE DIAMETER (inch)		MAXIMUM WEIGHT (lbs/1000 ft)
		NOMINAL	MAXIMUM	
55A6544-26-*	26	.064	.068	2.9
55A6544-24-*	24	.074	.078	4.1
55A6544-22-*	22	.086	.090	6.1
55A6544-20-*	20	.102	.108	9.2
55A6544-18-*	18	.122	.128	14.1
55A6544-16-*	16	.138	.144	18.0
55A6544-14-*	14	.172	.180	27.5
55A6544-12-*	12	.208	.216	41.4

CABLE RATINGS AND ADDITIONAL REQUIREMENTS

TEMPERATURE RATING: 200°C

Maximum continuous conductor temperature

VOLTAGE RATING: 600 volts (rms)

DIELECTRIC WITHSTAND: 1500 volts (rms), 60 Hz

INSULATION ELONGATION: 120% (minimum)

on wires removed from the finished cable

PART NUMBER:

The "*" in the part numbers above shall be replaced by color code designators with a slash separating the component wire colors.

Example: AWG 20, white and black component wires: 55A6544-20-9/0

NOTE: Nominal values are for information only.
Nominal values are not requirements.

COLORS AND COLOR CODE DESIGNATORS SHALL BE IN ACCORDANCE WITH MIL-STD-881.

DIMENSIONS ARE IN INCHES, AND UNLESS OTHERWISE DESIGNATED ARE NOMINAL.

Raychem

Raychem Corporation
300 Constitution Drive, Menlo Park, California 94025
1-800-2 Raychem Fax 1-650-361-6297

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[55A6544-18-9/90CS2063](#) [55A6544-24-9/96CS2868](#)