

# SPECIFICATION CONTROL DRAWING

55PC6015

TITLE

ONE CONDUCTOR CABLE, FLAT BRAID SHIELDED, JACKETED, 600 VOLT


Date

1-25-93

Revision

A

This specification sheet forms a part of the latest issue of Raychem Specification 55PC

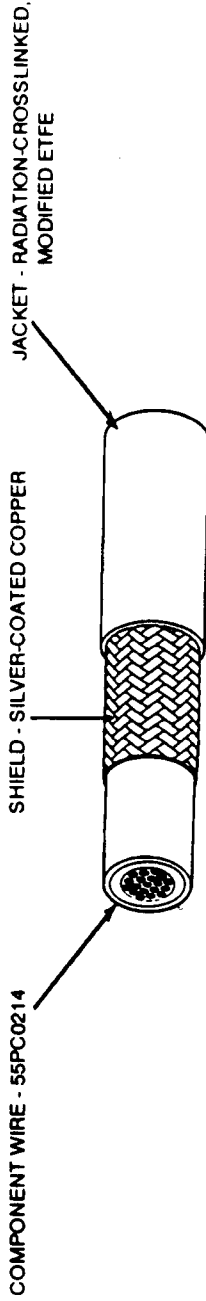

## CONSTRUCTION DETAILS

PART NUMBER	CONDUCTOR SIZE (AWG)	SHIELD STRAND THICKNESS (± .0004)	JACKET THICKNESS (in.)		DIAMETER (in.)		WEIGHT (lbs/1000 ft.)	
			LOWER SPEC LIMIT	TARGET WALL	LOWER SPEC LIMIT	TARGET VALUE	UPPER SPEC LIMIT	TARGET VALUE
55PC6015-26*	26	.0015	.0055	.0070	.056	.060	3.25	3.57
55PC6015-24*	24	.0015	.0055	.0070	.062	.066	4.08	4.43
55PC6015-22*	22	.0015	.0055	.0070	.067	.071	5.26	5.63
55PC6015-20*	20	.0015	.0055	.0070	.076	.080	7.12	7.55
55PC6015-18*	18	.0015	.0055	.0070	.085	.089	9.74	10.29
55PC6015-16*	16	.0015	.0055	.0070	.093	.097	11.86	12.43

## CABLE RATINGS AND ADDITIONAL REQUIREMENTS

TEMPERATURE RATING: 200°C

Maximum continuous conductor temperature

VOLTAGE RATING: 600 volts (rms)

DIELECTRIC WITHSTAND: 1500 volts (rms), 60 Hz

CROSSLINKING PROOF TEST: 300 ± 3°C for 1 hour

JACKET COLOR: White preferred

JACKET ELONGATION AND TENSILE STRENGTH:

Elongation, 50% (minimum)

Tensile Strength, 5000 lb/in<sup>2</sup> (minimum)

JACKET FLAWS:

Spark Test, 1000 volts (rms), 60 Hz, 100% test

Impulse Dielectric Test, 6.0 kV (peak), 100 % test

SHIELD COVERAGE: 85% (minimum)  
 VOLTAGE WITHSTAND TEST (POST ENVIRONMENTAL):  
 1000 volts (rms), 60 Hz, 1 minute

PART NUMBER:

The "\*" in the part numbers above shall be replaced by a color code designator with a dash separating the component wire color from the jacket color.  
 Example: AWG 24, white component wire, white jacket: 55PC6015-24-9-9

COLOR AND COLOR CODE DESIGNATORS SHALL BE IN ACCORDANCE WITH MIL-STD-681.

THIS SPECIFICATION SHEET TAKES PRECEDENCE OVER DOCUMENTS REFERENCED HEREIN REFERENCED DOCUMENTS SHALL BE OF THE ISSUE IN EFFECT ON DATE OF INVITATION FOR BID.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[55PC6015-22-9-9CS2573](#)