

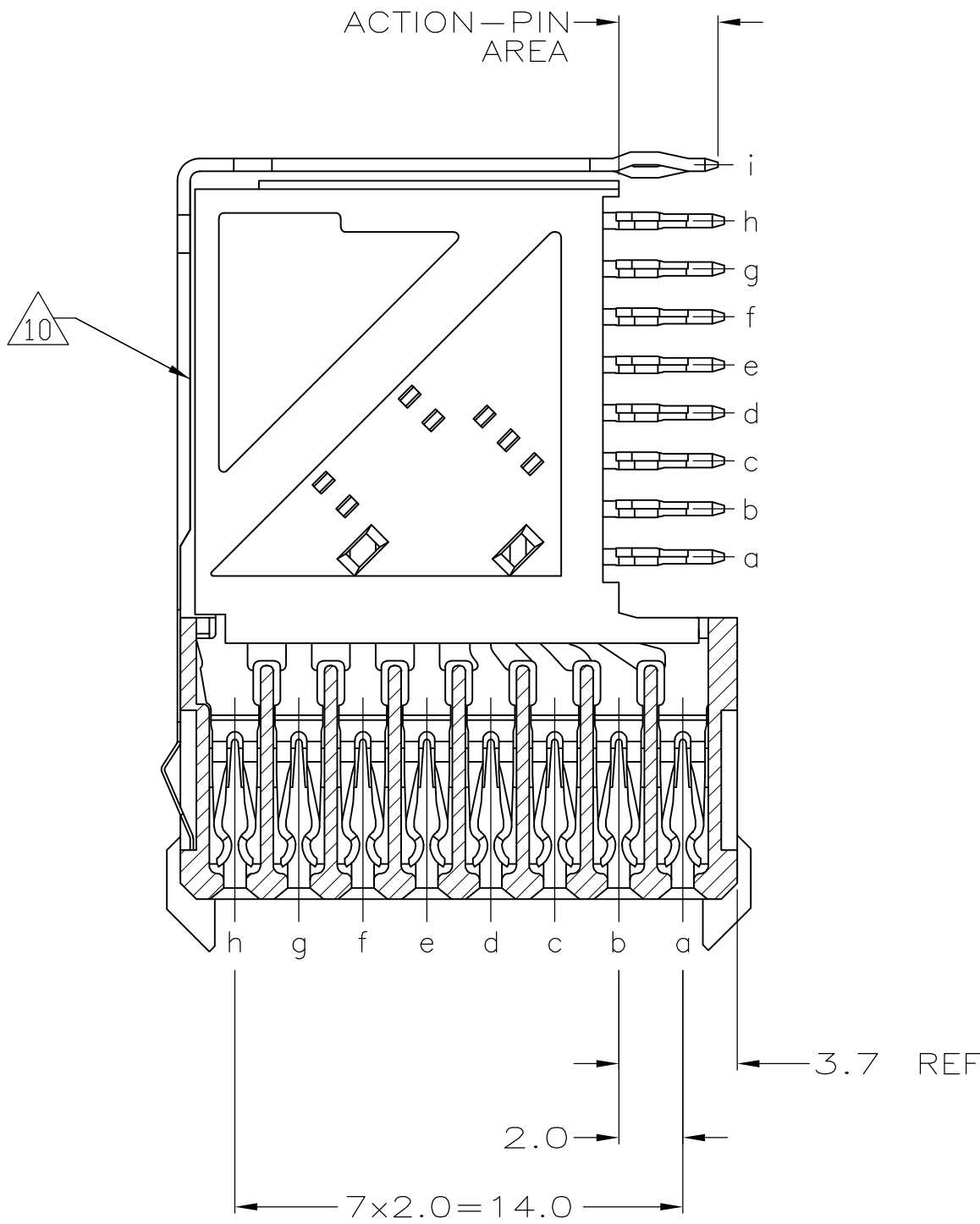
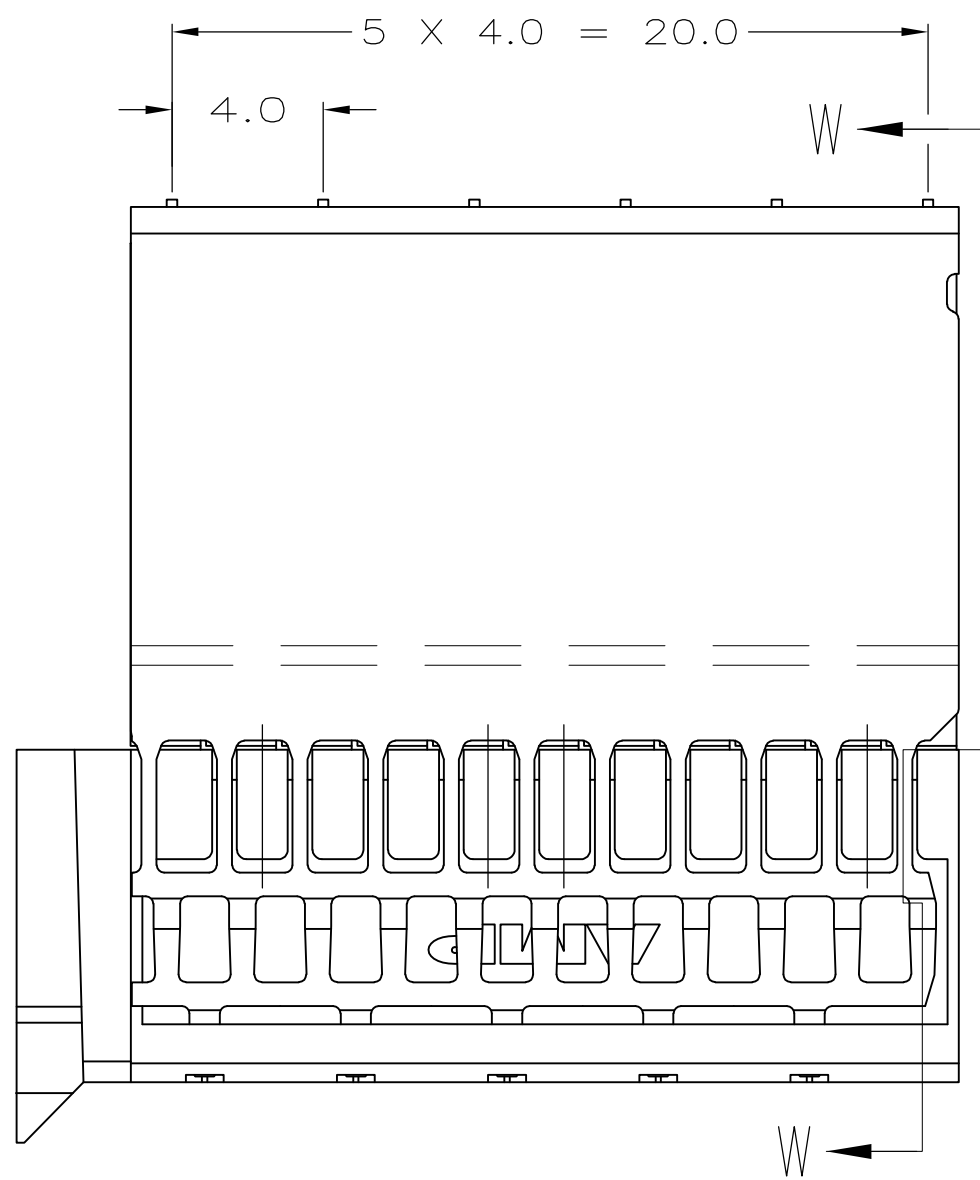
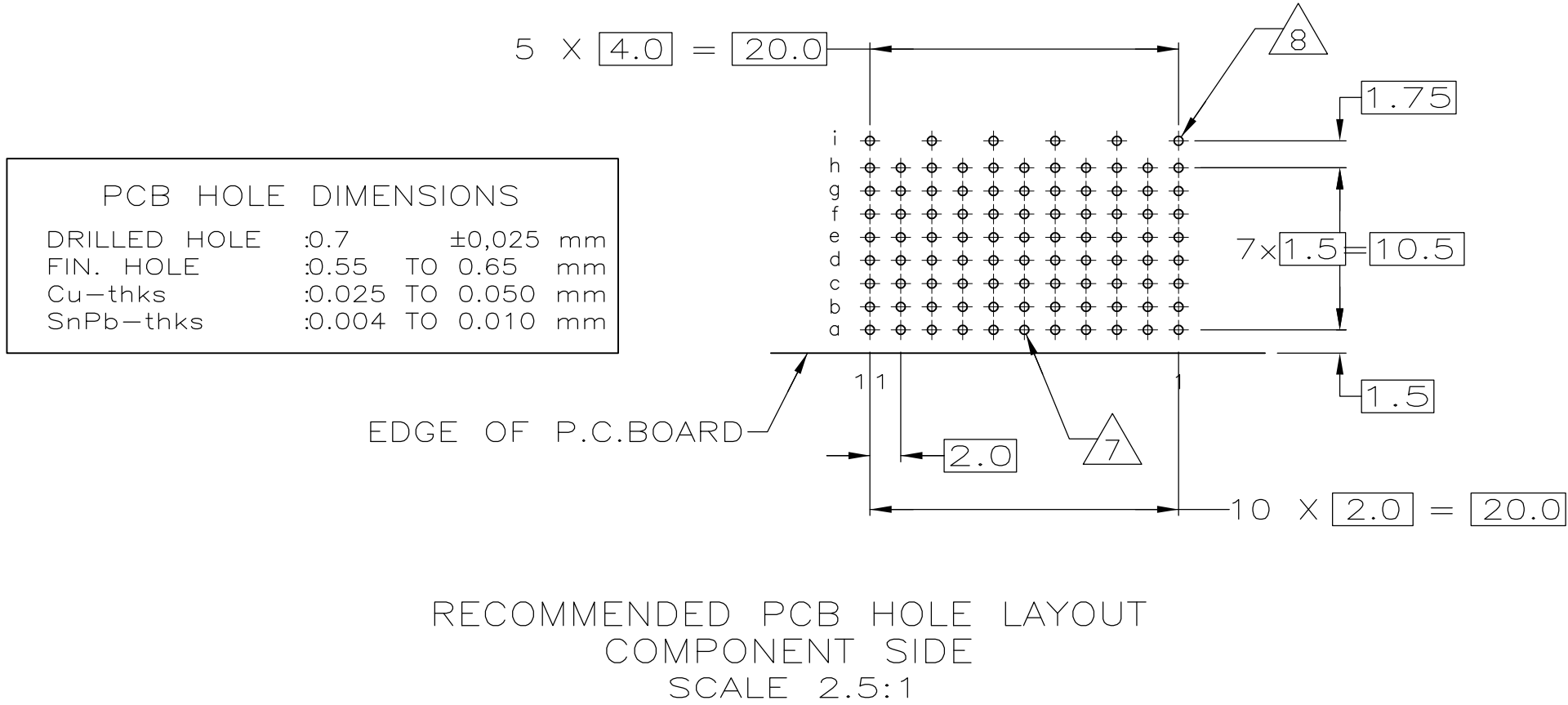


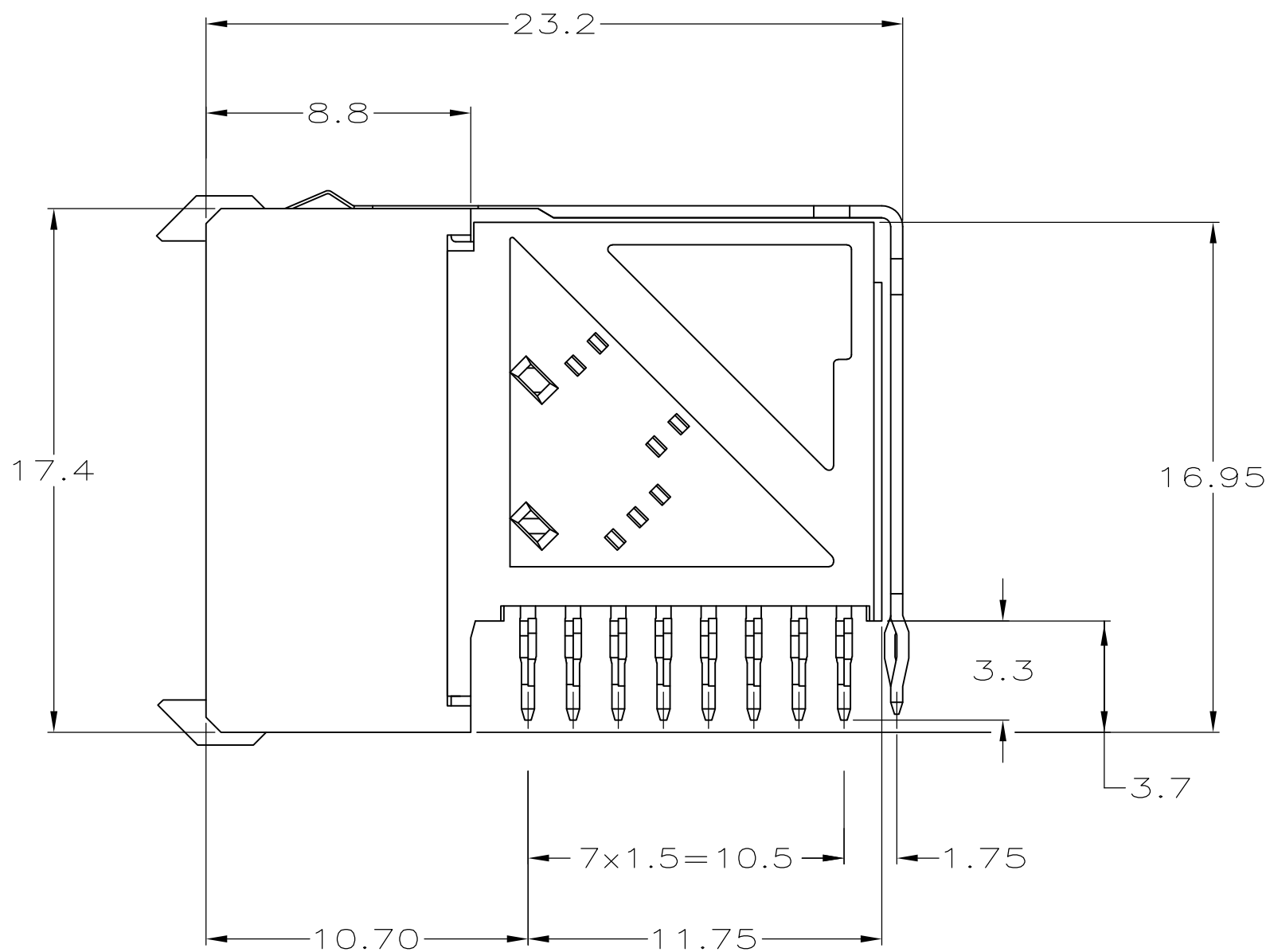

SECTION W-W

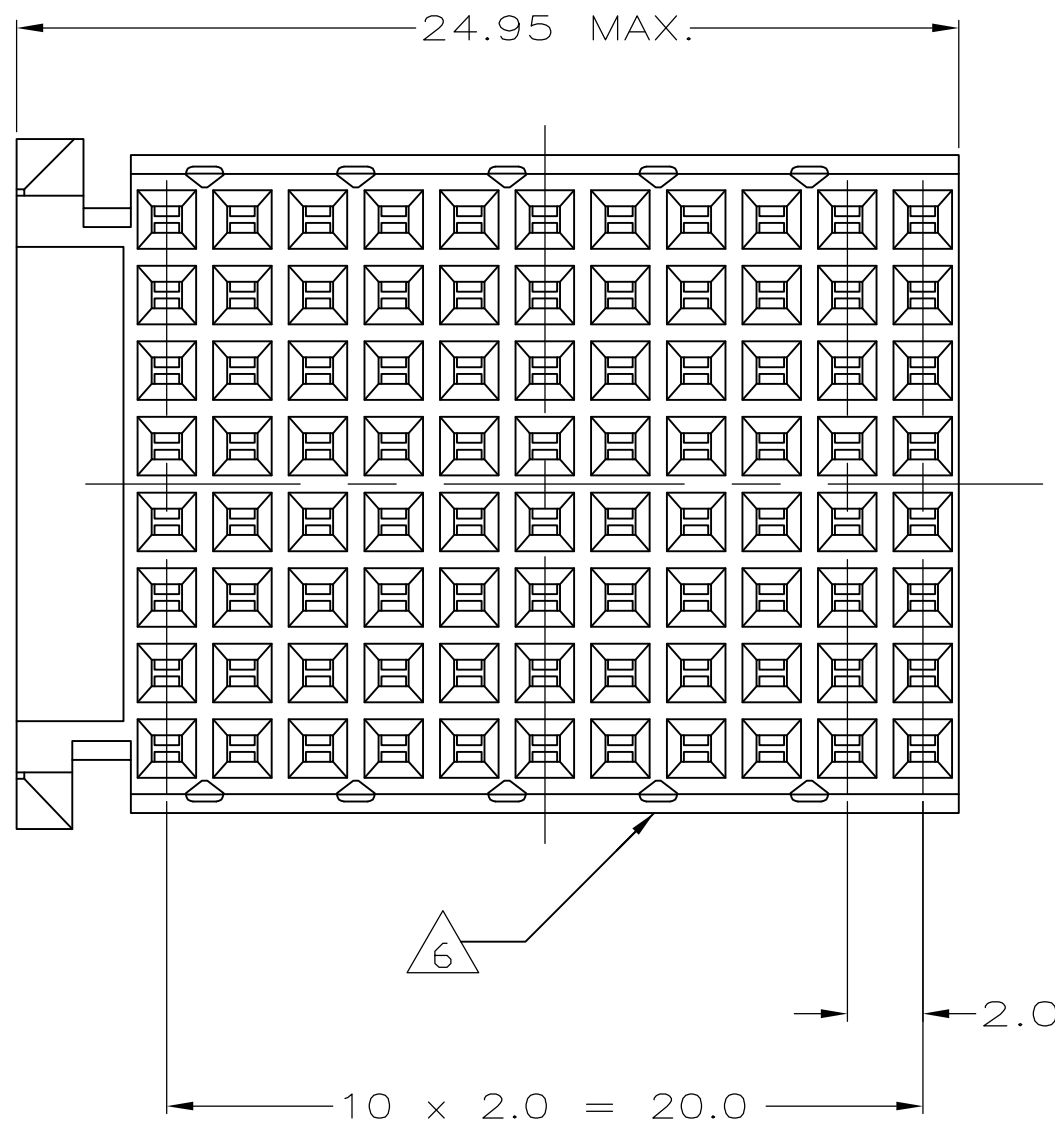

- 1 MATERIAL:
CONTACT: PHOSPHOR BRONZE.
HOUSING: GLASS-FILLED POLYESTER.
- 2 GENERAL PLATING SPECIFICATION: UNDERPLATING
(ENTIRE CONTACT): 1.27µm MIN NICKEL AND ACTION
PIN: 0.5µm MIN TIN/LEAD.
FOR PLATING OF MATING SURFACES SEE APPLICABLE
SPECIFICATION REFERENCE FOR EACH DASH NUMBER.
- 3 CONFORMS TO ALL TESTING ACCORDING TO IEC 61076-4-101
PERFORMANCE LEVEL 2.
- 4 CONNECTOR TESTED AND QUALIFIED AGAINST TELCORDIA GR-1217-CORE QUALITY LEVEL 3,
CENTRAL OFFICE APPLICATIONS.
- 5 CONNECTOR TESTED AND QUALIFIED AGAINST TELCORDIA GR-1217-CORE QUALITY LEVEL 3,
UNCONTROLLED ENVIROMENT APPLICATIONS.
- 6 CONNECTOR MARKED WITH PART NUMBER AND DATE CODE.
ADDITIONAL CHARACTERS OR MARKINGS, AS WELL AS THE LOCATION OF THE MARKINGS,
MAY BE ADDED FOR TRACEABILITY BASED UPON MANUFACTURERS DISCRETION.
- 7 PLATED-THROUGH HOLES AT 2x1.5mm GRID
88 TOTAL HOLES.
- 8 ROW "i" 6 PLATED THROUGH HOLES FOR UPPERSHIELD.
- 9 CONNECTOR & SHIELD LUBRICATED WITH BELCORE APPROVED LUBRICANT,
TECHNICAL REFERENCE: TR-NWT-001217 ISSUE 1, SEP 1992.
- 10 SHIELD MOUNTED ON CONNECTOR WITH DOUBLE SIDED ADHESIVE TAPE
OR ADHESIVE.
- 11 0.76µm MIN GOLD PLATING AT MATING SURFACES.

	2311	3-646492-0
OBSOLETE	259	1-646492-9
OBSOLETE	249	646492-9
OBSOLETE	23	646492-1
	FINISH	PART NUMBER

THIS DRAWING IS A CONTROLLED DOCUMENT.

DWN B CARBO
CHK G SKIPPER
APVD G SKIPPER
PRODUCT SPEC

TOLERANCES UNLESS OTHERWISE SPECIFIED:
0-PLG ±
1-PLG ±0.1
2-PLG ±
3-PLG ±
4-PLG ±
ANGLES ±

mm

0-PLG ±
1-PLG ±0.1
2-PLG ±
3-PLG ±
4-PLG ±
ANGLES ±

MATERIAL 1

SEE TABLE

DWN B CARBO
CHK G SKIPPER
APVD G SKIPPER
PRODUCT SPEC

APPLICATION SPEC

SIZE CAGE CODE DRAWING NO
A100779646492

RESTRICTED TO

CUSTOMER DRAWING

SCALE 5:1

SHEET 1 OF 1

REV M

Tyco Electronics Corporation
Harrisburg, PA 17105-3608

R/A RECEPTACLE ASSY, 88 POSN, TTR
8 ROW, TYPE F, Z-PACK 2mm HM

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[3-646492-0](#)