


REV. C
DCO 300783

TOLERANCES $\pm .010''$ - UNLESS OTHERWISE SPECIFIED

| | |
|-----------------|----------------------------|
| COIL: @ 25°C | |
| RESISTANCE | 500 OHMS $\pm 10\%$ |
| NOMINAL VOLTAGE | 28 VDC |
| MUST OPERATE | 13.5 VDC MAX. |
| MUST RELEASE | 5.5 VDC MAX., 2.3 VDC MIN. |

| | |
|-----------------------------------|---------------------------|
| ENVIRONMENT: | |
| VIBRATION | 70 Hz TO 3000 Hz @ 30 g's |
| SHOCK | 200 g's 6 MS. DURATION |
| TEMPERATURE | -70 °C TO +125 °C |
| NOTES: OPERATE, RELEASE 5 MS MAX. | |
| CONTACT STABILIZATION 2.5 MS MAX. | |
| CONTACT BOUNCE 1 MS MAX. | |

CUSTOMER DATA SHEET

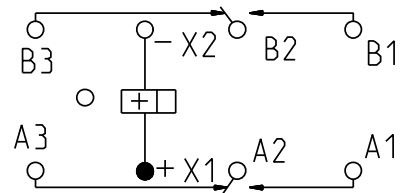

TERMINAL VIEW

| | |
|---|-----------|
| CONTACT RATING: | LOW LEVEL |
| TO 5 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE. | |
| 100,000 OPERATIONS | |

DR. B.D. 11MAR2008 CK. J.M.B. 3/17/08

Tyco Electronics ©COPYRIGHT 2005
TYCO ELECTRONICS CORPORATION
ALL INTERNATIONAL RIGHTS RESERVED

CUST. M83536/1-022M
CUST. NO. REV.

TE NUMBER
3-1617758-0

CII PART NUMBER
FCB-205-0122M

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[M83536/1-022M](#)