

REV. 0


DCO 15679

COIL: @ +25 °C
 RESISTANCE 700 OHMS ± 10%
 NOMINAL VOLTAGE 26.5 VDC
 MUST OPERATE 13.5 VDC
 MUST RELEASE 1.5 VDC

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 20 g's
 SHOCK 100 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C
 NOTES: OPERATE 4 MS MAX
 RELEASE 2 MS MAX
 BOUNCE 3 MS MAX

CUSTOMER DATA SHEET

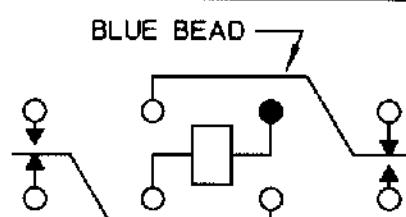

TERMINAL VIEW

CONTACT RATING: 2A 30 VDC
 RESISTIVE .75A 30 VDC INDUCTIVE
 100,000 OPERATIONS

DR. B.D. 6/1/99 CK. G94 6-1-99

COMMUNICATIONS
 INSTRUMENTS, INC.

CUST. HI-G
 CUST. NO. 2K-4A-126

TYPE "HFW" RELAY

HFW1501S26

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[HFW1501S26](#)