


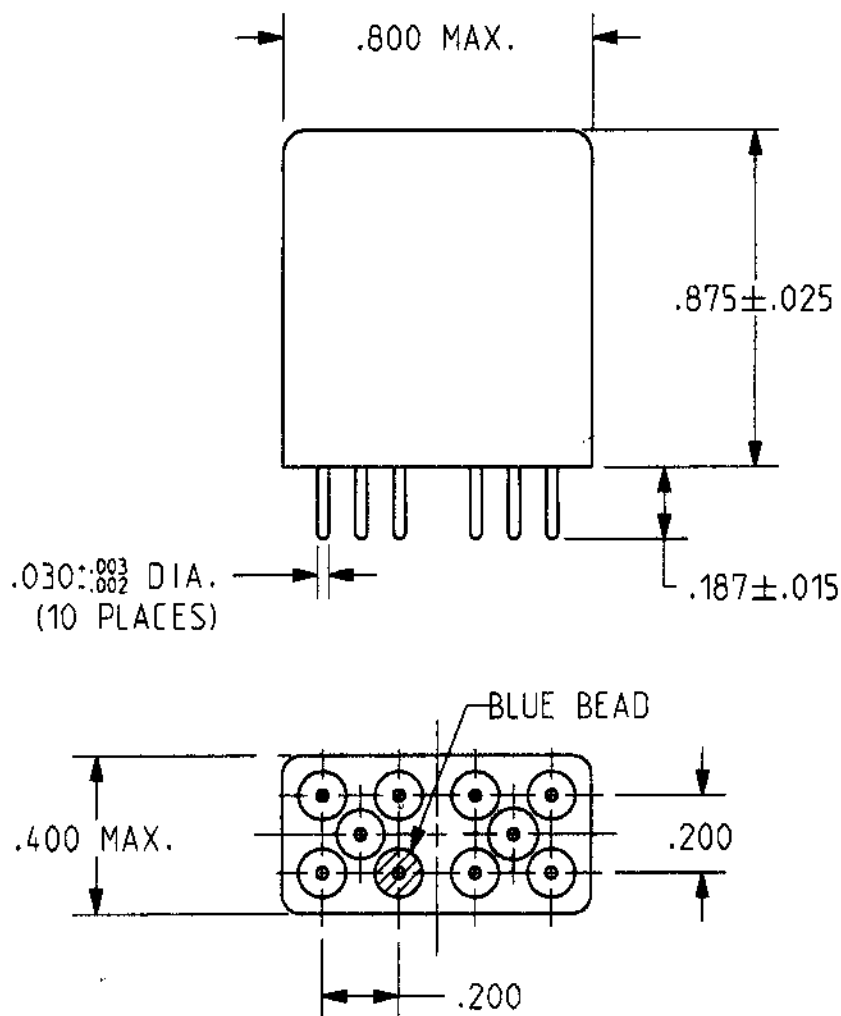

REV. 0

DCO 64173

TOL. = ±.010

COIL: @ 25°C

SET		RESET	
975 OHMS ±10%		975 OHMS ±10%	
26.5 VDC	NOMINAL VOLTAGE	26.5 VDC	NOMINAL VOLTAGE
12 VDC	MUST OPERATE	12 VDC	MUST OPERATE

ENVIRONMENT:

VIBRATION 10 Hz 3000 Hz 30 g's


SHOCK 100 g's 6 MS. DURATION

TEMPERATURE -65 °C TO +125 °C

NOTES: SET AND RESET TIME 5 MS MAX.

CONTACT BOUNCE 1.5 MS MAX.

CUSTOMER DATA SHEET

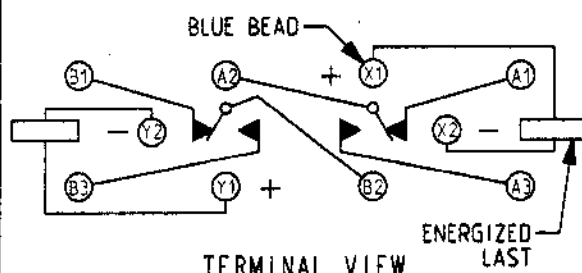

CONTACT RATING: LOW LEVEL TO 2A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 11/2/01

CK.TLG 11-2-01

CII Technologies
advanced control electronic solutions

CUST. GPL
CUST. NO. M39016/32-006

TYPE "3SAM" RELAY

3SAM1824A2

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[3SAM1824A2](#)