


REV. 0

TOL. = $\pm .010$

DCO 64253

| | | | |
|-------------------------------------|-----------------|---------------------|-----------------|
| COIL: @ 25°C | | | |
| SET | | RESET | |
| 300 OHMS $\pm 10\%$ | | 300 OHMS $\pm 10\%$ | |
| 12 VDC | NOMINAL VOLTAGE | 12 VDC | NOMINAL VOLTAGE |
| 5.8 VDC | MUST OPERATE | 5.8 VDC | MUST OPERATE |
| ENVIRONMENT: | | | |
| VIBRATION | 10 Hz | 3000 Hz | 30 g's |
| SHOCK | 100 g's | 6 MS. | DURATION |
| TEMPERATURE | -65 °C | TO | +125 °C |
| NOTES: SET AND RESET TIME 5 MS MAX. | | | |
| CONTACT BOUNCE 1.5 MS MAX. | | | |

CUSTOMER DATA SHEET

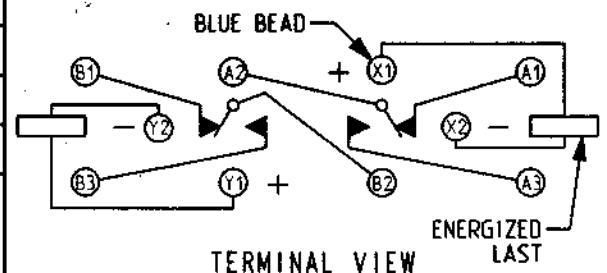

CONTACT RATING: LOW LEVEL TO 2A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. ASB 7 AUG 02

CK. 8/7/02

CII Technologies
advanced control electronic solutions

CUST. QPL
CUST. NO. M39016/32-009

TYPE "3SAM" RELAY

3SAM1827A2

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[3SAM1827A2](#)