

REV. 0

DCO 170403


COIL: @ 25°C
 RESISTANCE 100 OHMS ± 10%
 NOMINAL VOLTAGE 40.0 mADC
 MUST OPERATE 20.0 mADC
 MUST RELEASE 10.0 mADC MAX, 2.0 mADC MIN

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 15 g's
 SHOCK 100 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 15 MS MAX
 RELEASE TIME 10 MS MAX
 CONTACT BOUNCE 2 MS MAX

CUSTOMER DATA SHEET

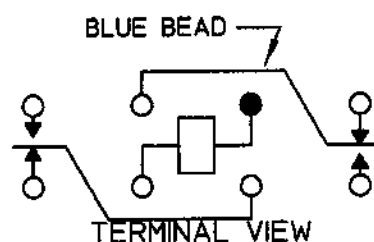

CONTACT RATING: LOW LEVEL TO 2A
 28 VDC RESISTIVE 100,000 OPERATIONS

DR. PBB 2/16/01

CK. TLG 02-16-01

CII Technologies
 advanced control electronic solutions

CUST. QPL
 CUST. NO. M5757/13-084 REV.

3SAT RELAY

3SAT1301A2

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[3SAT1301A2](#)