

REV. 0

DCO 170339

COIL: @ 25°C

RESISTANCE 5000 OHMS  $\pm 10\%$

NOMINAL VOLTAGE 6.0 mADC

MUST OPERATE 2.8 mADC

MUST RELEASE 1.4 mADC MAX, 0.3 mADC MIN

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 15 g's

SHOCK 100 g's 6 MS DURATION


TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 15 MS MAX.

RELEASE TIME 10 MS MAX.

CONTACT BOUNCE 2 MS MAX.

## CUSTOMER DATA SHEET

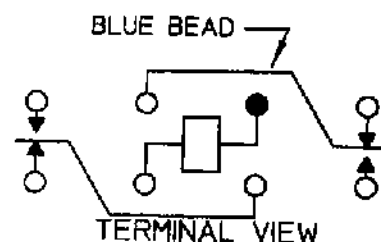

CONTACT RATING: 2 AMPS 28 VDC  
RESISTIVE 100,000 OPERATIONS

DR. PBB 12/6/00

CK. TLG 12-6-00

**CII Technologies**  
advanced control electronic solutions

CUST. QPL

CUST. NO. M5757/13-090

REV.

3SAT RELAY

3SAT1307A2

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[3SAT1307A2](#)