

REV. 0

DCO 170424


COIL: @ 25°C  
 RESISTANCE 2500 OHMS  
 NOMINAL VOLTAGE 8.0 mADC  
 MUST OPERATE 4.0 mADC  
 MUST RELEASE 2.0 mADC MAX, 0.40 mADC MIN

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 15 g's  
 SHOCK 100 g's 6 MS. DURATION  
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE 15 MS MAX  
RELEASE 10 MS MAX  
CONTACT BOUNCE 2 MS MAX

CUSTOMER DATA SHEET

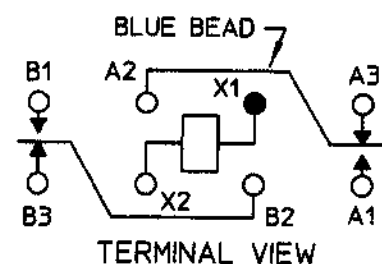

CONTACT RATING: LOW LEVEL TO 2A  
28 VDC RESISTIVE 100,000 OPERATIONS

DR. PBB 3/05/01

CK.TLG 3-5-01

**CII Technologies**  
 advanced control electronic solutions

CUST. QPL  
 CUST. NO. M5757/13-100 REV.

3SAT RELAY

3SAT1317A2

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[3SAT1317A2](#)