

REV. 0
DCO 170339


COIL: @ 25°C	
RESISTANCE	5000 OHMS
NOMINAL VOLTAGE	6.0 mADC
MUST OPERATE	2.8 mADC
MUST RELEASE	1.4 mADC MAX, 0.3 mADC MIN

ENVIRONMENT:

VIBRATION	10	CPS TO	2000	CPS @	15	g's
SHOCK	100	g's	6	MS. DURATION		
TEMPERATURE	-65	°C TO	+125	°C		

NOTES: OPERATE 15 MS MAX
RELEASE 10 MS MAX
CONTACT BOUNCE 2 MS MAX

CUSTOMER DATA SHEET

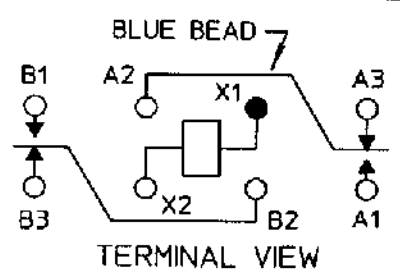

CONTACT RATING: LOW LEVEL TO 2A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. PBB 12/6/00 CK. TLG 12-11 -00



CUST. QPL	3SAT RELAY
CUST. NO. M5757/13-101 REV.	

3SAT1318A2

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[3SAT1318A2](#)