

REV. 0

DCO 170687


COIL: @ 25°C
 RESISTANCE 1000 OHMS ±10%
 NOMINAL VOLTAGE 13.0 mADC
 MUST OPERATE 6.5 mADC
 MUST RELEASE 3.1 mADC MAX, 0.65 mADC MIN

ENVIRONMENT:

VIBRATION 10 Hz TO 2000 Hz @ 15 g's
 SHOCK 100 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE 15 MS MAX
 RELEASE 10 MS MAX
 CONTACT BOUNCE 1 MS MAX

CUSTOMER DATA SHEET

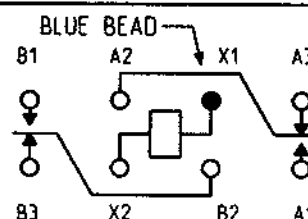

TERMINAL VIEW

CONTACT RATING: 2 AMPS 28 VDC
 RESISTIVE 100,000 OPERATIONS

DR. ASB 27MAY03

CK. 5/27/03

CII Technologies
 advanced control electronic solutions

CUST. QPL
 CUST. NO. M5757/13-107 REV.

"3SAT" RELAY

3SAT1324A2

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[3SAT1324A2](#)