

REV. 0

DCO 170352

COIL: @ 25°C  
 RESISTANCE 2500 OHMS  
 NOMINAL VOLTAGE 8.0 mADC  
 MUST OPERATE 4.0 mADC


MUST RELEASE 2.0 mADC MAX. 0.4 mADC MIN

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 15 g's  
 SHOCK 100 g's 6 MS. DURATION  
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE 15 MS MAX  
 RELEASE 10 MS MAX  
 CONTACT BOUNCE 1 MS MAX

CUSTOMER DATA SHEET

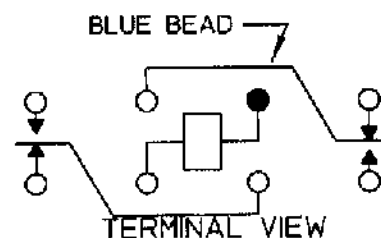

CONTACT RATING: 2 AMPS 28 VDC  
 RESISTIVE 100,000 OPERATIONS

DR. PBB 12/14/00

CK. TLG 12-14-00

**CI Technologies**  
 advanced control electronic solutions

CUST. QPL

CUST. NO. M5757/13-110

REV.

'3SAT' RELAY

3SAT1327A2

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[3SAT1327A2](#)