

REV. 0

DCO 170676

COIL: @ 25°C  
 RESISTANCE 10000 OHMS ±10%  
 NOMINAL VOLTAGE 4.0 mADC  
 MUST OPERATE 2.0 mADC  
 MUST RELEASE 1.0 mADC MAX, 0.2 mADC MIN.

ENVIRONMENT:

VIBRATION 10 Hz TO 2000 Hz @ 15 g's

SHOCK 100 g's 6 ± 1 MS. DURATION


TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE 15 MS MAX

RELEASE 10 MS MAX

CONTACT BOUNCE 2 MS MAX.

CUSTOMER DATA SHEET

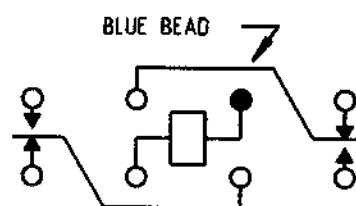

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO  
 2 AMPS @ 28 VDC RESISTIVE  
 100,000 OPERATIONS

DR. ASB 4 NOV 02

CK. 11/1/02

**CII Technologies**  
 advanced control electronic solutions

CUST. QPL

CUST. NO. M5757/13-123 REV.

3SAT RELAY

3SAT1340A2

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[3SAT1340A2](#)