

REV. 0

DCO 63167

COIL: @ 25°C

SET	RESET
975 OHMS ±10%	975 OHMS ±10%
26.5 VDC NOMINAL VOLTAGE	26.5 VDC NOMINAL VOLTAGE
13.5 VDC MUST OPERATE	13.5 VDC MUST OPERATE

ENVIRONMENT:

VIBRATION 10 Hz 3000 Hz 30 g's


SHOCK 100 g's 6 MS. DURATION

TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE 4 MS MAX.

CONTACT STABILIZATION 2.5 MS MAX.

CUSTOMER DATA SHEET

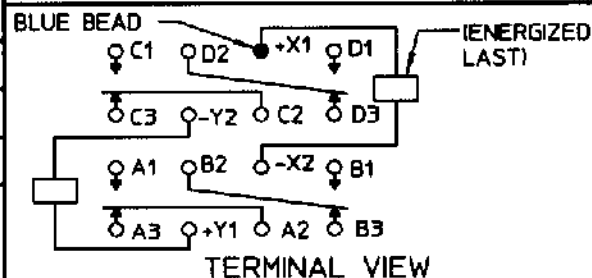

CONTACT RATING: LOW LEVEL TO  
2 AMPS 28 VDC RESISTIVE  
100,000 OPERATIONS

DR. B.D. 3/10/00

CK 3/10/00



COMMUNICATIONS  
INSTRUMENTS, INC.

CUST. QPL  
CUST. NO. M39016/31-003M

TYPE '3SBM' RELAY

3SBM1071A2

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[3SBM1071A2](#) [1617086-6](#)