

REV. 0
DCO 63279

COIL: @ 25°C

CUSTOMER DATA SHEET

SET

RESET

975 OHMS ±10%

975 OHMS ±10%

26.5 VDC NOMINAL VOLTAGE

26.5 VDC NOMINAL VOLTAGE

13.5 VDC MUST OPERATE

13.5 VDC MUST OPERATE

ENVIRONMENT:


VIBRATION 10 Hz 3000 Hz 30 g's

SHOCK 100 g's 6 MS. DURATION

TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE 4 MS MAX.

CONTACT BOUNCE 2.0 MS MAX.

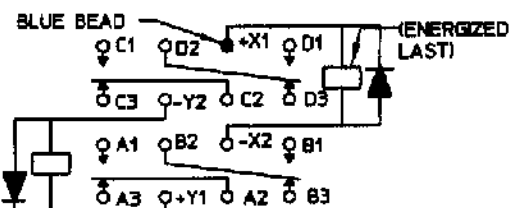

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO
2 AMPS 28 VDC RESISTIVE
100,000 OPERATIONS

DR. PBB 6-30-00

CK. 6/3/00



COMMUNICATIONS
INSTRUMENTS, INC.

CUST. QPL
CUST. NO. M39016/35-006L

TYPE '3SBM' RELAY

3SBM1106A2

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[3SBM1106A2](#)