
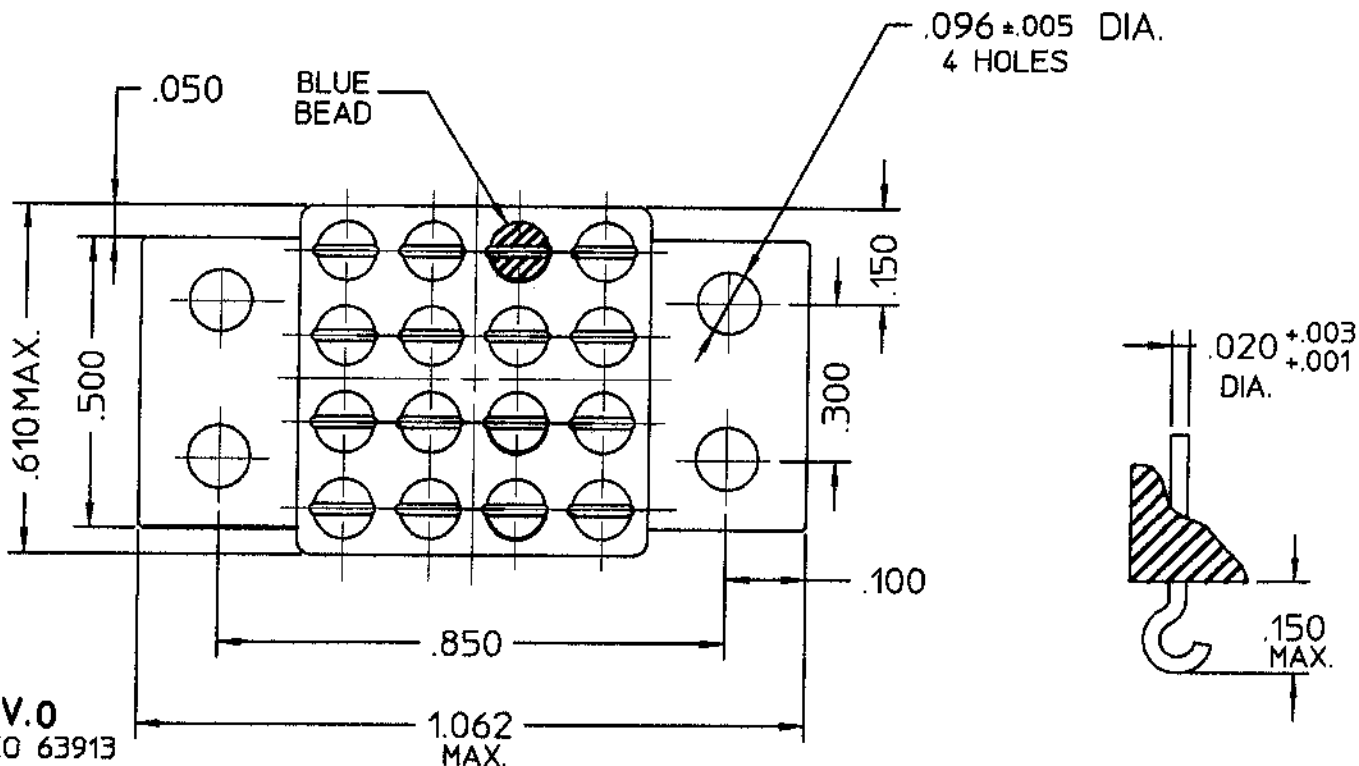


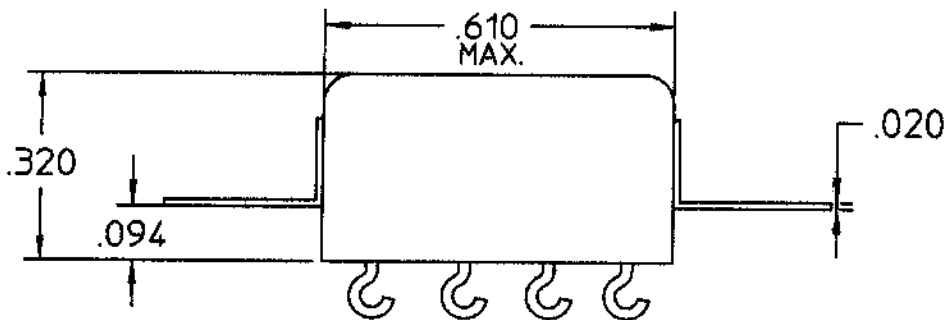

REV.0
DCO 63913

COIL: @ 25°C

CUSTOMER DATA SHEET

SET	RESET
975 OHMS ±10%	975 OHMS ±10%
26.5 NOMINAL VOLTAGE	26.5 NOMINAL VOLTAGE
13.5 MUST OPERATE	13.5 MUST OPERATE


ENVIRONMENT:

VIBRATION 10 Hz 3000 Hz 30 g's

SHOCK 100 g's 6 MS. DURATION

TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE 4 MS MAX.
CONTACT STABILIZATION 2.5 MS MAX.

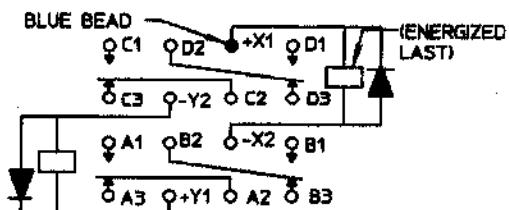

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO
2 AMPS 28 VDC RESISTIVE
100,000 OPERATIONS

DR. PBB 4/18/01

CK. 4/18/01

ICN Technologies
advanced control electronic solutions

CUST. QPL
CUST. NO. M39016/35-006M

TYPE '3SBM' RELAY

3SBM1112A2

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[3SBM1112A2](#)