

REV. 3

DCO 102478

COIL: @ 25°C  
 RESISTANCE 14-21 OHMS  
 NOMINAL VOLTAGE 6.0 VDC  
 MUST OPERATE 3.2 VDC  
 MUST RELEASE 1.8 VDC MAX .4 VDC MIN

ENVIRONMENT:


VIBRATION 10 CPS TO 2000 CPS @ 20 g's  
 SHOCK 50 g's 11 MS. DURATION  
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE & RELEASE 15 MS MAX.

OPERATE BOUNCE 5 MS MAX.

RELEASE BOUNCE 5 MS MAX.

CUSTOMER DATA SHEET

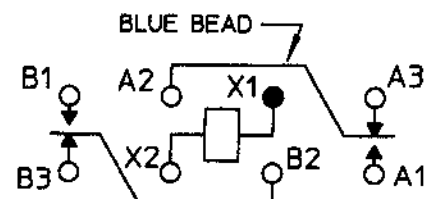

TERMINAL VIEW

CONTACT RATING: 10 AMPS 28 VDC  
 5 AMPS 115 VAC/400 Hz RESISTIVE  
 50,000 OPERATIONS

DR. R.B. 8/10/94 CK. TLG 11-28-00

**CH Technologies**  
 advanced control electronic solutions

CUST. QPL  
 CUST. NO. M5757/23-015 REV.

\*07" RELAY

B07D034BA2-0125

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[B07D034BA2-0125](#)