


REV. 3
DCO 102710

COIL: @ 25°C
RESISTANCE 170 OHMS ± 10%
NOMINAL VOLTAGE 18.0 VDC
MUST OPERATE 9.7 VDC
MUST RELEASE 1.15 VDC

ENVIRONMENT:
VIBRATION 10 CPS TO 2000 CPS @ 20 g's
SHOCK 50 g's 11 MS. DURATION
TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE & RELEASE 15 MS MAX.
OPERATE BOUNCE 5 MS MAX.
RELEASE BOUNCE 5 MS MAX.

CUSTOMER DATA SHEET

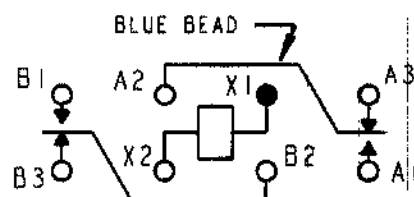

TERMINAL VIEW

CONTACT RATING: 10 AMPS 28 VDC
5 AMPS 115 VAC/400 Hz RESISTIVE
50,000 OPERATIONS

DR. R.B. 1/9/92 CK. TLG 8-17-01

CII Technologies
advanced control electronic solutions

CUST OPL
CUST. NO. M5757/23-041 REV.

"07" RELAY

B07D034BZ2-0357

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[B07D034BZ2-0357](#)