


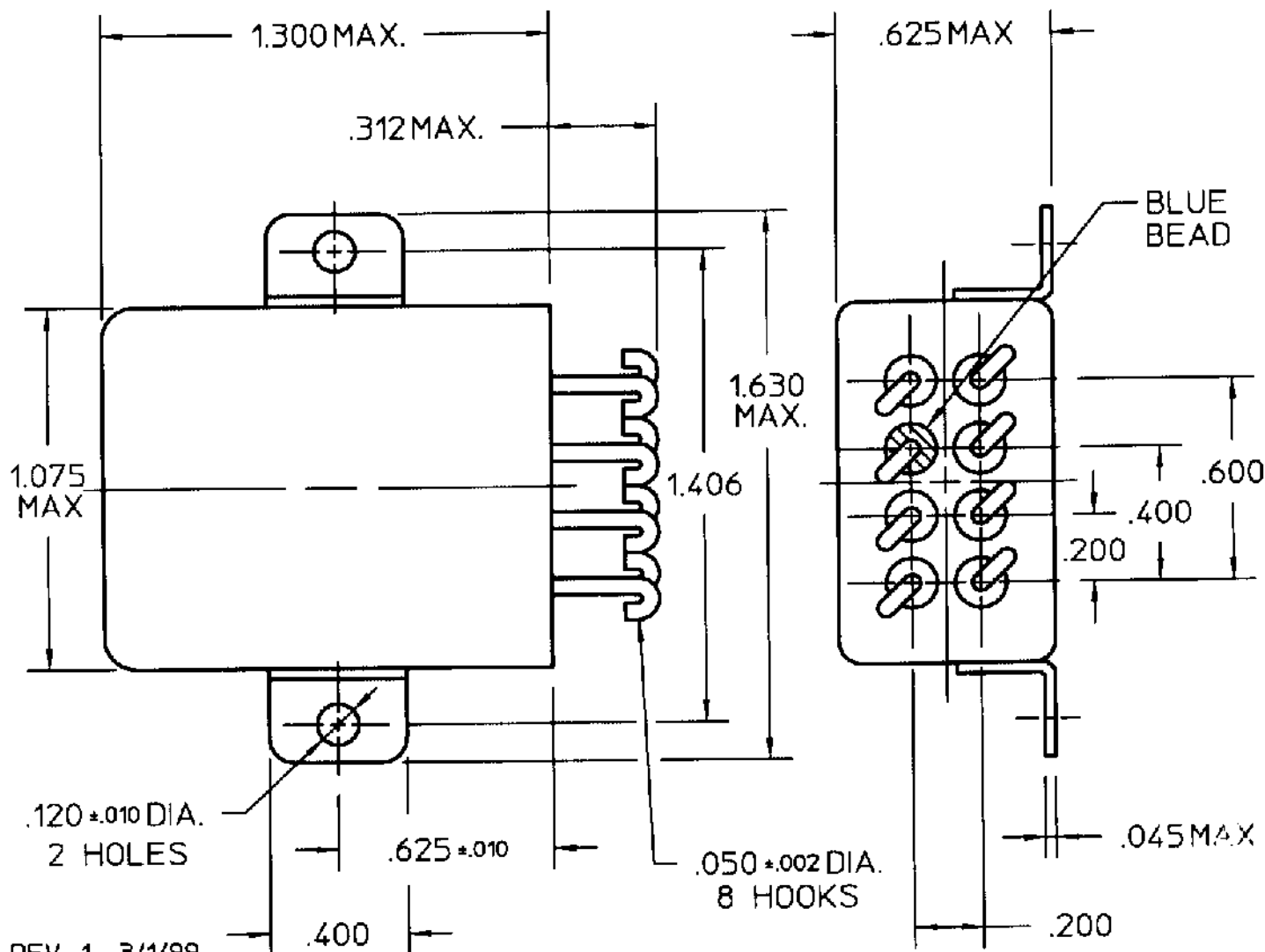

REV. 1 3/1/99
DCO 102094

COIL: Ø 25°C

RESISTANCE 14-21 OHMS

NOMINAL VOLTAGE 6.0 VDC

MUST OPERATE 3.25 VDC

MUST RELEASE 1.8 VDC MAX. 0.38 VDC MIN.

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 20 g's

SHOCK 50 g's 11 MS. DURATION


TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE & RELEASE 15 MS MAX.

OPERATE BOUNCE 5 MS MAX.

RELEASE BOUNCE 5 MS MAX.

CUSTOMER DATA SHEET

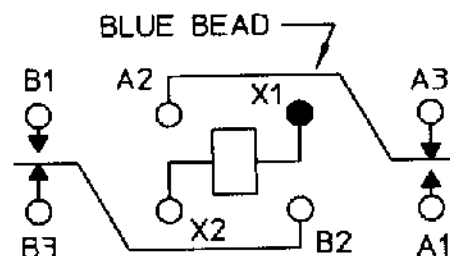

CONTACT RATING: 10 AMPS 28 VDC
5 AMPS 115 VAC/400 Hz RESISTIVE
50,000 OPERATIONS

DR. R.B. 7/2/97 CK3/1/02/98

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. QPL
CUST. NO. M5757/23-033

TYPE "07" RELAY

B07D932BA2-0350

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[B07D932BA2-0350](#)