


REV. 1
DCO 102710

COIL: @ 25°C
 RESISTANCE 58-83 OHMS
 NOMINAL VOLTAGE 12.0 VDC
 MUST OPERATE 6.5 VDC
 MUST RELEASE 3.6 VDC MAX, 0.8 VDC MIN.

ENVIRONMENT:
 VIBRATION 10 CPS TO 2000 CPS @ 20 g's
 SHOCK 50 g's 11 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C
 NOTES: OPERATE & RELEASE 15 MS MAX.
 OPERATE BOUNCE 5 MS MAX.
 RELEASE BOUNCE 5 MS MAX.

CUSTOMER DATA SHEET

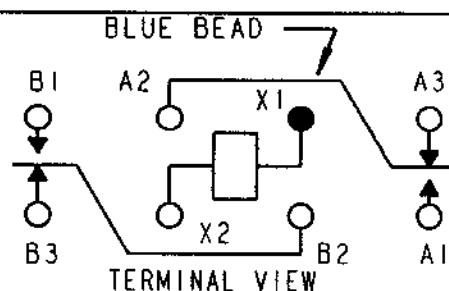

CONTACT RATING: 10 AMPS 28 VDC
 5 AMPS 115 VAC/400 H₂ RESISTIVE
 50,000 OPERATIONS

DR. RB 3/9/98 CK. TLG 8-17-01

CII Technologies
 advanced control electronic solutions

CUST. QPL
 CUST. NO. M5757/23-009 REV.

"07" RELAY

B07D934BB2-0119

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[B07D934BB2-0119](#) [4-1617004-7](#)